

TIMKEN



TIMKEN® SPLIT CYLINDRICAL ROLLER BEARING HOUSED UNIT

INTERCHANGE GUIDE

ABOUT THE TIMKEN COMPANY

As a global leader in bearings and power transmission systems, Timken focuses on precise solution design, materials and craftsmanship to deliver reliable and efficient performance that improves productivity and uptime. Timken offers a full range of bearings, belts, chains, couplings, gears and lubricants, along with rebuild and repair services. Timken (NYSE; TKR; www.timken.com) applies its proven expertise in metallurgy, tribology and mechanical power transmission to create innovative approaches to customers’ complex needs. Global availability of products and engineering talent, combined with exceptional service delivery across markets, makes Timken a preferred choice worldwide.

To view more Timken catalogs, go to www.timken.com/catalogs for interactive versions, or to download our catalog app to your smartphone or mobile device.

**TIMKEN® SPLIT CYLINDRICAL
ROLLER BEARING HOUSED
UNIT INTERCHANGE GUIDE
INDEX**

Introduction 4

Technical Features..... 5

Housed Unit Support Types 6

Nomenclature..... 7


Interchange Charts 8



STANDARD UNIT ANATOMY

Maximize uptime with an easy-to-install and quick-to-maintain solution to replace solid unit housings:

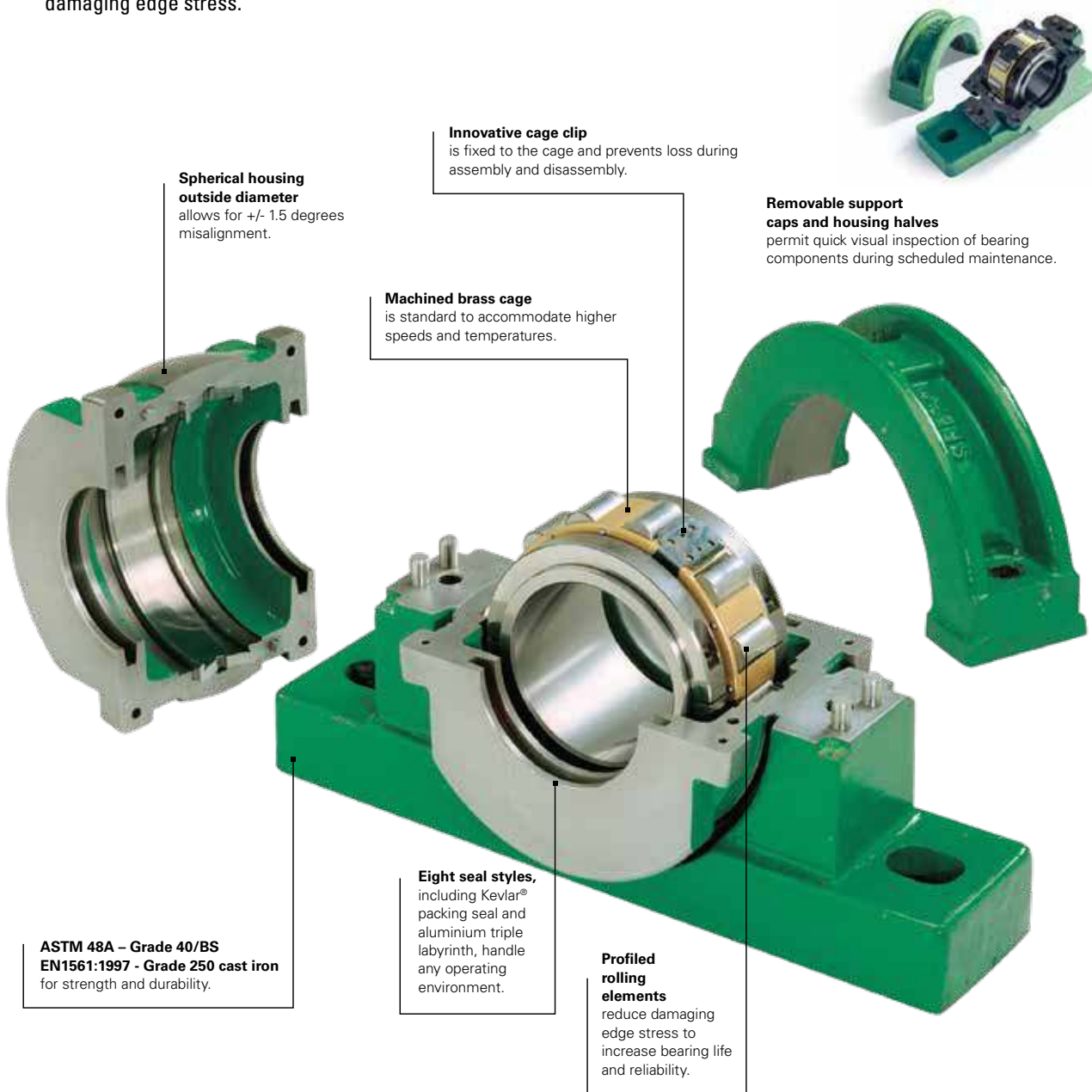

- Simple mounting procedure includes an innovative cage clip design.
- Easy bearing replacement improves uptime.
- Operate at higher speeds, temperature and acceleration due to a precision machined brass cage that reduces cage failure.
- Perform longer thanks to a robust pedestal design featuring double webs and thick sections of high-grade cast iron.
- Profiled rolling elements improve performance by reducing damaging edge stress.
- Handle a range of operating environments with eight application seal designs.
- Closely match load requirements with specially-engineered application-bearing
- Choose from housing styles designed for many different applications.
- Dimensionally interchangeable with split to the shaft roller bearings.
- Dimensionally interchangeable with SN/SD/SAF housings.
- Expert engineering service and support.
- Quick-fit design available for solid block conversions.



THE TIMKEN ADVANTAGES:

- Stronger support pedestals
- Easy-to-install SNQ/SAFQ Quick-Fit angled pedestals
- Sealing solutions for the harshest environments
- Interchangeable with competitive split-housed units
- Expert engineering services

TABLE 3. TIMKEN VS. COMPETITOR DESIGN COMPARISON

Timken Split Cylindrical Roller Bearings	Competitor's Design
<p>One durable design – A sturdy, precision-machined, window-type brass cage delivers reliable performance in harsh operating environments and demanding applications.</p>	<p>There is no standard design across their catalogue range. A variety of less robust designs includes polyamide, pressed steel, die cast and machined aluminium cages.</p>
<p>Fast assembly & easy maintenance – An innovative integrated cage joint clip makes easy assembly.</p>	<p>The c-section spring cage clip is a separate piece that can be difficult to fit and easily lost.</p>
<p>Stronger – Robust support pedestals and housings are made from HT250 grade cast iron and conform to BS EN1561. EN-GJS-450-10 grade ductile iron also is available.</p>	<p>Support pedestals and housings made from HT220 grade cast iron are weaker due to lower tensile strength. EN-GJS-400 grade ductile iron is less robust than the grade used by Timken.</p>
<p>Easiest installation – An angled SNQ/SDQ/SAFQ support pedestal makes installation simple and fast. The pedestal slides under the shaft eliminating the need to raise it and remove a drive to install a bearing. A wide range of sizes is available. The SAFQ pedestal is made from SG iron.</p>	<p>There is no product offering available currently.</p>
<p>Well protected – There are many sealing options. High-temperature resistant ATL triple labyrinth seals perform reliably in aggressive environments. KPS Kevlar® packing seals or high-temperature flinger seals may withstand even the harshest environments.</p>	<p>The range of sealing options is limited. Standard ATL Seals are not suitable for high-temperature operation. There is no Kevlar or flinger seal option.</p>
	
<p>Easy-to-assemble integrated cage clip and precision machined brass cage</p>	<p>Aluminium cage and easy-to-misplace cage clip</p>

Kevlar® is a registered trademark of E.I. du Pont de Nemours and Company or its affiliates.



HOUSED UNIT SUPPORT TYPES

Timken bearings and housings may be mounted in a variety of support units according to the application and loading constraints. A number of variants are available as standard types with other unit types available on request. Timken offers a design and manufacturing facility to produce custom units to cover more specialized applications.

PILLOW BLOCK (SUPPORT) TYPE

This is by far the most popular method for mounting Timken units. These supports are manufactured from high strength, ASTM 48A grade 35 cast iron. This, combined with the robust design, provides a stable, rigid base, allowing the split bearing fitted to give optimum performance.



Fig. 6. Pillow block support type.

FLANGE UNITS

In applications where bearings need to be mounted against horizontal or vertical faces, Timken flange units provide a simple means of achieving this goal. Again, the use of ASTM 48A Grade 35 cast iron ensures a durable unit.



Fig. 7. Flange units.

HANGER UNITS

A compact unit commonly used for supporting screw conveyors or similar equipment.



Fig. 8. Hanger units.

TAKE-UP UNITS

These sliding units can be used to effectively tension conveyor and elevator systems. Both pull and push types are available.



Fig. 9. Take-up units.

NOMENCLATURE

In order to provide our customers with clear and concise labeling, Timken has endeavored to keep things simple when creating references. The following should cover the majority of ordering

situations however, as always, your local Timken engineer will be pleased to provide further assistance if required.

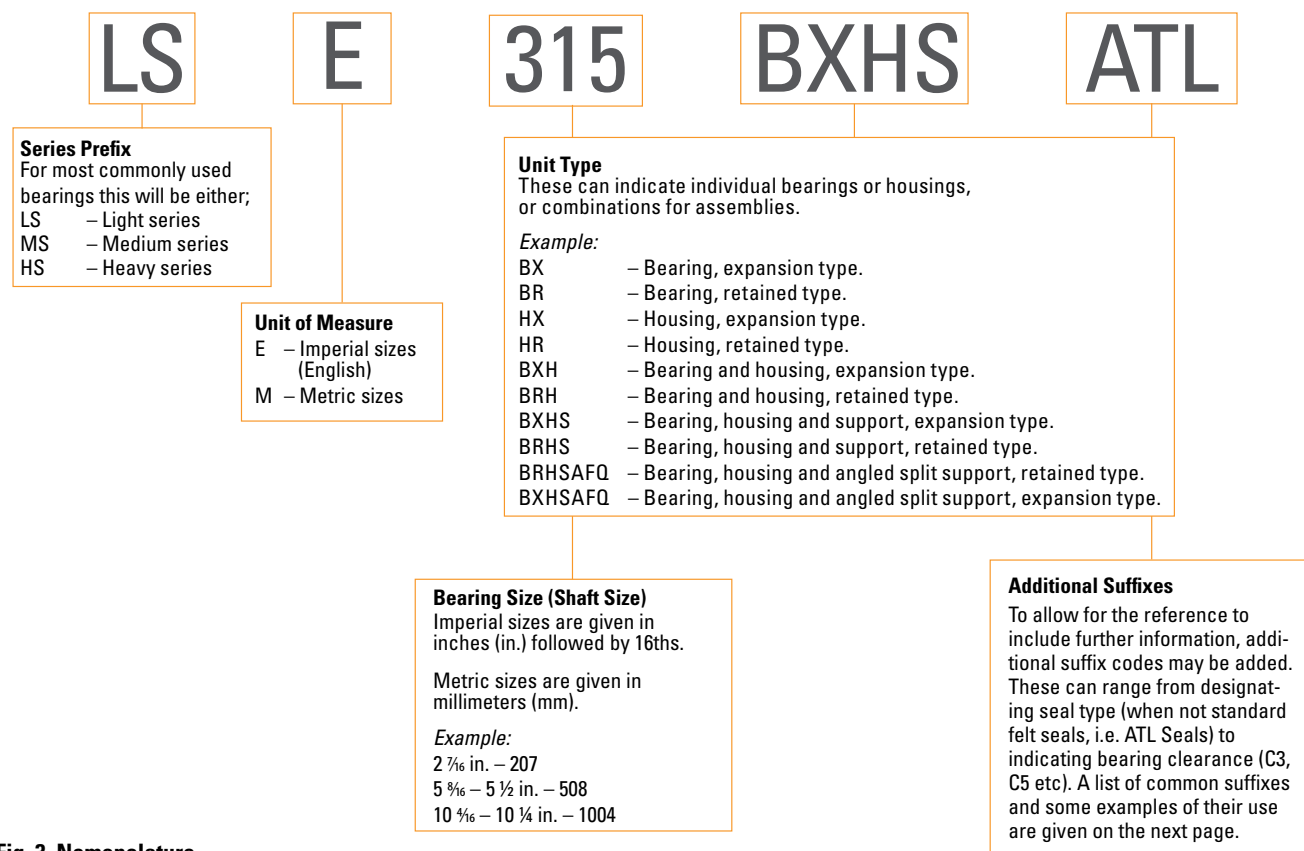


Fig. 3. Nomenclature.

For Triple Labyrinth (ATL) style housings and seals see pages 32-34.

Typical Examples

LSE108BXHATL

Light series 1 1/2 in. bearing with housing and ATL Seals.

LSE407BR

Light series 4 7/16 in. bearing retained.

MSE200BXHSATL

Medium series 2 in. expansion bearing with housing and with ATL Seals.

LSE700BXHSAFQATL

Light series 7 in. bearing, housing and angled split support retained type with ATL Seals .

MSE815BRHSKPS

Medium series 8 15/16 in. bearing, housing and support, retained type with Kevlar® seals.

LSE315BXHSATL

Light series 3 15/16 in. bearing, housing and support, expansion type with ATL Seals.

SPLIT CYLINDRICAL ROLLER BEARING INTERCHANGE GUIDE

The interchange guide is for reference only. Timken manufactures all units to be dimensionally comparable with competing manufacturers' in the market place.

This guide shows basic interchangeability, not all dimensions and specifications will be exactly identical.

For specific dimensions of each bearing part number, please refer to the corresponding section within the Timken® Split Cylindrical Roller Bearing Catalog (10868).

If you have questions or need further assistance using the interchange guide, please contact your Timken sales representative.

Cooper Part Number	Timken Part Number	Timken Description
01B1000EX	LSE1000BX	Light Series Imperial Expansion Bearing: 10 in. bore
01B1000GR	LSE1000BR	Light Series Imperial Retained Bearing: 10 in. bore
01B103EX	LSE103BX	Light Series Imperial Expansion Bearing: 1 3/16 in. bore
01B103GR	LSE103BR	Light Series Imperial Retained Bearing: 1 3/16 in. bore
01B104EX	LSE104BX	Light Series Imperial Expansion Bearing: 1 1/4 in. bore
01B104GR	LSE104BR	Light Series Imperial Retained Bearing: 1 1/4 in. bore
01B107EX	LSE107BX	Light Series Imperial Expansion Bearing: 1 7/16 in. bore
01B107GR	LSE107BR	Light Series Imperial Retained Bearing: 1 7/16 in. bore
01B108EX	LSE108BX	Light Series Imperial Expansion Bearing: 1 1/2 in. bore
01B108GR	LSE108BR	Light Series Imperial Retained Bearing: 1 1/2 in. bore
01B1100EX	LSE1100BX	Light Series Imperial Expansion Bearing: 11 in. bore
01B1100GR	LSE1100BR	Light Series Imperial Retained Bearing: 11 in. bore
01B110MEX	LSM110BX	Light Series Metric Expansion Bearing: 110mm bore
01B110MGR	LSM110BR	Light Series Metric Retained Bearing: 110mm bore
01B115MEX	LSM115BX	Light Series Metric Expansion Bearing: 115mm bore
01B115MGR	LSM115BR	Light Series Metric Retained Bearing: 115mm bore
01B1200EX	LSE1200BX	Light Series Imperial Expansion Bearing: 12 in. bore
01B1200GR	LSE1200BR	Light Series Imperial Retained Bearing: 12 in. bore
01B120MEX	LSM120BX	Light Series Metric Expansion Bearing: 120mm bore
01B120MGR	LSM120BR	Light Series Metric Retained Bearing: 120mm bore
01B125MEX	LSM125BX	Light Series Metric Expansion Bearing: 125mm bore
01B125MGR	LSM125BR	Light Series Metric Retained Bearing: 125mm bore
01B1300EX	LSE1300BX	Light Series Imperial Expansion Bearing: 13 in. bore
01B1300GR	LSE1300BR	Light Series Imperial Retained Bearing: 13 in. bore
01B130MEX	LSM130BX	Light Series Metric Expansion Bearing: 130mm bore
01B130MGR	LSM130BR	Light Series Metric Retained Bearing: 130mm bore
01B135MEX	LSM135BX	Light Series Metric Expansion Bearing: 135mm bore
01B135MGR	LSM135BR	Light Series Metric Retained Bearing: 135mm bore
01B1400EX	LSE1400BX	Light Series Imperial Expansion Bearing: 14 in. bore
01B1400GR	LSE1400BR	Light Series Imperial Retained Bearing: 14 in. bore
01B140MEX	LSM140BX	Light Series Metric Expansion Bearing: 140mm bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01B140MGR	LSM140BR	Light Series Metric Retained Bearing: 140mm bore
01B1500EX	LSE1500BX	Light Series Imperial Expansion Bearing: 15 in. bore
01B1500GR	LSE1500BR	Light Series Imperial Retained Bearing: 15 in. bore
01B150MEX	LSM150BX	Light Series Metric Expansion Bearing: 150mm bore
01B150MGR	LSM150BR	Light Series Metric Retained Bearing: 150mm bore
01B155MEX	LSM155BX	Light Series Metric Expansion Bearing: 155mm bore
01B155MGR	LSM155BR	Light Series Metric Retained Bearing: 155mm bore
01B1600EX	LSE1600BX	Light Series Imperial Expansion Bearing: 16 in. bore
01B1600GR	LSE1600BR	Light Series Imperial Retained Bearing: 16 in. bore
01B160MEX	LSM160BX	Light Series Metric Expansion Bearing: 160mm bore
01B160MGR	LSM160BR	Light Series Metric Retained Bearing: 160mm bore
01B1700EX	LSE1700BX	Light Series Imperial Expansion Bearing: 17 in. bore
01B1700GR	LSE1700BR	Light Series Imperial Retained Bearing: 17 in. bore
01B170MEX	LSM170BX	Light Series Metric Expansion Bearing: 170mm bore
01B170MGR	LSM170BR	Light Series Metric Retained Bearing: 170mm bore
01B1800EX	LSE1800BX	Light Series Imperial Expansion Bearing: 18 in. bore
01B1800GR	LSE1800BR	Light Series Imperial Retained Bearing: 18 in. bore
01B180MEX	LSM180BX	Light Series Metric Expansion Bearing: 180mm bore
01B180MGR	LSM180BR	Light Series Metric Retained Bearing: 180mm bore
01B1900EX	LSE1900BX	Light Series Imperial Expansion Bearing: 19 in. bore
01B1900GR	LSE1900BR	Light Series Imperial Retained Bearing: 19 in. bore
01B190MEX	LSM190BX	Light Series Metric Expansion Bearing: 190mm bore
01B190MGR	LSM190BR	Light Series Metric Retained Bearing: 190mm bore
01B2000EX	LSE2000BX	Light Series Imperial Expansion Bearing: 20 in. bore
01B2000GR	LSE2000BR	Light Series Imperial Retained Bearing: 20 in. bore
01B200MEX	LSM200BX	Light Series Metric Expansion Bearing: 200mm bore
01B200MGR	LSM200BR	Light Series Metric Retained Bearing: 200mm bore
01B2100EX	LSE2100BX	Light Series Imperial Expansion Bearing: 21 in. bore
01B2100GR	LSE2100BR	Light Series Imperial Retained Bearing: 21 in. bore
01B2200EX	LSE2200BX	Light Series Imperial Expansion Bearing: 22 in. bore
01B2200GR	LSE2200BR	Light Series Imperial Retained Bearing: 22 in. bore
01B220MEX	LSM220BX	Light Series Metric Expansion Bearing: 220mm bore
01B220MGR	LSM220BR	Light Series Metric Retained Bearing: 220mm bore
01B2300EX	LSE2300BX	Light Series Imperial Expansion Bearing: 23 in. bore
01B2300GR	LSE2300BR	Light Series Imperial Retained Bearing: 23 in. bore
01B2400EX	LSE2400BX	Light Series Imperial Expansion Bearing: 24 in. bore
01B2400GR	LSE2400BR	Light Series Imperial Retained Bearing: 24 in. bore
01B240MEX	LSM240BX	Light Series Metric Expansion Bearing: 240mm bore
01B240MGR	LSM240BR	Light Series Metric Retained Bearing: 240mm bore
01B260MEX	LSM260BX	Light Series Metric Expansion Bearing: 260mm bore
01B260MGR	LSM260BR	Light Series Metric Retained Bearing: 260mm bore
01B280MEX	LSM280BX	Light Series Metric Expansion Bearing: 280mm bore
01B280MGR	LSM280BR	Light Series Metric Retained Bearing: 280mm bore
01B300MEX	LSM300BX	Light Series Metric Expansion Bearing: 300mm bore
01B300MGR	LSM300BR	Light Series Metric Retained Bearing: 300mm bore
01B30MEX	LSM30BX	Light Series Metric Expansion Bearing: 30mm bore
01B30MGR	LSM30BR	Light Series Metric Retained Bearing: 30mm bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01B320MEX	LSM30BR	Light Series Metric Expansion Bearing: 320mm bore
01B320MGR	LSM320BR	Light Series Metric Retained Bearing: 320mm bore
01B340MEX	LSM340BX	Light Series Metric Expansion Bearing: 340mm bore
01B340MGR	LSM340BR	Light Series Metric Retained Bearing: 340mm bore
01B35MEX	LSM35BX	Light Series Metric Expansion Bearing: 35mm bore
01B35MGR	LSM35BR	Light Series Metric Retained Bearing: 35mm bore
01B360MEX	LSM360BX	Light Series Metric Expansion Bearing: 360mm bore
01B360MEX	LSM360BX	Light Series Metric Expansion Bearing: 360mm bore
01B360MGR	LSM360BR	Light Series Metric Retained Bearing: 360mm bore
01B380MEX	LSM380BX	Light Series Metric Expansion Bearing: 380mm bore
01B380MGR	LSM380BR	Light Series Metric Retained Bearing: 380mm bore
01B400MEX	LSM400BX	Light Series Metric Expansion Bearing: 400mm bore
01B400MGR	LSM400BR	Light Series Metric Retained Bearing: 400mm bore
01B403EX	LSE403BX	Light Series Imperial Expansion Bearing: 4 ³ / ₁₆ in. bore
01B403GR	LSE403BR	Light Series Imperial Retained Bearing: 4 ³ / ₁₆ in. bore
01B404EX	LSE404BX	Light Series Imperial Expansion Bearing: 4 ¹ / ₄ in. bore
01B404GR	LSE404BR	Light Series Imperial Retained Bearing: 4 ¹ / ₄ in. bore
01B407EX	LSE407BX	Light Series Imperial Expansion Bearing: 4 ⁷ / ₁₆ in. bore
01B407GR	LSE407BR	Light Series Imperial Retained Bearing: 4 ⁷ / ₁₆ in. bore
01B408EX	LSE408BX	Light Series Imperial Expansion Bearing: 4 ¹ / ₂ in. bore
01B408GR	LSE408BR	Light Series Imperial Retained Bearing: 4 ¹ / ₂ in. bore
01B40MEX	LSM40BX	Light Series Metric Expansion Bearing: 40mm bore
01B40MGR	LSM40BR	Light Series Metric Retained Bearing: 40mm bore
01B411EX	LSE411BX	Light Series Imperial Expansion Bearing: 4 ¹¹ / ₁₆ in. bore
01B411GR	LSE411BR	Light Series Imperial Retained Bearing: 4 ¹¹ / ₁₆ in. bore
01B412EX	LSE412BX	Light Series Imperial Expansion Bearing: 4 ¹ / ₂ in. bore
01B412GR	LSE412BR	Light Series Imperial Retained Bearing: 4 ¹ / ₂ in. bore
01B415EX	LSE415BX	Light Series Imperial Expansion Bearing: 4 ⁵ / ₁₆ in. bore
01B415GR	LSE415BR	Light Series Imperial Retained Bearing: 4 ⁵ / ₁₆ in. bore
01B420MEX	LSM420BX	Light Series Metric Expansion Bearing: 420mm bore
01B420MGR	LSM420BR	Light Series Metric Retained Bearing: 420mm bore
01B440MEX	LSM440BX	Light Series Metric Expansion Bearing: 440mm bore
01B440MGR	LSM440BR	Light Series Metric Retained Bearing: 440mm bore
01B460MEX	LSM460BX	Light Series Metric Expansion Bearing: 460mm bore
01B460MGR	LSM460BR	Light Series Metric Retained Bearing: 460mm bore
01B480MEX	LSM480BX	Light Series Metric Expansion Bearing: 480mm bore
01B480MGR	LSM480BR	Light Series Metric Retained Bearing: 480mm bore
01B500EX	LSE500BX	Light Series Imperial Expansion Bearing: 5 in. bore
01B500GR	LSE500BR	Light Series Imperial Retained Bearing: 5 in. bore
01B500MEX	LSM500BX	Light Series Metric Expansion Bearing: 500mm bore
01B500MGR	LSM500BR	Light Series Metric Retained Bearing: 500mm bore
01B503EX	LSE503BX	Light Series Imperial Expansion Bearing: 5 ³ / ₁₆ in. bore
01B503GR	LSE503BR	Light Series Imperial Retained Bearing: 5 ³ / ₁₆ in. bore
01B504EX	LSE504BX	Light Series Imperial Expansion Bearing: 5 ¹ / ₁₆ in. bore
01B504GR	LSE504BR	Light Series Imperial Retained Bearing: 5 ¹ / ₁₆ in. bore
01B507EX	LSE507BX	Light Series Imperial Expansion Bearing: 5 ⁷ / ₁₆ in. bore
01B507GR	LSE507BR	Light Series Imperial Retained Bearing: 5 ⁷ / ₁₆ in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01B508EX	LSE507BR	Light Series Imperial Expansion Bearing: 5 1/2 in. bore
01B508GR	LSE508BR	Light Series Imperial Retained Bearing: 5 1/2 in. bore
01B511EX	LSE511BX	Light Series Imperial Expansion Bearing: 5 1/4 in. bore
01B511GR	LSE511BR	Light Series Imperial Retained Bearing: 5 1/4 in. bore
01B512EX	LSE512BX	Light Series Imperial Expansion Bearing: 5 1/8 in. bore
01B512GR	LSE512BR	Light Series Imperial Retained Bearing: 5 1/8 in. bore
01B515EX	LSE515BX	Light Series Imperial Expansion Bearing: 5 3/8 in. bore
01B515GR	LSE515BR	Light Series Imperial Retained Bearing: 5 3/8 in. bore
01B530MEX	LSM530BX	Light Series Metric Expansion Bearing: 530mm bore
01B530MGR	LSM530BR	Light Series Metric Retained Bearing: 530mm bore
01B55MEX	LSM55BX	Light Series Metric Expansion Bearing: 55mm bore
01B55MGR	LSM55BR	Light Series Metric Retained Bearing: 55mm bore
01B560MEX	LSM560BX	Light Series Metric Expansion Bearing: 560mm bore
01B560MGR	LSM560BR	Light Series Metric Retained Bearing: 560mm bore
01B600EX	LSE600BX	Light Series Imperial Expansion Bearing: 6 in. bore
01B600GR	LSE600BR	Light Series Imperial Retained Bearing: 6 in. bore
01B600MEX	LSM600BX	Light Series Metric Expansion Bearing: 600mm bore
01B600MGR	LSM600BR	Light Series Metric Retained Bearing: 600mm bore
01B607EX	LSE607BX	Light Series Imperial Expansion Bearing: 6 7/16 in. bore
01B607GR	LSE607BR	Light Series Imperial Retained Bearing: 6 7/16 in. bore
01B608EX	LSE608BX	Light Series Imperial Expansion Bearing: 6 1/2 in. bore
01B608GR	LSE608BR	Light Series Imperial Retained Bearing: 6 1/2 in. bore
01B615EX	LSE615BX	Light Series Imperial Expansion Bearing: 6 3/8 in. bore
01B615GR	LSE615BR	Light Series Imperial Retained Bearing: 6 3/8 in. bore
01B700EX	LSE700BX	Light Series Imperial Expansion Bearing: 7 in. bore
01B700GR	LSE700BR	Light Series Imperial Retained Bearing: 7 in. bore
01B708EX	LSE708BX	Light Series Imperial Expansion Bearing: 7 1/2 in. bore
01B708GR	LSE708BR	Light Series Imperial Retained Bearing: 7 1/2 in. bore
01B715EX	LSE715BX	Light Series Imperial Expansion Bearing: 7 3/8 in. bore
01B715GR	LSE715BR	Light Series Imperial Retained Bearing: 7 3/8 in. bore
01B800EX	LSE800BX	Light Series Imperial Expansion Bearing: 8 in. bore
01B800GR	LSE800BR	Light Series Imperial Retained Bearing: 8 in. bore
01B808EX	LSE808BX	Light Series Imperial Expansion Bearing: 8 1/2 in. bore
01B808GR	LSE808BR	Light Series Imperial Retained Bearing: 8 1/2 in. bore
01B900EX	LSE900BX	Light Series Imperial Expansion Bearing: 9 in. bore
01B900GR	LSE900BR	Light Series Imperial Retained Bearing: 9 in. bore
01B908EX	LSE908BX	Light Series Imperial Expansion Bearing: 9 1/2 in. bore
01B908GR	LSE908BR	Light Series Imperial Retained Bearing: 9 1/2 in. bore
01BC1000EXAT	LSE1000BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 10 in. bore
01BC1000GRAT	LSE1000BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 10 in. bore
01BC103EXAT	LSE103BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 3/8 in. bore
01BC103GRAT	LSE103BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 3/8 in. bore
01BC104EXAT	LSE104BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 1/4 in. bore
01BC104GRAT	LSE104BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 1/4 in. bore
01BC107EXAT	LSE107BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 7/8 in. bore
01BC107GRAT	LSE107BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 7/8 in. bore
01BC108EXAT	LSE108BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 1/2 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01BC108GRAT	LSE108BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 ½ in. bore
01BC1100EXAT	LSE1100BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 11 in. bore
01BC1100GRAT	LSE1100BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 11 in. bore
01BC110MEXAT	LSM110BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 110mm bore
01BC110MGRAT	LSM110BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 110mm bore
01BC115MEXAT	LSM115BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 115mm bore
01BC115MGRAT	LSM115BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 115mm bore
01BC1200EXAT	LSE1200BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 12 in. bore
01BC1200GRAT	LSE1200BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 12 in. bore
01BC120MEXAT	LSM120BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 120mm bore
01BC120MGRAT	LSM120BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 120mm bore
01BC125MEXAT	LSM125BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 125mm bore
01BC125MGRAT	LSM125BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 125mm bore
01BC1300EXAT	LSE1300BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 13 in. bore
01BC1300EXLAB	LSE1300BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
01BC1300GRAT	LSE1300BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 13 in. bore
01BC1300GRLAB	LSE1300BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
01BC130MEXAT	LSM130BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 130mm bore
01BC130MGRAT	LSM130BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 130mm bore
01BC135MEXAT	LSM135BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 135mm bore
01BC135MGRAT	LSM135BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 135mm bore
01BC1400EXAT	LSE1400BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 14 in. bore
01BC1400EXLAB	LSE1400BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
01BC1400GRAT	LSE1400BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 14 in. bore
01BC1400GRLAB	LSE1400BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
01BC140MEXAT	LSM140BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 140mm bore
01BC140MGRAT	LSM140BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 140mm bore
01BC1500EXLAB	LSE1500BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
01BC1500GRLAB	LSE1500BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
01BC150MEXAT	LSM150BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 150mm bore
01BC150MGRAT	LSM150BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 150mm bore
01BC155MEXAT	LSM155BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 155mm bore
01BC155MGRAT	LSM155BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 155mm bore
01BC1600EXLAB	LSE1600BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 16 in. bore
01BC1600GRLAB	LSE1600BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 16 in. bore
01BC160MEXAT	LSM160BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 160mm bore
01BC160MGRAT	LSM160BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 160mm bore
01BC1700EXLAB	LSE1700BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
01BC1700GRLAB	LSE1700BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
01BC170MEXAT	LSM170BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 170mm bore
01BC170MGRAT	LSM170BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 170mm bore
01BC1800EXLAB	LSE1800BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
01BC1800GRLAB	LSE1800BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
01BC180MEXAT	LSM180BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 180mm bore
01BC180MGRAT	LSM180BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 180mm bore
01BC1900EXLAB	LSE1900BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 19 in. bore
01BC1900GRLAB	LSE1900BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 19 in. bore

Cooper Part Number	Timken Part Number	Timken Description
01BC190MEXAT	LSM190BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 190mm bore
01BC190MGRAT	LSM190BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 190mm bore
01BC2000EXLAB	LSE2000BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
01BC2000GRLAB	LSE2000BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
01BC200MEXAT	LSM200BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 200mm bore
01BC200MGRAT	LSM200BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 200mm bore
01BC2100EXLAB	LSE2100BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 21 in. bore
01BC2100GRLAB	LSE2100BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 21 in. bore
01BC2200EXLAB	LSE2200BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
01BC2200GRLAB	LSE2200BRHLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
01BC220MEXAT	LSM220BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 220mm bore
01BC220MGRAT	LSM220BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 220mm bore
01BC2300EXLAB	LSE2300BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
01BC2300GRLAB	LSE2300BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 23 in. bore
01BC2400EXLAB	LSE2400BXHLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 24 in. bore
01BC2400GRLAB	LSE2400BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 24 in. bore
01BC240MEXAT	LSM240BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 240mm bore
01BC240MGRAT	LSM240BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 240mm bore
01BC260MEXAT	LSM260BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 260mm bore
01BC260MGRAT	LSM260BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 260mm bore
01BC280MEXAT	LSM280BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 280mm bore
01BC280MGRAT	LSM280BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 280mm bore
01BC300MEXAT	LSM300BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 300mm bore
01BC300MGRAT	LSM300BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 300mm bore
01BC320MEXAT	LSM320BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 320mm bore
01BC320MEXLAB	LSM320BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
01BC320MGRAT	LSM320BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 320mm bore
01BC320MGRLAB	LSM320BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
01BC340MEXAT	LSM340BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 340mm bore
01BC340MEXLAB	LSM340BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
01BC340MGRAT	LSM340BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 340mm bore
01BC340MGRLAB	LSM340BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
01BC35MEXAT	LSM35BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 35mm bore
01BC35MGRAT	LSM35BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 35mm bore
01BC360MEXLAB	LSM360BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
01BC360MGRLAB	LSM360BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
01BC380MEXLAB	LSM380BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
01BC380MGRLAB	LSM380BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
01BC400MEXLAB	LSM400BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
01BC400MGRLAB	LSM400BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
01BC403EXAT	LSE403BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 3/16 in. bore
01BC403GRAT	LSE403BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 3/16 in. bore
01BC404EXAT	LSE404BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 1/4 in. bore
01BC407EXAT	LSE407BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 7/16 in. bore
01BC407GRAT	LSE407BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 7/16 in. bore
01BC408EXAT	LSE408BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 1/2 in. bore
01BC408GRAT	LSE408BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 1/2 in. bore

Cooper Part Number	Timken Part Number	Timken Description
01BC40MEXAT	LSM40BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 40mm bore
01BC40MGRAT	LSM40BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 40mm bore
01BC41EXAT	LSE411BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 1/16 in. bore
01BC411GRAT	LSE411BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 1/16 in. bore
01BC412EXAT	LSE412BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 3/16 in. bore
01BC412GRAT	LSE412BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 3/16 in. bore
01BC415EXAT	LSE415BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 1/4 in. bore
01BC415GRAT	LSE415BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 1/4 in. bore
01BC420MEXLAB	LSM420BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
01BC420MGRLAB	LSM420BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
01BC440MEXLAB	LSM440BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
01BC440MGRLAB	LSM440BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
01BC460MEXLAB	LSM460BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
01BC460MGRLAB	LSM460BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
01BC480MEXLAB	LSM480BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
01BC480MGRLAB	LSM480BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
01BC500EXAT	LSE500BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 in. bore
01BC500GRAT	LSE500BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 in. bore
01BC500MEXLAB	LSM500BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
01BC500MGRLAB	LSM500BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
01BC503EXAT	LSE503BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 3/16 in. bore
01BC503GRAT	LSE503BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 3/16 in. bore
01BC504EXAT	LSE504BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 1/4 in. bore
01BC504GRAT	LSE504BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 1/4 in. bore
01BC507EXAT	LSE507BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 7/16 in. bore
01BC507GRAT	LSE507BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 7/16 in. bore
01BC508EXAT	LSE508BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 1/2 in. bore
01BC508GRAT	LSE508BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 1/2 in. bore
01BC512EXAT	LSE512BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 3/4 in. bore
01BC512GRAT	LSE512BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 3/4 in. bore
01BC515EXAT	LSE515BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 15/16 in. bore
01BC515GRAT	LSE515BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 15/16 in. bore
01BC530MEXLAB	LSM530BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
01BC530MGRLAB	LSM530BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
01BC560MEXLAB	LSM560BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
01BC560MGRLAB	LSM560BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
01BC600EXAT	LSE600BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 in. bore
01BC600GRAT	LSE600BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 in. bore
01BC600MEXLAB	LSM600BXHLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
01BC600MGRLAB	LSM600BRHLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
01BC607EXAT	LSE607BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
01BC607GRAT	LSE607BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
01BC608EXAT	LSE608BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
01BC608GRAT	LSE608BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
01BC615EXAT	LSE615BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
01BC615GRAT	LSE615BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
01BC700EXAT	LSE700BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01BC700GRAT	LSE700BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 in. bore
01BC708EXAT	LSE708BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 ½ in. bore
01BC708GRAT	LSE708BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 ½ in. bore
01BC715EXAT	LSE715BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 ⅞ in. bore
01BC715GRAT	LSE715BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 ⅞ in. bore
01BC800EXAT	LSE800BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 8 in. bore
01BC800GRAT	LSE800BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 8 in. bore
01BC900EXAT	LSE900BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 in. bore
01BC900GRAT	LSE900BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 9 in. bore
01BC908EXAT	LSE908BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 ½ in. bore
01BCF1000EXAT	LSE1000BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
01BCF1000GRAT	LSE1000BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
01BCF103EXAT	LSE103BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 ⅜ in. bore
01BCF103GRAT	LSE103BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 ⅜ in. bore
01BCF104EXAT	LSE104BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 ¼ in. bore
01BCF104GRAT	LSE104BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 ¼ in. bore
01BCF107EXAT	LSE107BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 ⅞ in. bore
01BCF107GRAT	LSE107BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 ⅞ in. bore
01BCF108EXAT	LSE108BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 ½ in. bore
01BCF108GRAT	LSE108BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 ½ in. bore
01BCF1100EXAT	LSE1100BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
01BCF1100GRAT	LSE1100BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
01BCF110MEXAT	LSM110BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 110mm bore
01BCF110MGRAT	LSM110BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 110mm bore
01BCF115MEXAT	LSM115BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 115mm bore
01BCF115MGRAT	LSM115BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 115mm bore
01BCF1200EXAT	LSE1200BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
01BCF1200GRAT	LSE1200BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
01BCF120MEXAT	LSM120BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 120mm bore
01BCF120MGRAT	LSM120BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 120mm bore
01BCF125MEXAT	LSM125BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 125mm bore
01BCF125MGRAT	LSM125BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 125mm bore
01BCF130MEXAT	LSM130BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 130mm bore
01BCF130MGRAT	LSM130BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 130mm bore
01BCF135MEXAT	LSM135BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 135mm bore
01BCF135MGRAT	LSM135BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 135mm bore
01BCF140MEXAT	LSM140BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 140mm bore
01BCF140MGRAT	LSM140BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 140mm bore
01BCF150MEXAT	LSM150BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 150mm bore
01BCF150MGRAT	LSM150BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 150mm bore
01BCF155MEXAT	LSM155BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 155mm bore
01BCF155MGRAT	LSM155BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 155mm bore
01BCF160MEXAT	LSM160BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
01BCF160MGRAT	LSM160BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
01BCF170MEXAT	LSM170BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
01BCF170MGRAT	LSM170BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
01BCF180MEXAT	LSM180BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore

Cooper Part Number	Timken Part Number	Timken Description
01BCF180MGRAT	LSM180BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
01BCF190MEXAT	LSM190BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
01BCF190MGRAT	LSM190BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
01BCF200MEXAT	LSM200BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
01BCF200MGRAT	LSM200BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
01BCF220MEXAT	LSM220BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
01BCF220MGRAT	LSM220BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
01BCF240MEXAT	LSM240BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
01BCF240MGRAT	LSM240BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
01BCF260MEXAT	LSM260BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
01BCF260MGRAT	LSM260BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
01BCF280MEXAT	LSM280BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
01BCF280MGRAT	LSM280BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
01BCF300MEXAT	LSM300BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
01BCF300MGRAT	LSM300BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
01BCF35MEXAT	LSM35BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 35mm bore
01BCF35MGRAT	LSM35BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 35mm bore
01BCF403EXAT	LSE403BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 ³ / ₁₆ in. bore
01BCF403GRAT	LSE403BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 ³ / ₁₆ in. bore
01BCF404EXAT	LSE404BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 ¹ / ₄ in. bore
01BCF404GRAT	LSE404BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 ¹ / ₄ in. bore
01BCF407EXAT	LSE407BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 ⁷ / ₁₆ in. bore
01BCF407GRAT	LSE407BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 ⁷ / ₁₆ in. bore
01BCF408EXAT	LSE408BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 ¹ / ₂ in. bore
01BCF408GRAT	LSE408BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 ¹ / ₂ in. bore
01BCF40MEXAT	LSM40BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 40mm bore
01BCF40MGRAT	LSM40BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 40mm bore
01BCF415EXAT	LSE415BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 ¹⁵ / ₁₆ in. bore
01BCF415GRAT	LSE415BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 ¹⁵ / ₁₆ in. bore
01BCF500EXAT	LSE500BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 in. bore
01BCF500GRAT	LSE500BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 in. bore
01BCF503EXAT	LSE503BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 ³ / ₁₆ in. bore
01BCF503GRAT	LSE503BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 ³ / ₁₆ in. bore
01BCF507EXAT	LSE507BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 ⁷ / ₁₆ in. bore
01BCF507GRAT	LSE507BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 ⁷ / ₁₆ in. bore
01BCF508EXAT	LSE508BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 ¹ / ₂ in. bore
01BCF508GRAT	LSE508BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 ¹ / ₂ in. bore
01BCF515EXAT	LSE515BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 ¹⁵ / ₁₆ in. bore
01BCF515GRAT	LSE515BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 ¹⁵ / ₁₆ in. bore
01BCF600EXAT	LSE600BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 in. bore
01BCF600GRAT	LSE600BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 in. bore
01BCF607EXAT	LSE607BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 ⁷ / ₁₆ in. bore
01BCF607GRAT	LSE607BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 ⁷ / ₁₆ in. bore
01BCF608EXAT	LSE608BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 ¹ / ₂ in. bore
01BCF608GRAT	LSE608BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 ¹ / ₂ in. bore
01BCF615EXAT	LSE615BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 ¹⁵ / ₁₆ in. bore
01BCF615GRAT	LSE615BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 ¹⁵ / ₁₆ in. bore

Cooper Part Number	Timken Part Number	Timken Description
01BCF700EXAT	LSE700BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
01BCF700GRAT	LSE700BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
01BCF715EXAT	LSE715BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 1/16 in. bore
01BCF715GRAT	LSE715BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 1/16 in. bore
01BCF800EXAT	LSE800BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
01BCF800GRAT	LSE800BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
01BCF900EXAT	LSE900BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
01BCF900GRAT	LSE900BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
01BCP1000EXAT	LSE1000BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
01BCP1000GRAT	LSE1000BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
01BCP103EXAT	LSE103BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 3/16 in. bore
01BCP103GRAT	LSE103BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 3/16 in. bore
01BCP104EXAT	LSE104BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 1/4 in. bore
01BCP104GRAT	LSE104BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 1/4 in. bore
01BCP107EXAT	LSE107BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 7/16 in. bore
01BCP107GRAT	LSE107BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 7/16 in. bore
01BCP108EXAT	LSE108BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 1/2 in. bore
01BCP108GRAT	LSE108BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 1/2 in. bore
01BCP1100EXAT	LSE1100BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
01BCP1100GRAT	LSE1100BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
01BCP110MEXAT	LSM110BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 110mm bore
01BCP110MGRAT	LSM110BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 110mm bore
01BCP115MEXAT	LSM115BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 115mm bore
01BCP115MEXAT	LSM115BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 115mm bore
01BCP115MGRAT	LSM115BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 115mm bore
01BCP115MGRAT	LSM115BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 115mm bore
01BCP1200EXAT	LSE1200BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
01BCP1200GRAT	LSE1200BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
01BCP120MEXAT	LSM120BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 120mm bore
01BCP120MGRAT	LSM120BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 120mm bore
01BCP125MEXAT	LSM125BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 125mm bore
01BCP125MGRAT	LSM125BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 125mm bore
01BCP1300EXAT	LSE1300BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 13 in. bore
01BCP1300EXLAB	LSE1300BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
01BCP1300GRAT	LSE1300BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 13 in. bore
01BCP1300GRLAB	LSE1300BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
01BCP130MEXAT	LSM130BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 130mm bore
01BCP130MGRAT	LSM130BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 130mm bore
01BCP135MEXAT	LSM135BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 135mm bore
01BCP135MGRAT	LSM135BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 135mm bore
01BCP1400EXAT	LSE1400BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 14 in. bore
01BCP1400EXLAB	LSE1400BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
01BCP1400GRAT	LSE1400BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 14 in. bore
01BCP1400GRLAB	LSE1400BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
01BCP140MEXAT	LSM140BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 140mm bore
01BCP140MGRAT	LSM140BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 140mm bore
01BCP1500EXLAB	LSE1500BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01BCP1500GRLAB	LSE1500BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
01BCP150MEXAT	LSM150BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 150mm bore
01BCP150MGRAT	LSM150BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 150mm bore
01BCP155MEXAT	LSM155BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 155mm bore
01BCP155MGRAT	LSM155BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 155mm bore
01BCP1600EXLAB	LSE1600BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 16 in. bore
01BCP1600GRLAB	LSE1600BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 16 in. bore
01BCP160MEXAT	LSM160BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
01BCP160MGRAT	LSM160BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
01BCP1700EXLAB	LSE1700BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
01BCP1700GRLAB	LSE1700BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
01BCP170MEXAT	LSM170BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
01BCP170MGRAT	LSM170BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
01BCP1800EXLAB	LSE1800BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
01BCP1800GRLAB	LSE1800BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 18 in. bore
01BCP180MEXAT	LSM180BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
01BCP180MGRAT	LSM180BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
01BCP1900EXLAB	LSE1900BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 19 in. bore
01BCP1900GRLAB	LSE1900BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 19 in. bore
01BCP190MEXAT	LSM190BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
01BCP190MGRAT	LSM190BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
01BCP2000EXLAB	LSE2000BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
01BCP2000GRLAB	LSE2000BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
01BCP200MEXAT	LSM200BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
01BCP200MGRAT	LSM200BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
01BCP2100EXLAB	LSE2100BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 21 in. bore
01BCP2100GRLAB	LSE2100BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 21 in. bore
01BCP2200EXLAB	LSE2200BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
01BCP2200GRLAB	LSE2200BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
01BCP220MEXAT	LSM220BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 220mm bore
01BCP220MGRAT	LSM220BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 220mm bore
01BCP2300EXLAB	LSE2300BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
01BCP2300GRLAB	LSE2300BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
01BCP2400EXLAB	LSE2400BXHSLAB	Light Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 24 in. bore
01BCP2400GRLAB	LSE2400BRHSLAB	Light Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 24 in. bore
01BCP240MEXAT	LSM240BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 240mm bore
01BCP240MGRAT	LSM240BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 240mm bore
01BCP260MEXAT	LSM260BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 260mm bore
01BCP260MGRAT	LSM260BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 260mm bore
01BCP280MEXAT	LSM280BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 280mm bore
01BCP280MGRAT	LSM280BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 280mm bore
01BCP300MEXAT	LSM300BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 300mm bore
01BCP300MGRAT	LSM300BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 300mm bore
01BCP30MEXAT	LSM30BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 30mm bore
01BCP30MGRAT	LSM30BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 30mm bore
01BCP320MEXLAB	LSM320BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
01BCP320MGRLAB	LSM320BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01BCP340MEXLAB	LSM340BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
01BCP340MGRLAB	LSM340BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
01BCP35MEXAT	LSM35BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 35mm bore
01BCP35MGRAT	LSM35BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 35mm bore
01BCP360MEXLAB	LSM360BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
01BCP360MGRLAB	LSM360BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
01BCP380MEXLAB	LSM380BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
01BCP380MGRLAB	LSM380BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
01BCP400MEXLAB	LSM400BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
01BCP400MGRLAB	LSM400BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
01BCP403EXAT	LSE403BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 3/16 in. bore
01BCP403EXAT	LSE403BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 3/16 in. bore
01BCP403GRAT	LSE403BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 3/16 in. bore
01BCP403GRAT	LSE403BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 3/16 in. bore
01BCP404EXAT	LSE404BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 1/4 in. bore
01BCP404GRAT	LSE404BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 1/4 in. bore
01BCP407EXAT	LSE407BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 7/16 in. bore
01BCP407GRAT	LSE407BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 7/16 in. bore
01BCP408EXAT	LSE408BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 1/2 in. bore
01BCP408EXAT	LSE408BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 1/2 in. bore
01BCP408GRAT	LSE408BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 1/2 in. bore
01BCP408GRAT	LSE408BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 1/2 in. bore
01BCP40MEXAT	LSM40BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 40mm bore
01BCP40MGRAT	LSM40BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 40mm bore
01BCP411EXAT	LSE411BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 1/16 in. bore
01BCP411GRAT	LSE411BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 1/16 in. bore
01BCP412EXAT	LSE412BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 3/8 in. bore
01BCP412GRAT	LSE412BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 3/8 in. bore
01BCP415EXAT	LSE415BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 15/16 in. bore
01BCP415GRAT	LSE415BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 15/16 in. bore
01BCP420MEXLAB	LSM420BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
01BCP420MGRLAB	LSM420BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
01BCP440MEXLAB	LSM440BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
01BCP440MGRLAB	LSM440BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
01BCP460MEXLAB	LSM460BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
01BCP460MGRLAB	LSM460BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
01BCP480MEXLAB	LSM480BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
01BCP480MGRLAB	LSM480BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
01BCP500EXAT	LSE500BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 in. bore
01BCP500GRAT	LSE500BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 in. bore
01BCP500MEXLAB	LSM500BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
01BCP500MGRLAB	LSM500BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
01BCP503EXAT	LSE503BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 3/16 in. bore
01BCP503GRAT	LSE503BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 3/16 in. bore
01BCP504EXAT	LSE504BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 1/4 in. bore
01BCP504GRAT	LSE504BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 1/4 in. bore
01BCP507EXAT	LSE507BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 7/16 in. bore
01BCP507GRAT	LSE507BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 7/16 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01BCP508EXAT	LSE508BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 1/2 in. bore
01BCP508GRAT	LSE508BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 1/2 in. bore
01BCP512EXAT	LSE512BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 3/4 in. bore
01BCP512GRAT	LSE512BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 3/4 in. bore
01BCP515EXAT	LSE515BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 15/16 in. bore
01BCP515GRAT	LSE515BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 15/16 in. bore
01BCP530MEXLAB	LSM530BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
01BCP530MGRLAB	LSM530BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
01BCP560MEXLAB	LSM560BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
01BCP560MGRLAB	LSM560BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
01BCP600EXAT	LSE600BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 in. bore
01BCP600GRAT	LSE600BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 in. bore
01BCP600MEXLAB	LSM600BXHSLAB	Light Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
01BCP600MGRLAB	LSM600BRHSLAB	Light Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
01BCP607EXAT	LSE607BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
01BCP607GRAT	LSE607BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
01BCP608EXAT	LSE608BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore
01BCP608GRAT	LSE608BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore
01BCP615EXAT	LSE615BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 15/16 in. bore
01BCP615GRAT	LSE615BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 15/16 in. bore
01BCP700EXAT	LSE700BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
01BCP700GRAT	LSE700BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
01BCP708EXAT	LSE708BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 1/2 in. bore
01BCP708GRAT	LSE708BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 1/2 in. bore
01BCP715EXAT	LSE715BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 15/16 in. bore
01BCP715GRAT	LSE715BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 15/16 in. bore
01BCP800EXAT	LSE800BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
01BCP800GRAT	LSE800BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
01BCP900EXAT	LSE900BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
01BCP900GRAT	LSE900BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
01BCP908EXAT	LSE908BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 1/2 in. bore
01BCSAFC522404EXAT	LSE404BXHSAFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 1/4 in. bore
01BCSAFC522404GRAT	LSE404BRHSAFQAATL	Light Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 1/4 in. bore
01BCSAFC526500EXAT	LSE500BXHSAFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 in. bore
01BCSAFC526500GRAT	LSE500BRHSAFQAATL	Light Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 in. bore
01BCSNC524110MEXAT	LSM110BXHSNQATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 110mm bore
01BCSNC524110MGRAT	LSM110BRHSNQATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 110mm bore
01BCSNC524403EXAT	LSE403BXHSNQATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 3/8 in. bore
01BCSNC524403GRAT	LSE403BRHSNQATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 3/8 in. bore
01BCSNC526115MEXAT	LSM115BXHSNQATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 115mm bore
01BCSNC526115MGRAT	LSM115BRHSNQATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 115mm bore
01BCSNC526407EXAT	LSE407BXHSNQATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 7/16 in. bore
01BCSNC526407GRAT	LSE407BRHSNQATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 7/16 in. bore
01BCSNC526408EXAT	LSE408BXHSNQATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 1/2 in. bore
01BCSNC526408GRAT	LSE408BRHSNQATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 1/2 in. bore
01BCSNC528120MEXAT	LSM120BXHSNQATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 120mm bore
01BCSNC528120MGRAT	LSM120BRHSNQATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 120mm bore

Cooper Part Number	Timken Part Number	Timken Description
01BCSNC528125MEXAT	LSM125BXHSNQATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 125mm bore
01BCSNC528125MGRAT	LSM125BRHSNQATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 125mm bore
01BCSNC528415EXAT	LSE415BXHSNQATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 1/8 in. bore
01BCSNC528415GRAT	LSE415BRHSNQATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 1/8 in. bore
01BCSNC528500EXAT	LSE500BXHSNQATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 in. bore
01BCSNC528500GRAT	LSE500BRHSNQATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 in. bore
01BCSNC530135MEXAT	LSM135BXHSNQATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 135mm bore
01BCSNC530135MGRAT	LSM135BRHSNQATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 135mm bore
01BCSNC530503EXAT	LSE503BXHSNQATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 3/8 in. bore
01BCSNC530503GRAT	LSE503BRHSNQATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 3/8 in. bore
01BCSNC532140MEXAT	LSM140BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 140mm bore
01BCSNC532140MGRAT	LSM140BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 140mm bore
01BCSNC532507EXAT	LSE507BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 7/8 in. bore
01BCSNC532507GRAT	LSE507BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 7/8 in. bore
01BCSNC532508EXAT	LSE508BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 1/2 in. bore
01BCSNC532508GRAT	LSE508BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 5 1/2 in. bore
01C10EX	LS10HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C10GR	LS10HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C11GR	LS11HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C12GR	LS12HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1300GR	LSE1300HR	Light Series Imperial Retained Housing: 13 in. bore
01C13GR	LS13HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1400GR	LSE1400HR	Light Series Imperial Retained Housing: 14 in. bore
01C14GR	LS14HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1500GR	LSE1500HR	Light Series Imperial Retained Housing: 15 in. bore
01C15GR	LS15HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1600GR	LSE1600HR	Light Series Imperial Retained Housing: 16 in. bore
01C16GR	LS16HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1700GR	LSE1700HR	Light Series Imperial Retained Housing: 17 in. bore
01C17GR	LS17HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1800GR	LSE1800HR	Light Series Imperial Retained Housing: 18 in. bore
01C18GR	LS18HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1900GR	LSE1900HR	Light Series Imperial Retained Housing: 19 in. bore
01C19GR	LS19HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C1EX	LS1HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C1GR	LS1HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C2000GR	LSE2000HR	Light Series Imperial Retained Housing: 20 in. bore
01C2100GR	LSE2100HR	Light Series Imperial Retained Housing: 21 in. bore
01C2200GR	LSE2200HR	Light Series Imperial Retained Housing: 22 in. bore
01C2300GR	LSE2300HR	Light Series Imperial Retained Housing: 23 in. bore
01C2400GR	LSE2400HR	Light Series Imperial Retained Housing: 24 in. bore
01C2EX	LS2HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C2GR	LS2HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C320MGR	LSM320HR	Light Series Metric Retained Housing: 320mm bore
01C340MGR	LSM340HR	Light Series Metric Retained Housing: 340mm bore
01C360MGR	LSM360HR	Light Series Metric Retained Housing: 360mm bore
01C380MGR	LSM380HR	Light Series Metric Retained Housing: 380mm bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01C3EX	LS3HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C3GR	LS3HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C400MGR	LSM400HR	Light Series Metric Retained Housing: 400mm bore
01C420MGR	LSM420HR	Light Series Metric Retained Housing: 420mm bore
01C440MGR	LSM440HR	Light Series Metric Retained Housing: 440mm bore
01C460MGR	LSM460HR	Light Series Metric Retained Housing: 460mm bore
01C480MGR	LSM480HR	Light Series Metric Retained Housing: 480mm bore
01C4EX	LS4HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C4GR	LS4HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C500MGR	LSM500HR	Light Series Metric Retained Housing: 500mm bore
01C530MGR	LSM530HR	Light Series Metric Retained Housing: 530mm bore
01C560MGR	LSM560HR	Light Series Metric Retained Housing: 560mm bore
01C5EX	LS5HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C5GR	LS5HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C600MGR	LSM600HR	Light Series Metric Retained Housing: 600mm bore
01C6EX	LS6HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C6GR	LS6HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C7EX	LS7HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C7GR	LS7HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C8EX	LS8HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C8GR	LS8HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01C9EX	LS9HXTL	Light Series Housing configured for a Expansion Bearing and ATL Seals
01C9GR	LS9HRTL	Light Series Housing configured for a Retained Bearing and ATL Seals
01EB1000EX	LSE1000BX	Light Series Imperial Expansion Bearing: 10 in. bore
01EB1000GR	LSE1000BR	Light Series Imperial Retained Bearing: 10 in. bore
01EB100MEX	LSM100BX	Light Series Metric Expansion Bearing: 100mm bore
01EB100MGR	LSM100BR	Light Series Metric Retained Bearing: 100mm bore
01EB105MEX	LSM105BX	Light Series Metric Expansion Bearing: 105mm bore
01EB105MGR	LSM105BR	Light Series Metric Retained Bearing: 105mm bore
01EB1100EX	LSE1100BX	Light Series Imperial Expansion Bearing: 11 in. bore
01EB1100GR	LSE1100BR	Light Series Imperial Retained Bearing: 11 in. bore
01EB111EX	LSE111BX	Light Series Imperial Expansion Bearing: 1 1/8 in. bore
01EB111GR	LSE111BR	Light Series Imperial Retained Bearing: 1 1/8 in. bore
01EB112EX	LSE112BX	Light Series Imperial Expansion Bearing: 1 1/4 in. bore
01EB112GR	LSE112BR	Light Series Imperial Retained Bearing: 1 1/4 in. bore
01EB115EX	LSE115BX	Light Series Imperial Expansion Bearing: 1 3/8 in. bore
01EB115GR	LSE115BR	Light Series Imperial Retained Bearing: 1 3/8 in. bore
01EB1200EX	LSE1200BX	Light Series Imperial Expansion Bearing: 12 in. bore
01EB1200GR	LSE1200BR	Light Series Imperial Retained Bearing: 12 in. bore
01EB160MEX	LSM160BX	Light Series Metric Expansion Bearing: 160mm bore
01EB160MGR	LSM160BR	Light Series Metric Retained Bearing: 160mm bore
01EB170MEX	LSM170BX	Light Series Metric Expansion Bearing: 170mm bore
01EB170MGR	LSM170BR	Light Series Metric Retained Bearing: 170mm bore
01EB180MEX	LSM180BX	Light Series Metric Expansion Bearing: 180mm bore
01EB180MGR	LSM180BR	Light Series Metric Retained Bearing: 180mm bore
01EB190MEX	LSM190BX	Light Series Metric Expansion Bearing: 190mm bore
01EB190MGR	LSM190BR	Light Series Metric Retained Bearing: 190mm bore

Cooper Part Number	Timken Part Number	Timken Description
01EB200EX	LSE200BX	Light Series Imperial Expansion Bearing: 2 in. bore
01EB200GR	LSE200BR	Light Series Imperial Retained Bearing: 2 in. bore
01EB200MEX	LSM200BX	Light Series Metric Expansion Bearing: 200mm bore
01EB200MGR	LSM200BR	Light Series Metric Retained Bearing: 200mm bore
01EB203EX	LSE203BX	Light Series Imperial Expansion Bearing: 2 3/16 in. bore
01EB203GR	LSE203BR	Light Series Imperial Retained Bearing: 2 3/16 in. bore
01EB204EX	LSE204BX	Light Series Imperial Expansion Bearing: 2 1/4 in. bore
01EB204GR	LSE204BR	Light Series Imperial Retained Bearing: 2 1/4 in. bore
01EB207EX	LSE207BX	Light Series Imperial Expansion Bearing: 2 7/16 in. bore
01EB207GR	LSE207BR	Light Series Imperial Retained Bearing: 2 7/16 in. bore
01EB208EX	LSE208BX	Light Series Imperial Expansion Bearing: 2 1/2 in. bore
01EB208GR	LSE208BR	Light Series Imperial Retained Bearing: 2 1/2 in. bore
01EB211EX	LSE211BX	Light Series Imperial Expansion Bearing: 2 1/8 in. bore
01EB211GR	LSE211BR	Light Series Imperial Retained Bearing: 2 1/8 in. bore
01EB212EX	LSE212BX	Light Series Imperial Expansion Bearing: 2 1/8 in. bore
01EB212GR	LSE212BR	Light Series Imperial Retained Bearing: 2 1/8 in. bore
01EB215EX	LSE215BX	Light Series Imperial Expansion Bearing: 2 5/16 in. bore
01EB215GR	LSE215BR	Light Series Imperial Retained Bearing: 2 5/16 in. bore
01EB220MEX	LSM220BX	Light Series Metric Expansion Bearing: 220mm bore
01EB220MGR	LSM220BR	Light Series Metric Retained Bearing: 220mm bore
01EB240MEX	LSM240BX	Light Series Metric Expansion Bearing: 240mm bore
01EB240MGR	LSM240BR	Light Series Metric Retained Bearing: 240mm bore
01EB260MEX	LSM260BX	Light Series Metric Expansion Bearing: 260mm bore
01EB260MGR	LSM260BR	Light Series Metric Retained Bearing: 260mm bore
01EB280MEX	LSM280BX	Light Series Metric Expansion Bearing: 280mm bore
01EB280MGR	LSM280BR	Light Series Metric Retained Bearing: 280mm bore
01EB300EX	LSE300BX	Light Series Imperial Expansion Bearing: 3 in. bore
01EB300GR	LSE300BR	Light Series Imperial Retained Bearing: 3 in. bore
01EB300MEX	LSM300BX	Light Series Metric Expansion Bearing: 300mm bore
01EB300MGR	LSM300BR	Light Series Metric Retained Bearing: 300mm bore
01EB303EX	LSE303BX	Light Series Imperial Expansion Bearing: 3 3/16 in. bore
01EB303GR	LSE303BR	Light Series Imperial Retained Bearing: 3 3/16 in. bore
01EB304EX	LSE304BX	Light Series Imperial Expansion Bearing: 3 1/4 in. bore
01EB304GR	LSE304BR	Light Series Imperial Retained Bearing: 3 1/4 in. bore
01EB307EX	LSE307BX	Light Series Imperial Expansion Bearing: 3 7/16 in. bore
01EB307GR	LSE307BR	Light Series Imperial Retained Bearing: 3 7/16 in. bore
01EB308EX	LSE308BX	Light Series Imperial Expansion Bearing: 3 1/2 in. bore
01EB308GR	LSE308BR	Light Series Imperial Retained Bearing: 3 1/2 in. bore
01EB311EX	LSE311BX	Light Series Imperial Expansion Bearing: 3 11/16 in. bore
01EB311EX	LSE311BX	Light Series Imperial Expansion Bearing: 3 11/16 in. bore
01EB311GR	LSE311BR	Light Series Imperial Retained Bearing: 3 11/16 in. bore
01EB311GR	LSE311BR	Light Series Imperial Retained Bearing: 3 11/16 in. bore
01EB312EX	LSE312BX	Light Series Imperial Expansion Bearing: 3 1/2 in. bore
01EB312GR	LSE312BR	Light Series Imperial Retained Bearing: 3 1/2 in. bore
01EB315EX	LSE315BX	Light Series Imperial Expansion Bearing: 3 5/16 in. bore
01EB315GR	LSE315BR	Light Series Imperial Retained Bearing: 3 5/16 in. bore
01EB400EX	LSE400BX	Light Series Imperial Expansion Bearing: 4 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EB400GR	LSE400BR	Light Series Imperial Retained Bearing: 4 in. bore
01EB45MEX	LSM45BX	Light Series Metric Expansion Bearing: 45mm bore
01EB45MGR	LSM45BR	Light Series Metric Retained Bearing: 45mm bore
01EB50MEX	LSM50BX	Light Series Metric Expansion Bearing: 50mm bore
01EB50MGR	LSM50BR	Light Series Metric Retained Bearing: 50mm bore
01EB607EX	LSE607BX	Light Series Imperial Expansion Bearing: 6 ⁷ / ₁₆ in. bore
01EB607GR	LSE607BR	Light Series Imperial Retained Bearing: 6 ⁷ / ₁₆ in. bore
01EB608EX	LSE608BX	Light Series Imperial Expansion Bearing: 6 ¹ / ₂ in. bore
01EB608GR	LSE608BR	Light Series Imperial Retained Bearing: 6 ¹ / ₂ in. bore
01EB60MEX	LSM60BX	Light Series Metric Expansion Bearing: 60mm bore
01EB60MGR	LSM60BR	Light Series Metric Retained Bearing: 60mm bore
01EB615EX	LSE615BX	Light Series Imperial Expansion Bearing: 6 ¹⁵ / ₁₆ in. bore
01EB615GR	LSE615BR	Light Series Imperial Retained Bearing: 6 ¹⁵ / ₁₆ in. bore
01EB65MEX	LSM65BX	Light Series Metric Expansion Bearing: 65mm bore
01EB65MGR	LSM65BR	Light Series Metric Retained Bearing: 65mm bore
01EB700EX	LSE700BX	Light Series Imperial Expansion Bearing: 7 in. bore
01EB700GR	LSE700BR	Light Series Imperial Retained Bearing: 7 in. bore
01EB708EX	LSE708BX	Light Series Imperial Expansion Bearing: 7 ¹ / ₂ in. bore
01EB708GR	LSE708BR	Light Series Imperial Retained Bearing: 7 ¹ / ₂ in. bore
01EB70MEX	LSM70BX	Light Series Metric Expansion Bearing: 70mm bore
01EB70MGR	LSM70BR	Light Series Metric Retained Bearing: 70mm bore
01EB715EX	LSE715BX	Light Series Imperial Expansion Bearing: 7 ¹⁵ / ₁₆ in. bore
01EB715GR	LSE715BR	Light Series Imperial Retained Bearing: 7 ¹⁵ / ₁₆ in. bore
01EB75MEX	LSM75BX	Light Series Metric Expansion Bearing: 75mm bore
01EB75MGR	LSM75BR	Light Series Metric Retained Bearing: 75mm bore
01EB800EX	LSE800BX	Light Series Imperial Expansion Bearing: 8 in. bore
01EB800GR	LSE800BR	Light Series Imperial Retained Bearing: 8 in. bore
01EB80MEX	LSM80BX	Light Series Metric Expansion Bearing: 80mm bore
01EB80MGR	LSM80BR	Light Series Metric Retained Bearing: 80mm bore
01EB85MEX	LSM85BX	Light Series Metric Expansion Bearing: 85mm bore
01EB85MGR	LSM85BR	Light Series Metric Retained Bearing: 85mm bore
01EB900EX	LSE900BX	Light Series Imperial Expansion Bearing: 9 in. bore
01EB900GR	LSE900BR	Light Series Imperial Retained Bearing: 9 in. bore
01EB90MEX	LSM90BX	Light Series Metric Expansion Bearing: 90mm bore
01EB90MGR	LSM90BR	Light Series Metric Retained Bearing: 90mm bore
01EBC1000EXAT	LSE1000BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 10 in. bore
01EBC1000GRAT	LSE1000BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 10 in. Bore
01EBC100MEXAT	LSM100BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 100mm bore
01EBC100MGRAT	LSM100BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 100mm bore
01EBC105MEXAT	LSM105BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 105mm bore
01EBC105MGRAT	LSM105BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 105mm bore
01EBC1100EXAT	LSE1100BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 11 in. bore
01EBC1100GRAT	LSE1100BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 11 in. bore
01EBC111EXAT	LSE111BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 ¹¹ / ₁₆ in. bore
01EBC111GRAT	LSE111BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 ¹¹ / ₁₆ in. bore
01EBC112EXAT	LSE112BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 ³ / ₄ in. bore
01EBC112GRAT	LSE112BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 ³ / ₄ in. Bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EBC115EXAT	LSE115BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 1⁄16 in. bore
01EBC115GRAT	LSE115BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 1⁄16 in. bore
01EBC1200EXAT	LSE1200BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 12 in. bore
01EBC1200GRAT	LSE1200BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 12 in. bore
01EBC160MEXAT	LSM160BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 160mm bore
01EBC160MGRAT	LSM160BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 160mm bore
01EBC170MEXAT	LSM170BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 170mm bore
01EBC170MGRAT	LSM170BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 170mm bore
01EBC180MEXAT	LSM180BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 180mm bore
01EBC180MGRAT	LSM180BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 180mm bore
01EBC190MEXAT	LSM190BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 190mm bore
01EBC190MGRAT	LSM190BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 190mm bore
01EBC200EXAT	LSE200BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 in. bore
01EBC200GRAT	LSE200BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 in. bore
01EBC200MEXAT	LSM200BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 200mm bore
01EBC200MGRAT	LSM200BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 200mm bore
01EBC203EXAT	LSE203BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 3⁄16 in. bore
01EBC203GRAT	LSE203BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 3⁄16 in. bore
01EBC204EXAT	LSE204BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 1⁄4 in. bore
01EBC204GRAT	LSE204BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 1⁄4 in. bore
01EBC207EXAT	LSE207BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 7⁄16 in. bore
01EBC207GRAT	LSE207BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 7⁄16 in. bore
01EBC208EXAT	LSE208BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 1⁄2 in. bore
01EBC208GRAT	LSE208BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 1⁄2 in. bore
01EBC211EXAT	LSE211BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 11⁄16 in. bore
01EBC211GRAT	LSE211BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 11⁄16 in. bore
01EBC212EXAT	LSE212BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 3⁄4 in. bore
01EBC212GRAT	LSE212BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 3⁄4 in. bore
01EBC215EXAT	LSE215BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 15⁄16 in. bore
01EBC215GRAT	LSE215BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 15⁄16 in. bore
01EBC220MEXAT	LSM220BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 220mm bore
01EBC220MGRAT	LSM220BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 220mm bore
01EBC240MEXAT	LSM240BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 240mm bore
01EBC240MGRAT	LSM240BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 240mm bore
01EBC260MEXAT	LSM260BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 260mm bore
01EBC260MGRAT	LSM260BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 260mm bore
01EBC280MEXAT	LSM280BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 280mm bore
01EBC280MGRAT	LSM280BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 280mm bore
01EBC300EXAT	LSE300BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 in. bore
01EBC300GRAT	LSE300BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 in. bore
01EBC300MEXAT	LSM300BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 300mm bore
01EBC300MGRAT	LSM300BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 300mm bore
01EBC303EXAT	LSE303BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 3⁄16 in. bore
01EBC303GRAT	LSE303BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 3⁄16 in. bore
01EBC304EXAT	LSE304BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 1⁄4 in. bore
01EBC304GRAT	LSE304BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 1⁄4 in. bore
01EBC307EXAT	LSE307BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 7⁄16 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EBC307GRAT	LSE307BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 7/16 in. bore
01EBC308EXAT	LSE308BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 1/2 in. bore
01EBC308GRAT	LSE308BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 1/2 in. bore
01EBC311EXAT	LSE311BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 11/16 in. bore
01EBC311GRAT	LSE311BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 11/16 in. bore
01EBC312EXAT	LSE312BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 3/4 in. bore
01EBC312GRAT	LSE312BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 3/4 in. bore
01EBC315EXAT	LSE315BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 15/16 in. bore
01EBC315GRAT	LSE315BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 15/16 in. bore
01EBC400EXAT	LSE400BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 in. bore
01EBC400GRAT	LSE400BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 in. bore
01EBC45MEXAT	LSM45BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 45mm bore
01EBC45MGRAT	LSM45BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 45mm bore
01EBC50MEXAT	LSM50BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 50mm bore
01EBC50MGRAT	LSM50BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 50mm bore
01EBC55MEXAT	LSM55BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 55mm bore
01EBC55MGRAT	LSM55BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 55mm bore
01EBC607EXAT	LSE607BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
01EBC607GRAT	LSE607BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
01EBC608EXAT	LSE608BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
01EBC608GRAT	LSE608BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
01EBC60MEXAT	LSM60BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 60mm bore
01EBC60MGRAT	LSM60BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 60mm bore
01EBC615EXAT	LSE615BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
01EBC615GRAT	LSE615BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
01EBC65MEXAT	LSM65BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 65mm bore
01EBC65MGRAT	LSM65BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 65mm bore
01EBC700EXAT	LSE700BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 in. bore
01EBC700GRAT	LSE700BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 in. bore
01EBC708EXAT	LSE708BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 1/2 in. bore
01EBC708GRAT	LSE708BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 1/2 in. bore
01EBC70MEXAT	LSM70BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 70mm bore
01EBC70MGRAT	LSM70BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 70mm bore
01EBC715EXAT	LSE715BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
01EBC715GRAT	LSE715BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
01EBC75MEXAT	LSM75BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 75mm bore
01EBC75MGRAT	LSM75BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 75mm bore
01EBC800EXAT	LSE800BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 8 in. bore
01EBC800GRAT	LSE800BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 8 in. bore
01EBC80MEXAT	LSM80BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 80mm bore
01EBC80MGRAT	LSM80BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 80mm bore
01EBC85MEXAT	LSM85BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 85mm bore
01EBC85MGRAT	LSM85BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 85mm bore
01EBC900EXAT	LSE900BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 in. bore
01EBC900GRAT	LSE900BRHATL	Light Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 9 in. bore
01EBC908EXAT	LSE908BXHATL	Light Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 1/2 in. bore
01EBC90MEXAT	LSM90BXHATL	Light Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 90mm bore

Cooper Part Number	Timken Part Number	Timken Description
01EBC90MGRAT	LSM90BRHATL	Light Series Metric Retained Bearing with Housing Assembly and ATL Seals: 90mm bore
01EBCDF111EXAT	LSE111BXHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 9 in. bore
01EBCDF111GRAT	LSE111BRHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 9 in. bore
01EBCDF112EXAT	LSE112BXHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 9 1/2 in. bore
01EBCDF112GRAT	LSE112BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 10 in. bore
01EBCDF115EXAT	LSE115BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 10 in. bore
01EBCDF115GRAT	LSE115BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 1 3/16 in. bore
01EBCDF200EXAT	LSE200BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 1 3/16 in. bore
01EBCDF200GRAT	LSE200BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 1 1/4 in. bore
01EBCDF203EXAT	LSE203BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 1 1/4 in. bore
01EBCDF203GRAT	LSE203BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 1 7/16 in. bore
01EBCDF204EXAT	LSE204BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 1 7/16 in. bore
01EBCDF204GRAT	LSE204BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 1 1/2 in. bore
01EBCDF207EXAT	LSE207BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 1 1/2 in. bore
01EBCDF207GRAT	LSE207BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 11 in. bore
01EBCDF208EXAT	LSE208BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 11 in. bore
01EBCDF208GRAT	LSE208BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 110mm bore
01EBCDF211EXAT	LSE211BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 110mm bore
01EBCDF211GRAT	LSE211BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 115mm bore
01EBCDF212EXAT	LSE212BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 115mm bore
01EBCDF212GRAT	LSE212BRHDFATL	Light Series Imperial Expansion Bearing Square Flange Full Assembly with ATL Seals: 12 in. bore
01EBCDF215EXAT	LSE215BXHDFATL	Light Series Imperial Retained Bearing Square Flange Full Assembly with ATL Seals: 12 in. bore
01EBCDF215GRAT	LSE215BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 120mm bore
01EBCDF300EXAT	LSE300BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 120mm bore
01EBCDF300GRAT	LSE300BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 125mm bore
01EBCDF45MEXAT	LSM45BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 125mm bore
01EBCDF45MGRAT	LSM45BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 130mm bore
01EBCDF50MEXAT	LSM50BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 130mm bore
01EBCDF50MGRAT	LSM50BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 135mm bore
01EBCDF60MEXAT	LSM60BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 135mm bore
01EBCDF60MGRAT	LSM60BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 140mm bore
01EBCDF65MEXAT	LSM65BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 140mm bore
01EBCDF65MGRAT	LSM65BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 150mm bore
01EBCDF70MEXAT	LSM70BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 150mm bore
01EBCDF70MGRAT	LSM70BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 155mm bore
01EBCDF75MEXAT	LSM75BXHDFATL	Light Series Metric Retained Bearing Square Flange Full Assembly with ATL Seals: 155mm bore
01EBCDF75MGRAT	LSM75BRHDFATL	Light Series Metric Expansion Bearing Square Flange Full Assembly with ATL Seals: 160mm bore
01EBCF1000EXAT	LSE1000BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
01EBCF1000GRAT	LSE1000BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
01EBCF100MEXAT	LSM100BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 100mm bore
01EBCF100MGRAT	LSM100BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 100mm bore
01EBCF105MEXAT	LSM105BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 105mm bore
01EBCF105MGRAT	LSM105BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 105mm bore
01EBCF1100EXAT	LSE1100BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
01EBCF1100GRAT	LSE1100BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
01EBCF111EXAT	LSE111BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 1/16 in. bore
01EBCF111GRAT	LSE111BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 1/16 in. bore

Cooper Part Number	Timken Part Number	Timken Description
01EBCF112EXAT	LSE112BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 3/4 in. bore
01EBCF112GRAT	LSE112BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 3/4 in. bore
01EBCF115EXAT	LSE115BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 15/16 in. bore
01EBCF115GRAT	LSE115BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 15/16 in. bore
01EBCF1200EXAT	LSE1200BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
01EBCF1200GRAT	LSE1200BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
01EBCF160MEXAT	LSM160BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
01EBCF160MGRAT	LSM160BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
01EBCF170MEXAT	LSM170BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
01EBCF170MGRAT	LSM170BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
01EBCF180MEXAT	LSM180BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
01EBCF180MGRAT	LSM180BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
01EBCF190MEXAT	LSM190BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
01EBCF190MGRAT	LSM190BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
01EBCF200EXAT	LSE200BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 in. bore
01EBCF200GRAT	LSE200BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 in. bore
01EBCF200MEXAT	LSM200BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
01EBCF200MGRAT	LSM200BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
01EBCF203EXAT	LSE203BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 3/16 in. bore
01EBCF203GRAT	LSE203BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 3/16 in. bore
01EBCF204EXAT	LSE204BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 1/4 in. bore
01EBCF204GRAT	LSE204BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 1/4 in. bore
01EBCF207EXAT	LSE207BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 7/16 in. bore
01EBCF207GRAT	LSE207BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 7/16 in. bore
01EBCF208EXAT	LSE208BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 1/2 in. bore
01EBCF208GRAT	LSE208BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 1/2 in. bore
01EBCF211EXAT	LSE211BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 11/16 in. bore
01EBCF211GRAT	LSE211BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 11/16 in. bore
01EBCF212EXAT	LSE212BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 3/4 in. bore
01EBCF212GRAT	LSE212BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 3/4 in. bore
01EBCF215EXAT	LSE215BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 15/16 in. bore
01EBCF215GRAT	LSE215BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 15/16 in. bore
01EBCF220MEXAT	LSM220BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
01EBCF220MGRAT	LSM220BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
01EBCF240MEXAT	LSM240BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
01EBCF240MGRAT	LSM240BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
01EBCF260MEXAT	LSM260BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
01EBCF260MGRAT	LSM260BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
01EBCF280MEXAT	LSM280BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
01EBCF280MGRAT	LSM280BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
01EBCF300EXAT	LSE300BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 in. bore
01EBCF300GRAT	LSE300BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 in. bore
01EBCF300MEXAT	LSM300BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
01EBCF300MGRAT	LSM300BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
01EBCF303EXAT	LSE303BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 3/16 in. bore
01EBCF303GRAT	LSE303BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 3/16 in. bore
01EBCF304EXAT	LSE304BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 1/4 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EBCF304GRAT	LSE304BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 ¼ in. bore
01EBCF307EXAT	LSE307BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 ⅞ in. bore
01EBCF307GRAT	LSE307BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 ⅞ in. bore
01EBCF308EXAT	LSE308BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 ½ in. bore
01EBCF308GRAT	LSE308BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 ½ in. bore
01EBCF311EXAT	LSE311BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 ⅞ in. bore
01EBCF311GRAT	LSE311BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 ⅞ in. bore
01EBCF312EXAT	LSE312BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 ¾ in. bore
01EBCF312GRAT	LSE312BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 ¾ in. bore
01EBCF315EXAT	LSE315BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 ⅞ in. bore
01EBCF315GRAT	LSE315BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 ⅞ in. bore
01EBCF400EXAT	LSE400BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 in. bore
01EBCF400GRAT	LSE400BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 in. bore
01EBCF45MEXAT	LSM45BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 45mm bore
01EBCF45MGRAT	LSM45BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 45mm bore
01EBCF50MEXAT	LSM50BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 50mm bore
01EBCF50MGRAT	LSM50BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 50mm bore
01EBCF607EXAT	LSE607BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 ⅞ in. bore
01EBCF607GRAT	LSE607BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 ⅞ in. bore
01EBCF608EXAT	LSE608BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 ½ in. bore
01EBCF608GRAT	LSE608BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 ½ in. bore
01EBCF60MEXAT	LSM60BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 60mm bore
01EBCF60MGRAT	LSM60BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 60mm bore
01EBCF615EXAT	LSE615BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 ⅞ in. bore
01EBCF615GRAT	LSE615BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 ⅞ in. bore
01EBCF65MEXAT	LSM65BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 65mm bore
01EBCF65MGRAT	LSM65BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 65mm bore
01EBCF700EXAT	LSE700BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
01EBCF700GRAT	LSE700BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
01EBCF70MEXAT	LSM70BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 70mm bore
01EBCF70MGRAT	LSM70BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 70mm bore
01EBCF715EXAT	LSE715BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 ⅞ in. bore
01EBCF715GRAT	LSE715BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 ⅞ in. bore
01EBCF75MEXAT	LSM75BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 75mm bore
01EBCF75MGRAT	LSM75BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 75mm bore
01EBCF800EXAT	LSE800BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
01EBCF800GRAT	LSE800BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
01EBCF80MEXAT	LSM80BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 80mm bore
01EBCF80MGRAT	LSM80BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 80mm bore
01EBCF85MEXAT	LSM85BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 85mm bore
01EBCF85MGRAT	LSM85BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 85mm bore
01EBCF900EXAT	LSE900BXHFATL	Light Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
01EBCF900GRAT	LSE900BRHFATL	Light Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
01EBCF90MEXAT	LSM90BXHFATL	Light Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 90mm bore
01EBCF90MGRAT	LSM90BRHFATL	Light Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 90mm bore
01EBCFSAFC517308EXAT	LSE308BXHSAFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 ½ in. bore
01EBCFSAFC51780MEXAT	LSM80BXHSAFQAATL	Light Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 80mm bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EBCFS AFC51785MEXAT	LSM85BXHS AFQAATL	Light Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 85mm bore
01EBCFS AFC51785MGRAT	LSM85BRHS AFQAATL	Light Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 85mm bore
01EBCFS AFC520315EXAT	LSE315BXHS AFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 15/16 in. bore
01EBCFS AFC520315GRAT	LSE315BRHS AFQAATL	Light Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 15/16 in. bore
01EBCFS AFC520400EXAT	LSE400BXHS AFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 in. bore
01EBCFS AFC520400GRAT	LSE400BRHS AFQAATL	Light Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 in. bore
01EBCP1000EXAT	LSE1000BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
01EBCP1000GRAT	LSE1000BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
01EBCP100MEXAT	LSM100BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
01EBCP100MEXAT	LSM100BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
01EBCP100MGRAT	LSM100BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
01EBCP100MGRAT	LSM100BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
01EBCP105MEXAT	LSM105BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
01EBCP105MEXAT	LSM105BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
01EBCP105MGRAT	LSM105BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
01EBCP105MGRAT	LSM105BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
01EBCP1100EXAT	LSE1100BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
01EBCP1100GRAT	LSE1100BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
01EBCP111EXAT	LSE111BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 11/16 in. bore
01EBCP111GRAT	LSE111BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 11/16 in. bore
01EBCP112EXAT	LSE112BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 1/4 in. bore
01EBCP112GRAT	LSE112BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 1/4 in. bore
01EBCP115EXAT	LSE115BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 15/16 in. bore
01EBCP115GRAT	LSE115BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 15/16 in. bore
01EBCP1200EXAT	LSE1200BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
01EBCP1200GRAT	LSE1200BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
01EBCP160MEXAT	LSM160BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
01EBCP160MGRAT	LSM160BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
01EBCP170MEXAT	LSM170BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
01EBCP170MGRAT	LSM170BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
01EBCP180MEXAT	LSM180BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
01EBCP180MGRAT	LSM180BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
01EBCP190MEXAT	LSM190BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
01EBCP190MGRAT	LSM190BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
01EBCP200EXAT	LSE200BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 2 in. bore
01EBCP200GRAT	LSE200BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 2 in. bore
01EBCP200MEXAT	LSM200BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
01EBCP200MGRAT	LSM200BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
01EBCP203EXAT	LSE203BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 2 3/16 in. bore
01EBCP203GRAT	LSE203BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 2 3/16 in. bore
01EBCP204EXAT	LSE204BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 2 1/4 in. bore
01EBCP204GRAT	LSE204BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 2 1/4 in. bore
01EBCP207EXAT	LSE207BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 2 7/16 in. bore
01EBCP207GRAT	LSE207BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 2 7/16 in. bore
01EBCP208EXAT	LSE208BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 2 1/2 in. bore
01EBCP208GRAT	LSE208BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 2 1/2 in. bore
01EBCP211EXAT	LSE211BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 2 11/16 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EBCP400EXAT	LSE400BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 in. bore
01EBCP400EXAT	LSE400BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 in. bore
01EBCP400GRAT	LSE400BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 in. bore
01EBCP400GRAT	LSE400BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 in. bore
01EBCP45MEXAT	LSM45BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 45mm bore
01EBCP45MGRAT	LSM45BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 45mm bore
01EBCP50MEXAT	LSM50BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 50mm bore
01EBCP50MGRAT	LSM50BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 50mm bore
01EBCP607EXAT	LSE607BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
01EBCP607GRAT	LSE607BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
01EBCP608EXAT	LSE608BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore
01EBCP608GRAT	LSE608BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore
01EBCP60MEXAT	LSM60BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 60mm bore
01EBCP60MGRAT	LSM60BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 60mm bore
01EBCP615EXAT	LSE615BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 15/16 in. bore
01EBCP615GRAT	LSE615BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 15/16 in. bore
01EBCP65MEXAT	LSM65BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 65mm bore
01EBCP65MGRAT	LSM65BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 65mm bore
01EBCP700EXAT	LSE700BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
01EBCP700GRAT	LSE700BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
01EBCP70MEXAT	LSM70BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 70mm bore
01EBCP70MGRAT	LSM70BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 70mm bore
01EBCP715EXAT	LSE715BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 15/16 in. bore
01EBCP715GRAT	LSE715BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 15/16 in. bore
01EBCP75MEXAT	LSM75BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 75mm bore
01EBCP75MGRAT	LSM75BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 75mm bore
01EBCP800EXAT	LSE800BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
01EBCP800GRAT	LSE800BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
01EBCP80MEXAT	LSM80BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
01EBCP80MEXAT	LSM80BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
01EBCP80MGRAT	LSM80BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
01EBCP80MGRAT	LSM80BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
01EBCP85MEXAT	LSM85BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
01EBCP85MEXAT	LSM85BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
01EBCP85MGRAT	LSM85BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
01EBCP85MGRAT	LSM85BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
01EBCP900EXAT	LSE900BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
01EBCP900GRAT	LSE900BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
01EBCP908EXAT	LSE908BXHSATL	Light Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 1/2 in. bore
01EBCP908GRAT	LSE908BRHSATL	Light Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 9 1/2 in. bore
01EBCP90MEXAT	LSM90BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
01EBCP90MEXAT	LSM90BXHSATL	Light Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
01EBCP90MGRAT	LSM90BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
01EBCP90MGRAT	LSM90BRHSATL	Light Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
01EBCSAFC51111EXAT	LSE111BXHSAFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 1 11/16 in. bore
01EBCSAFC51111GRAT	LSE111BRHSAFQAATL	Light Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 1 11/16 in. bore
01EBCSAFC511112EXAT	LSE112BXHSAFQAATL	Light Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 1 3/4 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
01EBCSNC515208GRAT	LSE208BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ½ in. bore
01EBCSNC51565MEXAT	LSM65BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 65mm bore
01EBCSNC51565MGRAT	LSM65BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 65mm bore
01EBCSNC516211EXAT	LSE211BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ¼ in. bore
01EBCSNC516211GRAT	LSE211BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ¼ in. bore
01EBCSNC516212EXAT	LSE212BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ¾ in. bore
01EBCSNC516212GRAT	LSE212BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ¾ in. bore
01EBCSNC51670MEXAT	LSM70BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 70mm bore
01EBCSNC51670MGRAT	LSM70BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 70mm bore
01EBCSNC517215EXAT	LSE215BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ½ in. bore
01EBCSNC517215GRAT	LSE215BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 2 ½ in. bore
01EBCSNC517300EXAT	LSE300BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 in. bore
01EBCSNC517300GRAT	LSE300BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 in. bore
01EBCSNC518303EXAT	LSE303BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅙ in. bore
01EBCSNC518303GRAT	LSE303BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅙ in. bore
01EBCSNC518304EXAT	LSE304BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ¼ in. bore
01EBCSNC518304GRAT	LSE304BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ¼ in. bore
01EBCSNC518307EXAT	LSE307BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅞ in. bore
01EBCSNC518307GRAT	LSE307BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅞ in. bore
01EBCSNC51880MEXAT	LSM80BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 80mm bore
01EBCSNC51880MGRAT	LSM80BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 80mm bore
01EBCSNC51980MEXAT	LSM80BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 80mm bore
01EBCSNC51980MGRAT	LSM80BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 80mm bore
01EBCSNC51985MEXAT	LSM85BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 85mm bore
01EBCSNC51985MGRAT	LSM85BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 85mm bore
01EBCSNC520307EXAT	LSE307BXHSNQBATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅞ in. bore
01EBCSNC520307GRAT	LSE307BRHSNQBATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅞ in. bore
01EBCSNC520308EXAT	LSE308BXHSNQBATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ½ in. bore
01EBCSNC520308GRAT	LSE308BRHSNQBATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ½ in. bore
01EBCSNC52085MEXAT	LSM85BXHSNQBATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 85mm bore
01EBCSNC52085MGRAT	LSM85BRHSNQBATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 85mm bore
01EBCSNC52090MEXAT	LSM90BXHSNQBATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 90mm bore
01EBCSNC52090MGRAT	LSM90BRHSNQBATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 90mm bore
01EBCSNC522100MEXAT	LSM100BXHSNQAATL	Light Series Metric Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 100mm bore
01EBCSNC522100MGRAT	LSM100BRHSNQAATL	Light Series Metric Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 100mm bore
01EBCSNC522315EXAT	LSE315BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅝ in. bore
01EBCSNC522315GRAT	LSE315BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 3 ⅝ in. bore
01EBCSNC522400EXAT	LSE400BXHSNQAATL	Light Series Imperial Expansion Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 in. bore
01EBCSNC522400GRAT	LSE400BRHSNQAATL	Light Series Imperial Retained Bearing SN/S Dimensioned Full Housed Assembly (Quick Series) with ATL Seals 4 in. bore
02B1000EX	MSE1000BX	Medium Series Imperial Expansion Bearing: 10 in. bore
02B1000GR	MSE1000BR	Medium Series Imperial Retained Bearing: 10 in. bore
02B100MEX	MSM100BX	Medium Series Metric Expansion Bearing: 100mm bore
02B100MGR	MSM100BR	Medium Series Metric Retained Bearing: 100mm bore
02B105MEX	MSM105BX	Medium Series Metric Expansion Bearing: 105mm bore
02B105MGR	MSM105BR	Medium Series Metric Retained Bearing: 105mm bore
02B1100EX	MSE1100BX	Medium Series Imperial Expansion Bearing: 11 in. bore
02B1100GR	MSE1100BR	Medium Series Imperial Retained Bearing: 11 in. bore

Cooper Part Number	Timken Part Number	Timken Description
02B110MEX	MSM110BX	Medium Series Metric Expansion Bearing: 110mm bore
02B110MGR	MSM110BR	Medium Series Metric Retained Bearing: 110mm bore
02B115EX	MSE115BX	Medium Series Imperial Expansion Bearing: 1 1/16 in. bore
02B115GR	MSE115BR	Medium Series Imperial Retained Bearing: 1 1/16 in. bore
02B115MEX	MSM115BX	Medium Series Metric Expansion Bearing: 115mm bore
02B115MGR	MSM115BR	Medium Series Metric Retained Bearing: 115mm bore
02B1200EX	MSE1200BX	Medium Series Imperial Expansion Bearing: 12 in. bore
02B1200GR	MSE1200BR	Medium Series Imperial Retained Bearing: 12 in. bore
02B120MEX	MSM120BX	Medium Series Metric Expansion Bearing: 120mm bore
02B120MGR	MSM120BR	Medium Series Metric Retained Bearing: 120mm bore
02B125MEX	MSM125BX	Medium Series Metric Expansion Bearing: 125mm bore
02B125MGR	MSM125BR	Medium Series Metric Retained Bearing: 125mm bore
02B1300EX	MSE1300BX	Medium Series Imperial Expansion Bearing: 13 in. bore
02B1300GR	MSE1300BR	Medium Series Imperial Retained Bearing: 13 in. bore
02B130MEX	MSM130BX	Medium Series Metric Expansion Bearing: 130mm bore
02B130MGR	MSM130BR	Medium Series Metric Retained Bearing: 130mm bore
02B1400EX	MSE1400BX	Medium Series Imperial Expansion Bearing: 14 in. bore
02B1400GR	MSE1400BR	Medium Series Imperial Retained Bearing: 14 in. bore
02B140MEX	MSM140BX	Medium Series Metric Expansion Bearing: 140mm bore
02B140MGR	MSM140BR	Medium Series Metric Retained Bearing: 140mm bore
02B145MEX	MSM145BX	Medium Series Metric Expansion Bearing: 145mm bore
02B145MGR	MSM145BR	Medium Series Metric Retained Bearing: 145mm bore
02B1500EX	MSE1500BX	Medium Series Imperial Expansion Bearing: 15 in. bore
02B1500EX	MSE1500BX	Medium Series Imperial Expansion Bearing: 15 in. bore
02B1500GR	MSE1500BR	Medium Series Imperial Retained Bearing: 15 in. bore
02B150MEX	MSM150BX	Medium Series Metric Expansion Bearing: 150mm bore
02B150MGR	MSM150BR	Medium Series Metric Retained Bearing: 150mm bore
02B155MEX	MSM155BX	Medium Series Metric Expansion Bearing: 155mm bore
02B155MGR	MSM155BR	Medium Series Metric Retained Bearing: 155mm bore
02B1600EX	MSE1600BX	Medium Series Imperial Expansion Bearing: 16 in. bore
02B1600GR	MSE1600BR	Medium Series Imperial Retained Bearing: 16 in. bore
02B160MEX	MSM160BX	Medium Series Metric Expansion Bearing: 160mm bore
02B160MGR	MSM160BR	Medium Series Metric Retained Bearing: 160mm bore
02B1700EX	MSE1700BX	Medium Series Imperial Expansion Bearing: 17 in. bore
02B1700GR	MSE1700BR	Medium Series Imperial Retained Bearing: 17 in. bore
02B170MEX	MSM170BX	Medium Series Metric Expansion Bearing: 170mm bore
02B170MGR	MSM170BR	Medium Series Metric Retained Bearing: 170mm bore
02B1800EX	MSE1800BX	Medium Series Imperial Expansion Bearing: 18 in. bore
02B1800GR	MSE1800BR	Medium Series Imperial Retained Bearing: 18 in. bore
02B180MEX	MSM180BX	Medium Series Metric Expansion Bearing: 180mm bore
02B180MGR	MSM180BR	Medium Series Metric Retained Bearing: 180mm bore
02B1900EX	MSE1900BX	Medium Series Imperial Expansion Bearing: 19 in. bore
02B1900GR	MSE1900BR	Medium Series Imperial Retained Bearing: 19 in. bore
02B190MEX	MSM190BX	Medium Series Metric Expansion Bearing: 190mm bore
02B190MGR	MSM190BR	Medium Series Metric Retained Bearing: 190mm bore
02B2000EX	MSE2000BX	Medium Series Imperial Expansion Bearing: 20 in. bore
02B2000GR	MSE2000BR	Medium Series Imperial Retained Bearing: 20 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02B200EX	MSE200BX	Medium Series Imperial Expansion Bearing: 2 in. bore
02B200GR	MSE200BR	Medium Series Imperial Retained Bearing: 2 in. bore
02B200MEX	MSM200BX	Medium Series Metric Expansion Bearing: 200mm bore
02B200MGR	MSM200BR	Medium Series Metric Retained Bearing: 200mm bore
02B203EX	MSE203BX	Medium Series Imperial Expansion Bearing: 2 3/16 in. bore
02B203GR	MSE203BR	Medium Series Imperial Retained Bearing: 2 3/16 in. bore
02B204EX	MSE204BX	Medium Series Imperial Expansion Bearing: 2 1/4 in. bore
02B204GR	MSE204BR	Medium Series Imperial Retained Bearing: 2 1/4 in. bore
02B207EX	MSE207BX	Medium Series Imperial Expansion Bearing: 2 7/16 in. bore
02B207GR	MSE207BR	Medium Series Imperial Retained Bearing: 2 7/16 in. bore
02B208EX	MSE208BX	Medium Series Imperial Expansion Bearing: 2 1/2 in. bore
02B208GR	MSE208BR	Medium Series Imperial Retained Bearing: 2 1/2 in. bore
02B2100EX	MSE2100BX	Medium Series Imperial Expansion Bearing: 21 in. bore
02B2100GR	MSE2100BR	Medium Series Imperial Retained Bearing: 21 in. bore
02B211EX	MSE211BX	Medium Series Imperial Expansion Bearing: 2 11/16 in. bore
02B211GR	MSE211BR	Medium Series Imperial Retained Bearing: 2 11/16 in. bore
02B212EX	MSE212BX	Medium Series Imperial Expansion Bearing: 2 3/4 in. bore
02B212GR	MSE212BR	Medium Series Imperial Retained Bearing: 2 3/4 in. bore
02B215EX	MSE215BX	Medium Series Imperial Expansion Bearing: 2 15/16 in. bore
02B215GR	MSE215BR	Medium Series Imperial Retained Bearing: 2 15/16 in. bore
02B2200EX	MSE2200BX	Medium Series Imperial Expansion Bearing: 22 in. bore
02B2200GR	MSE2200BR	Medium Series Imperial Retained Bearing: 22 in. bore
02B220MEX	MSM220BX	Medium Series Metric Expansion Bearing: 220mm Bore
02B220MGR	MSM220BR	Medium Series Metric Retained Bearing: 220mm Bore
02B2300EX	MSE2300BX	Medium Series Imperial Expansion Bearing: 23 in. bore
02B2300GR	MSE2300BR	Medium Series Imperial Retained Bearing: 23 in. bore
02B2400EX	MSE2400BX	Medium Series Imperial Expansion Bearing: 24 in. bore
02B2400GR	MSE2400BR	Medium Series Imperial Retained Bearing: 24 in. bore
02B240MEX	MSM240BX	Medium Series Metric Expansion Bearing: 240mm bore
02B240MGR	MSM240BR	Medium Series Metric Retained Bearing: 240mm Bore
02B260MEX	MSM260BX	Medium Series Metric Expansion Bearing: 260mm Bore
02B260MGR	MSM260BR	Medium Series Metric Retained Bearing: 260mm Bore
02B280MEX	MSM280BX	Medium Series Metric Expansion Bearing: 280mm Bore
02B280MGR	MSM280BR	Medium Series Metric Retained Bearing: 280mm Bore
02B300EX	MSE300BX	Medium Series Imperial Expansion Bearing: 3 in. bore
02B300GR	MSE300BR	Medium Series Imperial Retained Bearing: 3 in. bore
02B300MEX	MSM300BX	Medium Series Metric Expansion Bearing: 300mm Bore
02B300MGR	MSM300BR	Medium Series Metric Retained Bearing: 300mm Bore
02B303EX	MSE303BX	Medium Series Imperial Expansion Bearing: 3 3/16 in. bore
02B303GR	MSE303BR	Medium Series Imperial Retained Bearing: 3 3/16 in. bore
02B304EX	MSE304BX	Medium Series Imperial Expansion Bearing: 3 1/4 in. bore
02B304GR	MSE304BR	Medium Series Imperial Retained Bearing: 3 1/4 in. bore
02B307EX	MSE307BX	Medium Series Imperial Expansion Bearing: 3 7/16 in. bore
02B307GR	MSE307BR	Medium Series Imperial Retained Bearing: 3 7/16 in. bore
02B308EX	MSE308BX	Medium Series Imperial Expansion Bearing: 3 1/2 in. bore
02B308GR	MSE308BR	Medium Series Imperial Retained Bearing: 3 1/2 in. bore
02B311EX	MSE311BX	Medium Series Imperial Expansion Bearing: 3 11/16 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02B311GR	MSE311BR	Medium Series Imperial Retained Bearing: 3 1/16 in. bore
02B312EX	MSE312BX	Medium Series Imperial Expansion Bearing: 3 3/4 in. bore
02B312GR	MSE312BR	Medium Series Imperial Retained Bearing: 3 3/4 in. bore
02B315EX	MSE315BX	Medium Series Imperial Expansion Bearing: 3 15/16 in. bore
02B315GR	MSE315BR	Medium Series Imperial Retained Bearing: 3 15/16 in. bore
02B320MEX	MSM320BX	Medium Series Metric Expansion Bearing: 320mm bore
02B320MGR	MSM320BR	Medium Series Metric Retained Bearing: 320mm bore
02B340MEX	MSM340BX	Medium Series Metric Expansion Bearing: 340mm bore
02B340MGR	MSM340BR	Medium Series Metric Retained Bearing: 340mm bore
02B360MEX	MSM360BX	Medium Series Metric Expansion Bearing: 360mm bore
02B360MGR	MSM360BR	Medium Series Metric Retained Bearing: 360mm bore
02B380MEX	MSM380BX	Medium Series Metric Expansion Bearing: 380mm bore
02B380MGR	MSM380BR	Medium Series Metric Retained Bearing: 380mm bore
02B400EX	MSE400BX	Medium Series Imperial Expansion Bearing: 4 in. bore
02B400GR	MSE400BR	Medium Series Imperial Retained Bearing: 4 in. bore
02B400MEX	MSM400BX	Medium Series Metric Expansion Bearing: 400mm bore
02B400MGR	MSM400BR	Medium Series Metric Retained Bearing: 400mm bore
02B403EX	MSE403BX	Medium Series Imperial Expansion Bearing: 4 3/16 in. bore
02B403GR	MSE403BR	Medium Series Imperial Retained Bearing: 4 3/16 in. bore
02B404EX	MSE404BX	Medium Series Imperial Expansion Bearing: 4 1/4 in. bore
02B404GR	MSE404BR	Medium Series Imperial Retained Bearing: 4 1/4 in. bore
02B407EX	MSE407BX	Medium Series Imperial Expansion Bearing: 4 7/16 in. bore
02B407GR	MSE407BR	Medium Series Imperial Retained Bearing: 4 7/16 in. bore
02B408EX	MSE408BX	Medium Series Imperial Expansion Bearing: 4 1/2 in. bore
02B408GR	MSE408BR	Medium Series Imperial Retained Bearing: 4 1/2 in. bore
02B411EX	MSE411BX	Medium Series Imperial Expansion Bearing: 4 11/16 in. bore
02B411GR	MSE411BR	Medium Series Imperial Retained Bearing: 4 11/16 in. bore
02B412EX	MSE412BX	Medium Series Imperial Expansion Bearing: 4 3/4 in. bore
02B412GR	MSE412BR	Medium Series Imperial Retained Bearing: 4 3/4 in. bore
02B415EX	MSE415BX	Medium Series Imperial Expansion Bearing: 4 15/16 in. bore
02B415GR	MSE415BR	Medium Series Imperial Retained Bearing: 4 15/16 in. bore
02B420MEX	MSM420BX	Medium Series Metric Expansion Bearing: 420mm bore
02B420MGR	MSM420BR	Medium Series Metric Retained Bearing: 420mm bore
02B440MEX	MSM440BX	Medium Series Metric Expansion Bearing: 440mm bore
02B440MGR	MSM440BR	Medium Series Metric Retained Bearing: 440mm bore
02B460MEX	MSM460BX	Medium Series Metric Expansion Bearing: 460mm bore
02B460MGR	MSM460BR	Medium Series Metric Retained Bearing: 460mm bore
02B480MEX	MSM480BX	Medium Series Metric Expansion Bearing: 480mm bore
02B480MGR	MSM480BR	Medium Series Metric Retained Bearing: 480mm bore
02B500EX	MSE500BX	Medium Series Imperial Expansion Bearing: 5 in. bore
02B500GR	MSE500BR	Medium Series Imperial Retained Bearing: 5 in. bore
02B500MEX	MSM500BX	Medium Series Metric Expansion Bearing: 500mm bore
02B500MGR	MSM500BR	Medium Series Metric Retained Bearing: 500mm bore
02B503EX	MSE503BX	Medium Series Imperial Expansion Bearing: 5 3/16 in. bore
02B503GR	MSE503BR	Medium Series Imperial Retained Bearing: 5 3/16 in. bore
02B507EX	MSE507BX	Medium Series Imperial Expansion Bearing: 5 7/16 in. bore
02B507GR	MSE507BR	Medium Series Imperial Retained Bearing: 5 7/16 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02B508EX	MSE508BX	Medium Series Imperial Expansion Bearing: 5 ½ in. bore
02B508GR	MSE508BR	Medium Series Imperial Retained Bearing: 5 ½ in. bore
02B50MEX	MSM50BX	Medium Series Metric Expansion Bearing: 50mm bore
02B50MGR	MSM50BR	Medium Series Metric Retained Bearing: 50mm bore
02B512EX	MSE512BX	Medium Series Imperial Expansion Bearing: 5 ¾ in. bore
02B512GR	MSE512BR	Medium Series Imperial Retained Bearing: 5 ¾ in. bore
02B515EX	MSE515BX	Medium Series Imperial Expansion Bearing: 5 15/16 in. bore
02B515GR	MSE515BR	Medium Series Imperial Retained Bearing: 5 15/16 in. bore
02B530MEX	MSM530BX	Medium Series Metric Expansion Bearing: 530mm bore
02B530MGR	MSM530BR	Medium Series Metric Retained Bearing: 530mm bore
02B560MEX	MSM560BX	Medium Series Metric Expansion Bearing: 560mm bore
02B560MGR	MSM560BR	Medium Series Metric Retained Bearing: 560mm bore
02B600EX	MSE600BX	Medium Series Imperial Expansion Bearing: 6 in. bore
02B600GR	MSE600BR	Medium Series Imperial Retained Bearing: 6 in. bore
02B600MEX	MSM600BX	Medium Series Metric Expansion Bearing: 600mm bore
02B600MGR	MSM600BR	Medium Series Metric Retained Bearing: 600mm bore
02B607EX	MSE607BX	Medium Series Imperial Expansion Bearing: 6 7/16 in. bore
02B607GR	MSE607BR	Medium Series Imperial Retained Bearing: 6 7/16 in. bore
02B608EX	MSE608BX	Medium Series Imperial Expansion Bearing: 6 ½ in. bore
02B608GR	MSE608BR	Medium Series Imperial Retained Bearing: 6 ½ in. bore
02B60MEX	MSM60BX	Medium Series Metric Expansion Bearing: 60mm bore
02B60MGR	MSM60BR	Medium Series Metric Retained Bearing: 60mm bore
02B615EX	MSE615BX	Medium Series Imperial Expansion Bearing: 6 15/16 in. bore
02B615GR	MSE615BR	Medium Series Imperial Retained Bearing: 6 15/16 in. bore
02B65MEX	MSM65BX	Medium Series Metric Expansion Bearing: 65mm bore
02B65MGR	MSM65BR	Medium Series Metric Retained Bearing: 65mm bore
02B700EX	MSE700BX	Medium Series Imperial Expansion Bearing: 7 in. bore
02B700GR	MSE700BR	Medium Series Imperial Retained Bearing: 7 in. bore
02B708EX	MSE708BX	Medium Series Imperial Expansion Bearing: 7 ½ in. bore
02B708GR	MSE708BR	Medium Series Imperial Retained Bearing: 7 ½ in. bore
02B70MEX	MSM70BX	Medium Series Metric Expansion Bearing: 70mm bore
02B70MGR	MSM70BR	Medium Series Metric Retained Bearing: 70mm bore
02B715EX	MSE715BX	Medium Series Imperial Expansion Bearing: 7 15/16 in. bore
02B715GR	MSE715BR	Medium Series Imperial Retained Bearing: 7 15/16 in. bore
02B75MEX	MSM75BX	Medium Series Metric Expansion Bearing: 75mm bore
02B75MGR	MSM75BR	Medium Series Metric Retained Bearing: 75mm bore
02B800EX	MSE800BX	Medium Series Imperial Expansion Bearing: 8 in. bore
02B800GR	MSE800BR	Medium Series Imperial Retained Bearing: 8 in. bore
02B808EX	MSE808BX	Medium Series Imperial Expansion Bearing: 8 ½ in. bore
02B808GR	MSE808BR	Medium Series Imperial Retained Bearing: 8 ½ in. bore
02B80MEX	MSM80BX	Medium Series Metric Expansion Bearing: 80mm bore
02B80MGR	MSM80BR	Medium Series Metric Retained Bearing: 80mm bore
02B85MEX	MSM85BX	Medium Series Metric Expansion Bearing: 85mm bore
02B85MGR	MSM85BR	Medium Series Metric Retained Bearing: 85mm bore
02B900EX	MSE900BX	Medium Series Imperial Expansion Bearing: 9 in. bore
02B900GR	MSE900BR	Medium Series Imperial Retained Bearing: 9 in. bore
02B90MEX	MSM90BX	Medium Series Metric Expansion Bearing: 90mm bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02B90MGR	MSM90BR	Medium Series Metric Retained Bearing: 90mm bore
02BC1000EXAT	MSE1000BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 10 in. bore
02BC1000GRAT	MSE1000BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 10 in. bore
02BC100MEXAT	MSM100BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 100mm bore
02BC100MGRAT	MSM100BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 100mm bore
02BC105MGRAT	MSM105BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 105mm bore
02BC1100EXAT	MSE1100BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 11 in. bore
02BC1100GRAT	MSE1100BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 11 in. bore
02BC110MEXAT	MSM110BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 110mm bore
02BC110MGRAT	MSM110BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 110mm bore
02BC115EXAT	MSE115BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 1 15/16 in. bore
02BC115GRAT	MSE115BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 1 15/16 in. bore
02BC115MEXAT	MSM115BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 115mm bore
02BC115MGRAT	MSM115BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 115mm bore
02BC1200EXAT	MSE1200BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 12 in. bore
02BC1200GRAT	MSE1200BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 12 in. bore
02BC120MEXAT	MSM120BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 120mm bore
02BC120MGRAT	MSM120BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 120mm bore
02BC125MEXAT	MSM125BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 125mm bore
02BC125MGRAT	MSM125BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 125mm bore
02BC1300EXAT	MSE1300BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 13 in. bore
02BC1300EXLAB	MSE1300BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
02BC1300GRAT	MSE1300BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 13 in. bore
02BC1300GRLAB	MSE1300BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
02BC130MEXAT	MSM130BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 130mm bore
02BC130MGRAT	MSM130BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 130mm bore
02BC1400EXLAB	MSE1400BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
02BC1400GRLAB	MSE1400BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
02BC140MEXAT	MSM140BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 140mm bore
02BC140MGRAT	MSM140BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 140mm bore
02BC145MEXAT	MSM145BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 145mm bore
02BC145MGRAT	MSM145BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 145mm bore
02BC1500EXLAB	MSE1500BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
02BC1500GRLAB	MSE1500BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
02BC150MEXAT	MSM150BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 150mm bore
02BC150MGRAT	MSM150BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 150mm bore
02BC155MEXAT	MSM155BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 155mm bore
02BC155MGRAT	MSM155BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 155mm bore
02BC1600EXLAB	MSE1600BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 16 in. bore
02BC1600GRLAB	MSE1600BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 16 in. bore
02BC160MEXAT	MSM160BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 160mm bore
02BC160MGRAT	MSM160BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 160mm bore
02BC1700EXLAB	MSE1700BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
02BC1700GRLAB	MSE1700BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
02BC170MEXAT	MSM170BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 170mm bore
02BC170MGRAT	MSM170BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 170mm bore
02BC1800EXLAB	MSE1800BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore

Cooper Part Number	Timken Part Number	Timken Description
02BC1800GRLAB	MSE1800BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 18 in. bore
02BC180MEXAT	MSM180BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 180mm bore
02BC180MGRAT	MSM180BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 180mm bore
02BC1900EXLAB	MSE1900BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 19 in. bore
02BC1900GRLAB	MSE1900BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 19 in. bore
02BC190MEXAT	MSM190BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 190mm bore
02BC190MGRAT	MSM190BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 190mm bore
02BC2000EXLAB	MSE2000BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
02BC2000GRLAB	MSE2000BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
02BC200EXAT	MSE200BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 in. bore
02BC200GRAT	MSE200BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 in. bore
02BC200MEXAT	MSM200BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 200mm bore
02BC200MGRAT	MSM200BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 200mm bore
02BC203EXAT	MSE203BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 3/16 in. bore
02BC203GRAT	MSE203BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 3/16 in. bore
02BC204EXAT	MSE204BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 1/4 in. bore
02BC204GRAT	MSE204BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 1/4 in. bore
02BC207EXAT	MSE207BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 7/16 in. bore
02BC207GRAT	MSE207BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 7/16 in. bore
02BC208EXAT	MSE208BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 1/2 in. bore
02BC208GRAT	MSE208BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 1/2 in. bore
02BC2100EXLAB	MSE2100BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 21 in. bore
02BC2100GRLAB	MSE2100BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 21 in. bore
02BC211EXAT	MSE211BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 1/16 in. bore
02BC211GRAT	MSE211BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 1/16 in. bore
02BC212EXAT	MSE212BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 3/8 in. bore
02BC212GRAT	MSE212BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 3/8 in. bore
02BC215EXAT	MSE215BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 2 15/16 in. bore
02BC215GRAT	MSE215BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 2 15/16 in. bore
02BC2200EXLAB	MSE2200BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
02BC2200GRLAB	MSE2200BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
02BC220MEXAT	MSM220BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 220mm bore
02BC220MGRAT	MSM220BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 220mm bore
02BC2300EXLAB	MSE2300BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
02BC2300GRLAB	MSE2300BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
02BC2400EXLAB	MSE2400BXHLAB	Medium Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 24 in. bore
02BC2400GRLAB	MSE2400BRHLAB	Medium Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 24 in. bore
02BC240MEXAT	MSM240BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 240mm bore
02BC240MGRAT	MSM240BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 240mm bore
02BC260MEXAT	MSM260BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 260mm bore
02BC260MGRAT	MSM260BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 260mm bore
02BC280MEXAT	MSM280BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 280mm bore
02BC280MGRAT	MSM280BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 280mm bore
02BC300EXAT	MSE300BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 in. bore
02BC300GRAT	MSE300BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 in. bore
02BC300MEXAT	MSM300BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 300mm bore
02BC300MGRAT	MSM300BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 300mm bore

Cooper Part Number	Timken Part Number	Timken Description
02BC303EXAT	MSE303BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 3/16 in. bore
02BC303GRAT	MSE303BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 3/16 in. bore
02BC304EXAT	MSE304BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 1/4 in. bore
02BC304GRAT	MSE304BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 1/4 in. bore
02BC307EXAT	MSE307BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 7/16 in. bore
02BC307GRAT	MSE307BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 7/16 in. bore
02BC308EXAT	MSE308BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 1/2 in. bore
02BC308GRAT	MSE308BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 1/2 in. bore
02BC311EXAT	MSE311BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 11/16 in. bore
02BC311GRAT	MSE311BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 11/16 in. bore
02BC312EXAT	MSE312BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 3/4 in. bore
02BC312GRAT	MSE312BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 3/4 in. bore
02BC315EXAT	MSE315BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 15/16 in. bore
02BC315GRAT	MSE315BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 15/16 in. bore
02BC320MEXLAB	MSM320BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
02BC320MGRLAB	MSM320BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
02BC340MEXLAB	MSM340BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
02BC340MGRLAB	MSM340BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
02BC360MEXLAB	MSM360BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
02BC360MGRLAB	MSM360BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
02BC380MEXLAB	MSM380BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
02BC380MGRLAB	MSM380BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
02BC400EXAT	MSE400BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 in. bore
02BC400GRAT	MSE400BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 in. bore
02BC400MEXLAB	MSM400BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
02BC400MGRLAB	MSM400BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
02BC403EXAT	MSE403BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 3/16 in. bore
02BC403GRAT	MSE403BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 3/16 in. bore
02BC407EXAT	MSE407BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 7/16 in. bore
02BC407GRAT	MSE407BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 7/16 in. bore
02BC408EXAT	MSE408BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 1/2 in. bore
02BC408GRAT	MSE408BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 1/2 in. bore
02BC411EXAT	MSE411BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 11/16 in. bore
02BC411GRAT	MSE411BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 11/16 in. bore
02BC412EXAT	MSE412BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 3/4 in. bore
02BC412GRAT	MSE412BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 3/4 in. bore
02BC415EXAT	MSE415BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 15/16 in. bore
02BC415GRAT	MSE415BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 15/16 in. bore
02BC420MEXLAB	MSM420BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
02BC420MGRLAB	MSM420BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
02BC440MEXLAB	MSM440BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
02BC440MGRLAB	MSM440BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
02BC460MEXLAB	MSM460BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
02BC460MGRLAB	MSM460BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
02BC480MEXLAB	MSM480BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
02BC480MGRLAB	MSM480BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
02BC500EXAT	MSE500BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02BC500GRAT	MSE500BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 in. bore
02BC500MEXLAB	MSM500BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
02BC500MGRLAB	MSM500BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
02BC503EXAT	MSE503BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 3/16 in. bore
02BC503GRAT	MSE503BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 3/16 in. bore
02BC507EXAT	MSE507BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 7/16 in. bore
02BC507GRAT	MSE507BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 7/16 in. bore
02BC508EXAT	MSE508BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 1/2 in. bore
02BC508GRAT	MSE508BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 1/2 in. bore
02BC50MEXAT	MSM50BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 50mm bore
02BC50MGRAT	MSM50BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 50mm bore
02BC512EXAT	MSE512BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 3/4 in. bore
02BC512GRAT	MSE512BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 3/4 in. bore
02BC515EXAT	MSE515BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 15/16 in. bore
02BC515GRAT	MSE515BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 15/16 in. bore
02BC530MEXLAB	MSM530BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
02BC530MGRLAB	MSM530BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
02BC560MEXLAB	MSM560BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
02BC560MGRLAB	MSM560BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
02BC600EXAT	MSE600BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 in. bore
02BC600GRAT	MSE600BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 in. bore
02BC600MEXLAB	MSM600BXHLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
02BC600MGRLAB	MSM600BRHLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
02BC607EXAT	MSE607BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
02BC607GRAT	MSE607BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
02BC608EXAT	MSE608BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
02BC608GRAT	MSE608BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
02BC60MEXAT	MSM60BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 60mm bore
02BC60MGRAT	MSM60BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 60mm bore
02BC615EXAT	MSE615BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
02BC615GRAT	MSE615BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
02BC65MEXAT	MSM65BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 65mm bore
02BC65MGRAT	MSM65BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 65mm bore
02BC700EXAT	MSE700BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 in. bore
02BC700GRAT	MSE700BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 in. bore
02BC708EXAT	MSE708BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 1/2 in. bore
02BC708GRAT	MSE708BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 1/2 in. bore
02BC70MEXAT	MSM70BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 70mm bore
02BC70MGRAT	MSM70BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 70mm bore
02BC715EXAT	MSE715BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
02BC715GRAT	MSE715BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
02BC75MEXAT	MSM75BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 75mm bore
02BC75MGRAT	MSM75BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 75mm bore
02BC800EXAT	MSE800BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 8 in. bore
02BC800GRAT	MSE800BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 8 in. bore
02BC80MEXAT	MSM80BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 80mm bore
02BC80MGRAT	MSM80BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 80mm bore

Cooper Part Number	Timken Part Number	Timken Description
02BC85MEXAT	MSM85BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 85mm bore
02BC85MGRAT	MSM85BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 85mm bore
02BC900EXAT	MSE900BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 in. bore
02BC900GRAT	MSE900BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 9 in. bore
02BC90MEXAT	MSM90BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 90mm bore
02BC90MGRAT	MSM90BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 90mm bore
02BCF1000EXAT	MSE1000BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
02BCF1000GRAT	MSE1000BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
02BCF100MEXAT	MSM100BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 100mm bore
02BCF100MGRAT	MSM100BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 100mm bore
02BCF105MEXAT	MSM105BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 105mm bore
02BCF105MGRAT	MSM105BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 105mm bore
02BCF1100EXAT	MSE1100BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
02BCF1100GRAT	MSE1100BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
02BCF110MEXAT	MSM110BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 110mm bore
02BCF110MGRAT	MSM110BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 110mm bore
02BCF115EXAT	MSE115BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 1 15/16 in. bore
02BCF115GRAT	MSE115BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 1 15/16 in. bore
02BCF115MEXAT	MSM115BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 115mm bore
02BCF115MGRAT	MSM115BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 115mm bore
02BCF1200EXAT	MSE1200BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
02BCF1200GRAT	MSE1200BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
02BCF120MEXAT	MSM120BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 120mm bore
02BCF120MGRAT	MSM120BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 120mm bore
02BCF125MEXAT	MSM125BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 125mm bore
02BCF125MGRAT	MSM125BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 125mm bore
02BCF130MEXAT	MSM130BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 130mm bore
02BCF130MGRAT	MSM130BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 130mm bore
02BCF140MEXAT	MSM140BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 140mm bore
02BCF140MGRAT	MSM140BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 140mm bore
02BCF150MEXAT	MSM150BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 150mm bore
02BCF150MGRAT	MSM150BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 150mm bore
02BCF155MEXAT	MSM155BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 155mm bore
02BCF155MGRAT	MSM155BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 155mm bore
02BCF160MEXAT	MSM160BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
02BCF160MGRAT	MSM160BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
02BCF170MEXAT	MSM170BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
02BCF170MGRAT	MSM170BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
02BCF180MEXAT	MSM180BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
02BCF180MGRAT	MSM180BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
02BCF190MEXAT	MSM190BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
02BCF190MGRAT	MSM190BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
02BCF200EXAT	MSE200BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 in. bore
02BCF200GRAT	MSE200BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 in. bore
02BCF200MEXAT	MSM200BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
02BCF200MGRAT	MSM200BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
02BCF203EXAT	MSE203BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 3/16 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02BCF203GRAT	MSE203BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 3/16 in. bore
02BCF204EXAT	MSE204BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 1/4 in. bore
02BCF204GRAT	MSE204BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 1/4 in. bore
02BCF207EXAT	MSE207BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 7/16 in. bore
02BCF207GRAT	MSE207BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 7/16 in. bore
02BCF208EXAT	MSE208BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 1/2 in. bore
02BCF208GRAT	MSE208BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 1/2 in. bore
02BCF211EXAT	MSE211BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 11/16 in. bore
02BCF211GRAT	MSE211BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 11/16 in. bore
02BCF212EXAT	MSE212BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 3/4 in. bore
02BCF212GRAT	MSE212BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 3/4 in. bore
02BCF215EXAT	MSE215BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 2 15/16 in. bore
02BCF215GRAT	MSE215BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 2 15/16 in. bore
02BCF220MEXAT	MSM220BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
02BCF220MGRAT	MSM220BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
02BCF240MEXAT	MSM240BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
02BCF240MGRAT	MSM240BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
02BCF260MEXAT	MSM260BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
02BCF260MGRAT	MSM260BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
02BCF280MEXAT	MSM280BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
02BCF280MGRAT	MSM280BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
02BCF300EXAT	MSE300BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 in. bore
02BCF300GRAT	MSE300BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 in. bore
02BCF300MEXAT	MSM300BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
02BCF300MGRAT	MSM300BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
02BCF303EXAT	MSE303BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 3/16 in. bore
02BCF303GRAT	MSE303BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 3/16 in. bore
02BCF304EXAT	MSE304BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 1/4 in. bore
02BCF304GRAT	MSE304BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 1/4 in. bore
02BCF307EXAT	MSE307BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 7/16 in. bore
02BCF307GRAT	MSE307BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 7/16 in. bore
02BCF308EXAT	MSE308BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 1/2 in. bore
02BCF308GRAT	MSE308BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 1/2 in. bore
02BCF311EXAT	MSE311BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 11/16 in. bore
02BCF311GRAT	MSE311BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 11/16 in. bore
02BCF312EXAT	MSE312BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 3/4 in. bore
02BCF312GRAT	MSE312BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 3/4 in. bore
02BCF315EXAT	MSE315BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 3 15/16 in. bore
02BCF315GRAT	MSE315BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 3 15/16 in. bore
02BCF400EXAT	MSE400BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 in. bore
02BCF400GRAT	MSE400BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 in. bore
02BCF403EXAT	MSE403BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 3/16 in. bore
02BCF403GRAT	MSE403BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 3/16 in. bore
02BCF407EXAT	MSE407BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 7/16 in. bore
02BCF407GRAT	MSE407BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 7/16 in. bore
02BCF408EXAT	MSE408BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 1/2 in. bore
02BCF408GRAT	MSE408BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 1/2 in. bore

Cooper Part Number	Timken Part Number	Timken Description
02BCF415EXAT	MSE415BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 15/16 in. bore
02BCF415GRAT	MSE415BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 15/16 in. bore
02BCF500EXAT	MSE500BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 in. bore
02BCF500GRAT	MSE500BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 in. bore
02BCF503EXAT	MSE503BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 3/16 in. bore
02BCF503GRAT	MSE503BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 3/16 in. bore
02BCF507EXAT	MSE507BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 7/16 in. bore
02BCF507GRAT	MSE507BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 7/16 in. bore
02BCF508EXAT	MSE508BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 1/2 in. bore
02BCF508GRAT	MSE508BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 1/2 in. bore
02BCF50MEXAT	MSM50BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 50mm bore
02BCF50MGRAT	MSM50BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 50mm bore
02BCF515EXAT	MSE515BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 15/16 in. bore
02BCF515GRAT	MSE515BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 15/16 in. bore
02BCF600EXAT	MSE600BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 in. bore
02BCF600GRAT	MSE600BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 in. bore
02BCF607EXAT	MSE607BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 7/16 in. bore
02BCF607GRAT	MSE607BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 7/16 in. bore
02BCF608EXAT	MSE608BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 1/2 in. bore
02BCF608GRAT	MSE608BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 1/2 in. bore
02BCF60MEXAT	MSM60BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 60mm bore
02BCF60MGRAT	MSM60BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 60mm bore
02BCF615EXAT	MSE615BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 15/16 in. bore
02BCF615GRAT	MSE615BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 15/16 in. bore
02BCF65MEXAT	MSM65BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 65mm bore
02BCF65MGRAT	MSM65BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 65mm bore
02BCF700EXAT	MSE700BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
02BCF700GRAT	MSE700BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
02BCF70MEXAT	MSM70BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 70mm bore
02BCF70MGRAT	MSM70BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 70mm bore
02BCF715EXAT	MSE715BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 15/16 in. bore
02BCF715GRAT	MSE715BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 15/16 in. bore
02BCF75MEXAT	MSM75BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 75mm bore
02BCF75MGRAT	MSM75BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 75mm bore
02BCF800EXAT	MSE800BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
02BCF800GRAT	MSE800BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
02BCF80MEXAT	MSM80BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 80mm bore
02BCF80MGRAT	MSM80BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 80mm bore
02BCF85MEXAT	MSM85BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 85mm bore
02BCF85MGRAT	MSM85BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 85mm bore
02BCF900EXAT	MSE900BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
02BCF900GRAT	MSE900BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
02BCF90MEXAT	MSM90BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 90mm bore
02BCF90MGRAT	MSM90BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 90mm bore
02BCFSAFC517211EXAT	MSE211BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 13/16 in. bore
02BCFSAFC517211GRAT	MSE211BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 13/16 in. bore
02BCFSAFC517212EXAT	MSE212BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 3/4 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02BCFS AFC517212GRAT	MSE212BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 ¾ in. bore
02BCFS AFC517215EXAT	MSE215BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 15/16 in. bore
02BCFS AFC517215GRAT	MSE215BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 15/16 in. bore
02BCFS AFC517300EXAT	MSE300BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 in. bore
02BCFS AFC517300GRAT	MSE300BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 in. bore
02BCFS AFC51770MEXAT	MSM70BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 70mm bore
02BCFS AFC51770MGRAT	MSM70BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 70mm bore
02BCFS AFC51775MEXAT	MSM75BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 75mm bore
02BCFS AFC51775MGRAT	MSM75BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 75mm bore
02BCFS AFC520303EXAT	MSE303BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 3/16 in. bore
02BCFS AFC520303GRAT	MSE303BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 3/16 in. bore
02BCFS AFC520304EXAT	MSE304BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 ¼ in. bore
02BCFS AFC520304GRAT	MSE304BRHFAFQAATL	
02BCFS AFC520307EXAT	MSE307BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 7/16 in. bore
02BCFS AFC520307GRAT	MSE307BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 7/16 in. bore
02BCFS AFC520308EXAT	MSE308BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 ½ in. bore
02BCFS AFC520308GRAT	MSE308BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 ½ in. bore
02BCFS AFC52080MEXAT	MSM80BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 80mm bore
02BCFS AFC52080MGRAT	MSM80BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 80mm bore
02BCFS AFC52085MEXAT	MSM85BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 85mm bore
02BCFS AFC52085MGRAT	MSM85BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 85mm bore
02BCFS AFC52090MEXAT	MSM85BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 85mm bore
02BCFS AFC52090MGRAT	MSM85BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 85mm bore
02BCP1000EXAT	MSE1000BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
02BCP1000GRAT	MSE1000BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
02BCP100MEXAT	MSM100BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
02BCP100MEXAT	MSM100BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
02BCP100MGRAT	MSM100BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
02BCP100MGRAT	MSM100BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
02BCP105MEXAT	MSM105BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
02BCP105MEXAT	MSM105BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
02BCP105MGRAT	MSM105BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
02BCP105MGRAT	MSM105BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 105mm bore
02BCP1100EXAT	MSE1100BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
02BCP1100GRAT	MSE1100BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
02BCP110MEXAT	MSM110BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 110mm bore
02BCP110MGRAT	MSM110BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 110mm bore
02BCP115EXAT	MSE115BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 1 15/16 in. bore
02BCP115GRAT	MSE115BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 1 15/16 in. bore
02BCP115MEXAT	MSM115BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 115mm bore
02BCP115MGRAT	MSM115BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 115mm bore
02BCP1200EXAT	MSE1200BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
02BCP1200GRAT	MSE1200BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
02BCP120MEXAT	MSM120BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 120mm bore
02BCP120MGRAT	MSM120BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 120mm bore
02BCP125MEXAT	MSM125BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 125mm bore
02BCP125MGRAT	MSM125BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 125mm bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02BCP420MEXLAB	MSM420BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
02BCP420MGRLAB	MSM420BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
02BCP440MEXLAB	MSM440BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
02BCP440MGRLAB	MSM440BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
02BCP460MEXLAB	MSM460BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
02BCP460MGRLAB	MSM460BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
02BCP480MEXLAB	MSM480BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
02BCP480MGRLAB	MSM480BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 480mm bore
02BCP500EXAT	MSE500BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 in. bore
02BCP500GRAT	MSE500BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 in. bore
02BCP500MEXLAB	MSM500BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
02BCP500MGRLAB	MSM500BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
02BCP503EXAT	MSE503BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 3/16 in. bore
02BCP503GRAT	MSE503BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 3/16 in. bore
02BCP507EXAT	MSE507BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 7/16 in. bore
02BCP507GRAT	MSE507BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 7/16 in. bore
02BCP508EXAT	MSE508BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 1/2 in. bore
02BCP508GRAT	MSE508BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 1/2 in. bore
02BCP50MEXAT	MSM50BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 50mm bore
02BCP50MGRAT	MSM50BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 50mm bore
02BCP512EXAT	MSE512BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 3/4 in. bore
02BCP512GRAT	MSE512BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 3/4 in. bore
02BCP515EXAT	MSE515BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 15/16 in. bore
02BCP515GRAT	MSE515BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 15/16 in. bore
02BCP530MEXLAB	MSM530BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
02BCP530MGRLAB	MSM530BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
02BCP560MEXLAB	MSM560BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
02BCP560MGRLAB	MSM560BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
02BCP600EXAT	MSE600BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 in. bore
02BCP600GRAT	MSE600BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 in. bore
02BCP600MEXLAB	MSM600BXHSLAB	Medium Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
02BCP600MGRLAB	MSM600BRHSLAB	Medium Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
02BCP607EXAT	MSE607BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
02BCP607GRAT	MSE607BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
02BCP608EXAT	MSE608BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore
02BCP608GRAT	MSE608BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore
02BCP60MEXAT	MSM60BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 60mm bore
02BCP60MGRAT	MSM60BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 60mm bore
02BCP615EXAT	MSE615BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 15/16 in. bore
02BCP615GRAT	MSE615BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 15/16 in. bore
02BCP65MEXAT	MSM65BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 65mm bore
02BCP65MGRAT	MSM65BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 65mm bore
02BCP700EXAT	MSE700BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
02BCP700GRAT	MSE700BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
02BCP708EXAT	MSE708BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 1/2 in. bore
02BCP708GRAT	MSE708BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 1/2 in. bore
02BCP70MEXAT	MSM70BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 70mm bore

Cooper Part Number	Timken Part Number	Timken Description
02BCP70MEXAT	MSM70BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 70mm bore
02BCP70MGRAT	MSM70BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 70mm bore
02BCP70MGRAT	MSM70BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 70mm bore
02BCP715EXAT	MSE715BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 1/8 in. bore
02BCP715GRAT	MSE715BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 1/8 in. bore
02BCP75MEXAT	MSM75BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 75mm bore
02BCP75MEXAT	MSM75BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 75mm bore
02BCP75MGRAT	MSM75BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 75mm bore
02BCP75MGRAT	MSM75BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 75mm bore
02BCP800EXAT	MSE800BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
02BCP800GRAT	MSE800BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
02BCP80MEXAT	MSM80BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
02BCP80MEXAT	MSM80BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
02BCP80MGRAT	MSM80BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
02BCP80MGRAT	MSM80BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 80mm bore
02BCP85MEXAT	MSM85BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
02BCP85MEXAT	MSM85BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
02BCP85MGRAT	MSM85BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
02BCP85MGRAT	MSM85BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 85mm bore
02BCP900EXAT	MSE900BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
02BCP900GRAT	MSE900BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
02BCP90MEXAT	MSM90BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
02BCP90MEXAT	MSM90BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
02BCP90MGRAT	MSM90BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
02BCP90MGRAT	MSM90BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 90mm bore
02BCSAFC517204EXAT	MSE204BXHSAFQATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 1/4 in. bore
02BCSAFC517204GRAT	MSE204BRHSAFQATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 1/4 in. bore
02BCSAFC517208EXAT	MSE208BXHSAFQATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 1/2 in. bore
02BCSAFC517208GRAT	MSE208BRHSAFQATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 1/2 in. bore
02BCSAFC518212EXAT	MSE212BXHSAFQBATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 3/4 in. bore
02BCSAFC518212GRAT	MSE212BRHSAFQBATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 3/4 in. bore
02BCSAFC520211EXAT	MSE211BXHSAFQATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 1/8 in. bore
02BCSAFC520211GRAT	MSE211BRHSAFQATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 1/8 in. bore
02BCSAFC520212EXAT	MSE212BXHSAFQATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 3/4 in. bore
02BCSAFC520212GRAT	MSE212BRHSAFQATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 2 3/4 in. bore
02BCSAFC522100MEXAT	MSM100BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 100mm bore
02BCSAFC522100MGRAT	MSM100BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 100mm bore
02BCSAFC522105MEXAT	MSM105BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 105mm bore
02BCSAFC522105MGRAT	MSM105BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 105mm bore
02BCSAFC522311EXAT	MSE311BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 1/8 in. bore
02BCSAFC522311GRAT	MSE311BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 1/8 in. bore
02BCSAFC522312EXAT	MSE312BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 3/4 in. bore
02BCSAFC522312GRAT	MSE312BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 3/4 in. bore
02BCSAFC522315EXAT	MSE315BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 1/4 in. bore
02BCSAFC522315GRAT	MSE315BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 3 1/4 in. bore
02BCSAFC522400EXAT	MSE400BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 in. bore
02BCSAFC522400GRAT	MSE400BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02BCSAFC526110MEXAT	MSM110BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 110mm bore
02BCSAFC526110MGRAT	MSM110BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 110mm bore
02BCSAFC526115MEXAT	MSM115BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 115mm bore
02BCSAFC526115MGRAT	MSM115BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 115mm bore
02BCSAFC526403EXAT	MSE403BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 3/16 in. bore
02BCSAFC526403GRAT	MSE403BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 3/16 in. bore
02BCSAFC526407EXAT	MSE407BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 7/16 in. bore
02BCSAFC526407GRAT	MSE407BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 7/16 in. bore
02BCSAFC526408EXAT	MSE408BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 1/2 in. bore
02BCSAFC526408GRAT	MSE408BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 1/2 in. bore
02BCSAFC528125MEXAT	MSM125BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 125mm bore
02BCSAFC528125MGRAT	MSM125BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 125mm bore
02BCSAFC528415EXAT	MSE415BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 15/16 in. bore
02BCSAFC528415GRAT	MSE415BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 4 15/16 in. bore
02BCSAFC528500EXAT	MSE500BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 in. bore
02BCSAFC528500GRAT	MSE500BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 in. bore
02BCSAFC532140MEXAT	MSM140BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 140mm bore
02BCSAFC532140MGRAT	MSM140BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 140mm bore
02BCSAFC532503EXAT	MSE503BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 3/16 in. bore
02BCSAFC532503GRAT	MSE503BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 3/16 in. bore
02BCSAFC532507EXAT	MSE507BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 7/16 in. bore
02BCSAFC532507GRAT	MSE507BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 7/16 in. bore
02BCSAFC532508EXAT	MSE508BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 1/2 in. bore
02BCSAFC532508GRAT	MSE508BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 1/2 in. bore
02BCSAFC534150MEXAT	MSM150BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 150mm bore
02BCSAFC534150MGRAT	MSM150BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 150mm bore
02BCSAFC534155MEXAT	MSM155BXHSAFQAATL	Medium Series Metric Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 155mm bore
02BCSAFC534155MGRAT	MSM155BRHSAFQAATL	Medium Series Metric Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 155mm bore
02BCSAFC534515EXAT	MSE515BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 15/16 in. bore
02BCSAFC534515GRAT	MSE515BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 5 15/16 in. bore
02BCSAFC534600EXAT	MSE600BXHSAFQAATL	Medium Series Imperial Expansion Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 6 in. bore
02BCSAFC534600GRAT	MSE600BRHSAFQAATL	Medium Series Imperial Retained Bearing SAF Dimensioned Full Housed Assembly (Quick Series) with ATL Seals: 6 in. bore
02C10EX	MS10HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C10GR	MS10HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C1300GR	MSE1300HR	Medium Series Imperial Retained Housing: 13 in. bore
02C1400GR	MSE1400HR	Medium Series Imperial Retained Housing: 14 in. bore
02C1500GR	MSE1500HR	Medium Series Imperial Retained Housing: 15 in. bore
02C1600GR	MSE1600HR	Medium Series Imperial Retained Housing: 16 in. bore
02C1700GR	MSE1700HR	Medium Series Imperial Retained Housing: 17 in. bore
02C1800GR	MSE1800HR	Medium Series Imperial Retained Housing: 18 in. bore
02C1900GR	MSE1900HR	Medium Series Imperial Retained Housing: 19 in. bore
02C2000GR	MSE2000HR	Medium Series Imperial Retained Housing: 20 in. bore
02C2100GR	MSE2100HR	Medium Series Imperial Retained Housing: 21 in. bore
02C2200GR	MSE2200HR	Medium Series Imperial Retained Housing: 22 in. bore
02C2300GR	MSE2300HR	Medium Series Imperial Retained Housing: 23 in. bore
02C2400GR	MSE2400HR	Medium Series Imperial Retained Housing: 24 in. bore
02C30EX	MS30HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals

Cooper Part Number	Timken Part Number	Timken Description
02C30GR	MS30HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C31EX	MS31HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C31GR	MS31HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C320MGR	MSM320HR	Medium Series Metric Retained Housing: 320mm bore
02C32GR	MS32HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C33GR	MS33HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C340MGR	MSM340HR	Medium Series Metric Retained Housing: 340mm bore
02C34GR	MS34HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C35GR	MS35HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C360MGR	MSM360HR	Medium Series Metric Retained Housing: 360mm bore
02C36GR	MS36HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C37GR	MS37HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C380MGR	MSM380HR	Medium Series Metric Retained Housing: 380mm bore
02C38GR	MS38HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C39GR	MS39HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C3EX	MS3HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C3GR	MS3HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C400MGR	MSM400HR	Medium Series Metric Retained Housing: 400mm bore
02C40GR	MS40HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C420MGR	MSM420HR	Medium Series Metric Retained Housing: 420mm bore
02C440MGR	MSM440HR	Medium Series Metric Retained Housing: 440mm bore
02C460MGR	MSM460HR	Medium Series Metric Retained Housing: 460mm bore
02C480MGR	MSM480HR	Medium Series Metric Retained Housing: 480mm bore
02C4EX	MS4HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C4GR	MS4HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C500MGR	MSM500HR	Medium Series Metric Retained Housing: 500mm bore
02C530MGR	MSM530HR	Medium Series Metric Retained Housing: 530mm bore
02C560MGR	MSM560HR	Medium Series Metric Retained Housing: 560mm bore
02C5EX	MS5HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C5GR	MS5HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C600MGR	MSM600HR	Medium Series Metric Retained Housing: 600mm bore
02C6EX	MS6HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C6GR	MS6HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C7EX	MS7HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C7GR	MS7HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02C8EX	MS8HXTL	Medium Series Housing configured for a Expansion Bearing and ATL Seals
02C8GR	MS8HRTL	Medium Series Housing configured for a Retained Bearing and ATL Seals
02EB1000EX	MSE1000BX	Medium Series Imperial Expansion Bearing: 10 in. bore
02EB1000GR	MSE1000BR	Medium Series Imperial Retained Bearing: 10 in. bore
02EB1100EX	MSE1100BX	Medium Series Imperial Expansion Bearing: 11 in. bore
02EB1100GR	MSE1100BR	Medium Series Imperial Retained Bearing: 11 in. bore
02EB1200EX	MSE1200BX	Medium Series Imperial Expansion Bearing: 12 in. bore
02EB1200GR	MSE1200BR	Medium Series Imperial Retained Bearing: 12 in. bore
02EB160MEX	MSM160BX	Medium Series Metric Expansion Bearing: 160mm bore
02EB160MGR	MSM160BR	Medium Series Metric Retained Bearing: 160mm bore
02EB170MEX	MSM170BX	Medium Series Metric Expansion Bearing: 170mm bore
02EB170MGR	MSM170BR	Medium Series Metric Retained Bearing: 170mm bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02EB180MEX	MSM180BX	Medium Series Metric Expansion Bearing: 180mm bore
02EB180MGR	MSM180BR	Medium Series Metric Retained Bearing: 180mm bore
02EB190MEX	MSM190BX	Medium Series Metric Expansion Bearing: 190mm bore
02EB190MGR	MSM190BR	Medium Series Metric Retained Bearing: 190mm bore
02EB200MEX	MSM200BX	Medium Series Metric Expansion Bearing: 200mm bore
02EB200MGR	MSM200BR	Medium Series Metric Retained Bearing: 200mm bore
02EB220MEX	MSM220BX	Medium Series Metric Expansion Bearing: 220mm bore
02EB220MGR	MSM220BR	Medium Series Metric Retained Bearing: 220mm bore
02EB240MEX	MSM240BX	Medium Series Metric Expansion Bearing: 240mm bore
02EB240MGR	MSM240BR	Medium Series Metric Retained Bearing: 240mm bore
02EB260MEX	MSM260BX	Medium Series Metric Expansion Bearing: 260mm bore
02EB260MGR	MSM260BR	Medium Series Metric Retained Bearing: 260mm bore
02EB280MEX	MSM280BX	Medium Series Metric Expansion Bearing: 280mm bore
02EB280MGR	MSM280BR	Medium Series Metric Retained Bearing: 280mm bore
02EB300MEX	MSM300BX	Medium Series Metric Expansion Bearing: 300mm bore
02EB300MGR	MSM300BR	Medium Series Metric Retained Bearing: 300mm bore
02EB607EX	MSE607BX	Medium Series Imperial Expansion Bearing: 6 7/16 in. bore
02EB607GR	MSE607BR	Medium Series Imperial Retained Bearing: 6 7/16 in. bore
02EB608EX	MSE608BX	Medium Series Imperial Expansion Bearing: 6 1/2 in. bore
02EB608GR	MSE608BR	Medium Series Imperial Retained Bearing: 6 1/2 in. bore
02EB615EX	MSE615BX	Medium Series Imperial Expansion Bearing: 6 15/16 in. bore
02EB615GR	MSE615BR	Medium Series Imperial Retained Bearing: 6 15/16 in. bore
02EB700EX	MSE700BX	Medium Series Imperial Expansion Bearing: 7 in. bore
02EB700GR	MSE700BR	Medium Series Imperial Retained Bearing: 7 in. bore
02EB715EX	MSE715BX	Medium Series Imperial Expansion Bearing: 7 15/16 in. bore
02EB715GR	MSE715BR	Medium Series Imperial Retained Bearing: 7 15/16 in. bore
02EB800EX	MSE800BX	Medium Series Imperial Expansion Bearing: 8 in. bore
02EB800GR	MSE800BR	Medium Series Imperial Retained Bearing: 8 in. bore
02EB900EX	MSE900BX	Medium Series Imperial Expansion Bearing: 9 in. bore
02EB900GR	MSE900BR	Medium Series Imperial Retained Bearing: 9 in. bore
02EBC1000EXAT	MSE1000BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 10 in. bore
02EBC1000GRAT	MSE1000BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 10 in. bore
02EBC1100EXAT	MSE1100BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 11 in. bore
02EBC1100GRAT	MSE1100BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 11 in. bore
02EBC1200EXAT	MSE1200BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 12 in. bore
02EBC1200GRAT	MSE1200BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 12 in. bore
02EBC160MEXAT	MSM160BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 160mm bore
02EBC160MGRAT	MSM160BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 160mm bore
02EBC170MEXAT	MSM170BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 170mm bore
02EBC170MGRAT	MSM170BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 170mm bore
02EBC180MEXAT	MSM180BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 180mm bore
02EBC180MGRAT	MSM180BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 180mm bore
02EBC190MEXAT	MSM190BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 190mm bore
02EBC190MGRAT	MSM190BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 190mm bore
02EBC200MEXAT	MSM200BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 200mm bore
02EBC200MGRAT	MSM200BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 200mm bore
02EBC220MEXAT	MSM220BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 220mm bore

Cooper Part Number	Timken Part Number	Timken Description
02EBC220MGRAT	MSM220BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 220mm bore
02EBC240MEXAT	MSM240BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 240mm bore
02EBC240MGRAT	MSM240BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 240mm bore
02EBC260MEXAT	MSM260BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 260mm bore
02EBC260MGRAT	MSM260BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 260mm bore
02EBC280MEXAT	MSM280BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 280mm bore
02EBC280MGRAT	MSM280BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 280mm bore
02EBC300MEXAT	MSM300BXHATL	Medium Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 300mm bore
02EBC300MGRAT	MSM300BRHATL	Medium Series Metric Retained Bearing with Housing Assembly and ATL Seals: 300mm bore
02EBC607EXAT	MSE607BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
02EBC607GRAT	MSE607BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
02EBC608EXAT	MSE608BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
02EBC608GRAT	MSE608BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
02EBC615EXAT	MSE615BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
02EBC615GRAT	MSE615BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
02EBC700EXAT	MSE700BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 in. bore
02EBC700GRAT	MSE700BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 in. bore
02EBC708EXAT	MSE708BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 1/2 in. bore
02EBC708GRAT	MSE708BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 1/2 in. bore
02EBC715EXAT	MSE715BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
02EBC715GRAT	MSE715BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
02EBC800EXAT	MSE800BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 8 in. bore
02EBC800GRAT	MSE800BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 8 in. bore
02EBC900EXAT	MSE900BXHATL	Medium Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 in. bore
02EBC900GRAT	MSE900BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 9 in. bore
02EBC915GRAT	MSE915BRHATL	Medium Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 9 15/16 in. bore
02EBCF1000EXAT	MSE1000BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
02EBCF1000GRAT	MSE1000BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
02EBCF1100EXAT	MSE1100BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
02EBCF1100GRAT	MSE1100BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 11 in. bore
02EBCF1200EXAT	MSE1200BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
02EBCF1200GRAT	MSE1200BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 12 in. bore
02EBCF160MEXAT	MSM160BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
02EBCF160MGRAT	MSM160BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 160mm bore
02EBCF170MEXAT	MSM170BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
02EBCF170MGRAT	MSM170BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 170mm bore
02EBCF180MEXAT	MSM180BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
02EBCF180MGRAT	MSM180BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
02EBCF190MEXAT	MSM190BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
02EBCF190MGRAT	MSM190BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 190mm bore
02EBCF200MEXAT	MSM200BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
02EBCF200MGRAT	MSM200BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 200mm bore
02EBCF220MEXAT	MSM220BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 220mm bore
02EBCF240MEXAT	MSM240BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
02EBCF240MGRAT	MSM240BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
02EBCF260MEXAT	MSM260BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
02EBCF260MGRAT	MSM260BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore

Cooper Part Number	Timken Part Number	Timken Description
02EBCF280MEXAT	MSM280BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
02EBCF280MGRAT	MSM280BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 280mm bore
02EBCF300MEXAT	MSM300BXHFATL	Medium Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
02EBCF300MGRAT	MSM300BRHFATL	Medium Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 300mm bore
02EBCF607EXAT	MSE607BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 7/16 in. bore
02EBCF607GRAT	MSE607BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 7/16 in. bore
02EBCF608EXAT	MSE608BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 1/2 in. bore
02EBCF608GRAT	MSE608BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 1/2 in. bore
02EBCF615EXAT	MSE615BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 15/16 in. bore
02EBCF615GRAT	MSE615BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 15/16 in. bore
02EBCF700EXAT	MSE700BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
02EBCF700GRAT	MSE700BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
02EBCF715EXAT	MSE715BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 15/16 in. bore
02EBCF715GRAT	MSE715BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 15/16 in. bore
02EBCF800EXAT	MSE800BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
02EBCF800GRAT	MSE800BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 8 in. bore
02EBCF900EXAT	MSE900BXHFATL	Medium Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
02EBCF900GRAT	MSE900BRHFATL	Medium Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 9 in. bore
02EBCP1000EXAT	MSE1000BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
02EBCP1000GRAT	MSE1000BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
02EBCP1100EXAT	MSE1100BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
02EBCP1100GRAT	MSE1100BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
02EBCP1200EXAT	MSE1200BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
02EBCP1200GRAT	MSE1200BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
02EBCP160MEXAT	MSM160BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
02EBCP160MGRAT	MSM160BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
02EBCP170MEXAT	MSM170BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
02EBCP170MGRAT	MSE170BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 2 in. bore
02EBCP180MEXAT	MSM180BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
02EBCP180MGRAT	MSM180BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
02EBCP190MEXAT	MSM190BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
02EBCP190MGRAT	MSM190BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
02EBCP200MEXAT	MSM200BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
02EBCP200MGRAT	MSM200BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
02EBCP220MEXAT	MSM220BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 220mm bore
02EBCP220MGRAT	MSM220BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 220mm bore
02EBCP240MEXAT	MSM240BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 240mm bore
02EBCP240MGRAT	MSM240BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 240mm bore
02EBCP260MEXAT	MSM260BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 260mm bore
02EBCP260MGRAT	MSM260BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 260mm bore
02EBCP280MEXAT	MSM280BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 280mm bore
02EBCP280MGRAT	MSM280BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 280mm bore
02EBCP300MEXAT	MSM300BXHSATL	Medium Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 300mm bore
02EBCP300MGRAT	MSM300BRHSATL	Medium Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 300mm bore
02EBCP607EXAT	MSE607BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
02EBCP607GRAT	MSE607BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 7/16 in. bore
02EBCP608EXAT	MSE608BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 1/2 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
02EBCP608GRAT	MSE608BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 ½ in. bore
02EBCP615EXAT	MSE615BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 15⁄16 in. bore
02EBCP615GRAT	MSE615BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 15⁄16 in. bore
02EBCP700EXAT	MSE700BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
02EBCP700GRAT	MSE700BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
02EBCP715EXAT	MSE715BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 15⁄16 in. bore
02EBCP715GRAT	MSE715BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 15⁄16 in. bore
02EBCP800EXAT	MSE800BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
02EBCP800GRAT	MSE800BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
02EBCP900EXAT	MSE900BXHSATL	Medium Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
02EBCP900GRAT	MSE900BRHSATL	Medium Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
03B1000EX	HSE1000BX	Heavy Series Imperial Expansion Bearing: 10 in. bore
03B1000GR	HSE1000BR	Heavy Series Imperial Retained Bearing: 10 in. bore
03B100MEX	HSM100BX	Heavy Series Metric Expansion Bearing: 100mm bore
03B100MGR	HSM100BR	Heavy Series Metric Retained Bearing: 100mm bore
03B110MEX	HSM110BX	Heavy Series Metric Expansion Bearing: 110mm bore
03B110MGR	HSM110BR	Heavy Series Metric Retained Bearing: 110mm bore
03B115MEX	HSM115BX	Heavy Series Metric Expansion Bearing: 115mm bore
03B115MGR	HSM115BR	Heavy Series Metric Retained Bearing: 115mm bore
03B1200EX	HSE1200BX	Heavy Series Imperial Expansion Bearing: 12 in. bore
03B1200GR	HSE1200BR	Heavy Series Imperial Retained Bearing: 12 in. bore
03B120MEX	HSM120BX	Heavy Series Metric Expansion Bearing: 120mm bore
03B120MGR	HSM120BR	Heavy Series Metric Retained Bearing: 120mm bore
03B1300EX	HSE1300BX	Heavy Series Imperial Expansion Bearing: 13 in. bore
03B1300GR	HSE1300BR	Heavy Series Imperial Retained Bearing: 13 in. bore
03B130MEX	HSM130BX	Heavy Series Metric Expansion Bearing: 130mm bore
03B130MGR	HSM130BR	Heavy Series Metric Retained Bearing: 130mm bore
03B140MEX	HSM140BX	Heavy Series Metric Expansion Bearing: 140mm bore
03B140MGR	HSM140BR	Heavy Series Metric Retained Bearing: 140mm bore
03B1500EX	HSE1500BX	Heavy Series Imperial Expansion Bearing: 15 in. bore
03B1500GR	HSE1500BR	Heavy Series Imperial Retained Bearing: 15 in. bore
03B150MEX	HSM150BX	Heavy Series Metric Expansion Bearing: 150mm bore
03B150MGR	HSM150BR	Heavy Series Metric Retained Bearing: 150mm bore
03B155MEX	HSM155BX	Heavy Series Metric Expansion Bearing: 155mm bore
03B155MGR	HSM155BR	Heavy Series Metric Retained Bearing: 155mm bore
03B160MEX	HSM160BX	Heavy Series Metric Expansion Bearing: 160mm bore
03B160MGR	HSM160BR	Heavy Series Metric Retained Bearing: 160mm bore
03B170MEX	HSM170BX	Heavy Series Metric Expansion Bearing: 170mm bore
03B170MGR	HSM170BR	Heavy Series Metric Retained Bearing: 170mm bore
03B180MEX	HSM180BX	Heavy Series Metric Expansion Bearing: 180mm bore
03B180MGR	HSM180BR	Heavy Series Metric Retained Bearing: 180mm bore
03B190MEX	HSM190BX	Heavy Series Metric Expansion Bearing: 190mm bore
03B190MGR	HSM190BR	Heavy Series Metric Retained Bearing: 190mm bore
03B2000EX	HSE2000BX	Heavy Series Imperial Expansion Bearing: 20 in. bore
03B2000GR	HSE2000BR	Heavy Series Imperial Retained Bearing: 20 in. bore
03B200MEX	HSM200BX	Heavy Series Metric Expansion Bearing: 200mm bore
03B200MGR	HSM200BR	Heavy Series Metric Retained Bearing: 200mm bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
03B220MEX	HSM220BX	Heavy Series Metric Expansion Bearing: 220mm bore
03B220MGR	HSM220BR	Heavy Series Metric Retained Bearing: 220mm bore
03B240MEX	HSM240BX	Heavy Series Metric Expansion Bearing: 240mm bore
03B240MGR	HSM240BR	Heavy Series Metric Retained Bearing: 240mm bore
03B260MEX	HSM260BX	Heavy Series Metric Expansion Bearing: 260mm bore
03B260MGR	HSM260BR	Heavy Series Metric Retained Bearing: 260mm bore
03B300MEX	HSM300BX	Heavy Series Metric Expansion Bearing: 300mm bore
03B300MGR	HSM300BR	Heavy Series Metric Retained Bearing: 300mm bore
03B315EX	HSE315BX	Heavy Series Imperial Expansion Bearing: 3 1/8 in. bore
03B315GR	HSE315BR	Heavy Series Imperial Retained Bearing: 3 1/8 in. bore
03B320MEX	HSM320BX	Heavy Series Metric Expansion Bearing: 320mm bore
03B320MGR	HSM320BR	Heavy Series Metric Retained Bearing: 320mm bore
03B380MEX	HSM380BX	Heavy Series Metric Expansion Bearing: 380mm bore
03B380MGR	HSM380BR	Heavy Series Metric Retained Bearing: 380mm bore
03B400EX	HSE400BX	Heavy Series Imperial Expansion Bearing: 4 in. bore
03B400GR	HSE400BR	Heavy Series Imperial Retained Bearing: 4 in. bore
03B400MEX	HSM400BX	Heavy Series Metric Expansion Bearing: 400mm bore
03B400MGR	HSM400BR	Heavy Series Metric Retained Bearing: 400mm bore
03B407EX	HSE407BX	Heavy Series Imperial Expansion Bearing: 4 7/16 in. bore
03B407GR	HSE407BR	Heavy Series Imperial Retained Bearing: 4 7/16 in. bore
03B408EX	HSE408BX	Heavy Series Imperial Expansion Bearing: 4 1/2 in. bore
03B408GR	HSE408BR	Heavy Series Imperial Retained Bearing: 4 1/2 in. bore
03B415EX	HSE415BX	Heavy Series Imperial Expansion Bearing: 4 15/16 in. bore
03B415GR	HSE415BR	Heavy Series Imperial Retained Bearing: 4 15/16 in. bore
03B500EX	HSE500BX	Heavy Series Imperial Expansion Bearing: 5 in. bore
03B500GR	HSE500BR	Heavy Series Imperial Retained Bearing: 5 in. bore
03B500MEX	HSM500BX	Heavy Series Metric Expansion Bearing: 500mm bore
03B500MGR	HSM500BR	Heavy Series Metric Retained Bearing: 500mm bore
03B507EX	HSE507BX	Heavy Series Imperial Expansion Bearing: 5 7/16 in. bore
03B507GR	HSE507BR	Heavy Series Imperial Retained Bearing: 5 7/16 in. bore
03B508EX	HSE508BX	Heavy Series Imperial Expansion Bearing: 5 1/2 in. bore
03B508GR	HSE508BR	Heavy Series Imperial Retained Bearing: 5 1/2 in. bore
03B515EX	HSE515BX	Heavy Series Imperial Expansion Bearing: 5 15/16 in. bore
03B515GR	HSE515BR	Heavy Series Imperial Retained Bearing: 5 15/16 in. bore
03B530MEX	HSM530BX	Heavy Series Metric Expansion Bearing: 530mm bore
03B530MGR	HSM530BR	Heavy Series Metric Retained Bearing: 530mm bore
03B600EX	HSE600BX	Heavy Series Imperial Expansion Bearing: 6 in. bore
03B600GR	HSE600BR	Heavy Series Imperial Retained Bearing: 6 in. bore
03B607EX	HSE607BX	Heavy Series Imperial Expansion Bearing: 6 7/16 in. bore
03B607GR	HSE607BR	Heavy Series Imperial Retained Bearing: 6 7/16 in. bore
03B608EX	HSE608BX	Heavy Series Imperial Expansion Bearing: 6 1/2 in. bore
03B608GR	HSE608BR	Heavy Series Imperial Retained Bearing: 6 1/2 in. bore
03B615EX	HSE615BX	Heavy Series Imperial Expansion Bearing: 6 15/16 in. bore
03B615GR	HSE615BR	Heavy Series Imperial Retained Bearing: 6 15/16 in. bore
03B700EX	HSE700BX	Heavy Series Imperial Expansion Bearing: 7 in. bore
03B700GR	HSE700BR	Heavy Series Imperial Retained Bearing: 7 in. bore
03B715EX	HSE715BX	Heavy Series Imperial Expansion Bearing: 7 15/16 in. bore

Cooper Part Number	Timken Part Number	Timken Description
03B715GR	HSE715BR	Heavy Series Imperial Retained Bearing: 7 15/16 in. bore
03B800EX	HSE800BX	Heavy Series Imperial Expansion Bearing: 8 in. bore
03B800GR	HSE800BR	Heavy Series Imperial Retained Bearing: 8 in. bore
03B900EX	HSE900BX	Heavy Series Imperial Expansion Bearing: 9 in. bore
03B900GR	HSE900BR	Heavy Series Imperial Retained Bearing: 9 in. bore
03BC1000EXAT	HSE1000BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 10 in. bore
03BC1000GRAT	HSE1000BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 10 in. bore
03BC100MEXAT	HSM100BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 100mm bore
03BC100MGRAT	HSM100BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 100mm bore
03BC110MEXAT	HSM110BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 110mm bore
03BC110MGRAT	HSM110BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 110mm bore
03BC115MEXAT	HSM115BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 115mm bore
03BC115MGRAT	HSM115BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 115mm bore
03BC1200EXAT	HSE1200BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 12 in. bore
03BC1200GRAT	HSE1200BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 12 in. bore
03BC120MEXAT	HSM120BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 120mm bore
03BC120MGRAT	HSM120BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 120mm bore
03BC1300EXLAB	HSE1300BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
03BC1300GRLAB	HSE1300BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
03BC130MEXAT	HSM130BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 130mm bore
03BC130MGRAT	HSM130BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 130mm bore
03BC140MEXAT	HSM140BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 140mm bore
03BC140MGRAT	HSM140BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 140mm bore
03BC1500EXLAB	HSE1500BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
03BC1500GRLAB	HSE1500BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
03BC150MEXAT	HSM150BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 150mm bore
03BC150MGRAT	HSM150BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 150mm bore
03BC160MEXAT	HSM160BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 160mm bore
03BC160MGRAT	HSM160BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 160mm bore
03BC170MEXAT	HSM170BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 170mm bore
03BC170MGRAT	HSM170BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 170mm bore
03BC180MEXAT	HSM180BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 180mm bore
03BC180MGRAT	HSM180BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 180mm bore
03BC190MEXAT	HSM190BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 190mm bore
03BC190MGRAT	HSM190BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 190mm bore
03BC2000EXLAB	HSE2000BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
03BC2000GRLAB	HSE2000BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
03BC200MEXAT	HSM200BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 200mm bore
03BC200MGRAT	HSM200BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 200mm bore
03BC220MEXAT	HSM220BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 220mm bore
03BC220MGRAT	HSM220BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 220mm bore
03BC240MEXAT	HSM240BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 240mm bore
03BC240MGRAT	HSM240BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 240mm bore
03BC260MEXAT	HSM260BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 260mm bore
03BC260MGRAT	HSM260BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 260mm bore
03BC300MEXAT	HSM300BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 300mm bore
03BC300MGRAT	HSM300BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 300mm bore

Cooper Part Number	Timken Part Number	Timken Description
03BC315EXAT	HSE315BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 3 15/16 in. bore
03BC315GRAT	HSE315BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 3 15/16 in. bore
03BC320MEXLAB	HSM320BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
03BC320MGRLAB	HSM320BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
03BC380MEXLAB	HSM380BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
03BC380MGRLAB	HSM380BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
03BC400EXAT	HSE400BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 in. bore
03BC400GRAT	HSE400BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 in. bore
03BC400MEXLAB	HSM400BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
03BC400MGRLAB	HSM400BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
03BC407EXAT	HSE407BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 7/16 in. bore
03BC407GRAT	HSE407BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 7/16 in. bore
03BC408EXAT	HSE408BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 1/2 in. bore
03BC408GRAT	HSE408BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 1/2 in. bore
03BC415EXAT	HSE415BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 4 15/16 in. bore
03BC415GRAT	HSE415BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 4 15/16 in. bore
03BC500EXAT	HSE500BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 in. bore
03BC500GRAT	HSE500BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 in. bore
03BC500MEXLAB	HSM500BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
03BC500MGRLAB	HSM500BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
03BC507EXAT	HSE507BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 7/16 in. bore
03BC507GRAT	HSE507BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 7/16 in. bore
03BC508EXAT	HSE508BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 1/2 in. bore
03BC508GRAT	HSE508BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 1/2 in. bore
03BC515EXAT	HSE515BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 5 15/16 in. bore
03BC515GRAT	HSE515BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 5 15/16 in. bore
03BC530MEXLAB	HSM530BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
03BC530MGRLAB	HSM530BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
03BC600EXAT	HSE600BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 in. bore
03BC600GRAT	HSE600BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 in. bore
03BC607EXAT	HSE607BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
03BC607GRAT	HSE607BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 7/16 in. bore
03BC608EXAT	HSE608BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
03BC608GRAT	HSE608BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 1/2 in. bore
03BC615EXAT	HSE615BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
03BC615GRAT	HSE615BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 6 15/16 in. bore
03BC700EXAT	HSE700BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 in. bore
03BC700GRAT	HSE700BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 in. bore
03BC715EXAT	HSE715BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
03BC715GRAT	HSE715BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 7 15/16 in. bore
03BC800EXAT	HSE800BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 8 in. bore
03BC800GRAT	HSE800BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 8 in. bore
03BC900EXAT	HSE900BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 9 in. bore
03BC900GRAT	HSE900BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 9 in. bore
03BCF1000EXAT	HSE1000BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
03BCF1000GRAT	HSE1000BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 10 in. bore
03BCF125MEXAT	HSM125BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 125mm bore

Cooper Part Number	Timken Part Number	Timken Description
03BCF125MGRAT	HSM125BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 125mm bore
03BCF130MEXAT	HSM130BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 130mm bore
03BCF130MGRAT	HSM130BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 130mm bore
03BCF150MEXAT	HSM150BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 150mm bore
03BCF150MGRAT	HSM150BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 150mm bore
03BCF155MEXAT	HSM155BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 155mm bore
03BCF155MGRAT	HSM155BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 155mm bore
03BCF180MEXAT	HSM180BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
03BCF180MGRAT	HSM180BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 180mm bore
03BCF240MEXAT	HSM240BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
03BCF240MGRAT	HSM240BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 240mm bore
03BCF250MEXAT	HSM250BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 250mm bore
03BCF250MGRAT	HSM250BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 250mm bore
03BCF260MEXAT	HSM260BXHFATL	Heavy Series Metric Expansion Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
03BCF260MGRAT	HSM260BRHFATL	Heavy Series Metric Retained Bearing with Housing with Flange Assembly and ATL Seals: 260mm bore
03BCF411EXAT	HSE411BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 1/16 in. bore
03BCF411GRAT	HSE411BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 1/16 in. bore
03BCF412EXAT	HSE412BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 3/4 in. bore
03BCF412GRAT	HSE412BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 3/4 in. bore
03BCF415EXAT	HSE415BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 4 15/16 in. bore
03BCF415GRAT	HSE415BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 4 15/16 in. bore
03BCF500EXAT	HSE500BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 in. bore
03BCF500GRAT	HSE500BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 in. bore
03BCF511EXAT	HSE511BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 1/16 in. bore
03BCF511GRAT	HSE511BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 1/16 in. bore
03BCF512EXAT	HSE512BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 3/4 in. bore
03BCF512GRAT	HSE512BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 3/4 in. bore
03BCF515EXAT	HSE515BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 5 15/16 in. bore
03BCF515GRAT	HSE515BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 5 15/16 in. bore
03BCF600EXAT	HSE600BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 in. bore
03BCF600GRAT	HSE600BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 in. bore
03BCF602EXAT	HSE602BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 1/4 in. bore
03BCF602GRAT	HSE602BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 1/4 in. bore
03BCF612EXAT	HSE612BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 3/4 in. bore
03BCF612GRAT	HSE612BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 3/4 in. bore
03BCF615EXAT	HSE615BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 6 15/16 in. bore
03BCF615GRAT	HSE615BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 6 15/16 in. bore
03BCF700EXAT	HSE700BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
03BCF700GRAT	HSE700BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 7 in. bore
03BCF908EXAT	HSE908BXHFATL	Heavy Series Imperial Expansion Bearing with Housing with Flange Assembly and ATL Seals: 9 1/2 in. bore
03BCF908GRAT	HSE908BRHFATL	Heavy Series Imperial Retained Bearing with Housing with Flange Assembly and ATL Seals: 9 1/2 in. bore
03BCP1000EXAT	HSE1000BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
03BCP1000GRAT	HSE1000BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 10 in. bore
03BCP100MEXAT	HSM100BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
03BCP100MGRAT	HSM100BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 100mm bore
03BCP110MEXAT	HSM110BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 110mm bore
03BCP110MGRAT	HSM110BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 110mm bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
03BCP1200EXAT	HSE1200BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
03BCP1200GRAT	HSE1200BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 12 in. bore
03BCP120MEXAT	HSM120BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 120mm bore
03BCP120MGRAT	HSM120BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 120mm bore
03BCP1300EXLAB	HSE1300BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
03BCP1300GRLAB	HSE1300BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 13 in. bore
03BCP130MEXAT	HSM130BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 130mm bore
03BCP130MGRAT	HSM130BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 130mm bore
03BCP140MEXAT	HSM140BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 140mm bore
03BCP140MGRAT	HSM140BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 140mm bore
03BCP1500EXLAB	HSE1500BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
03BCP1500GRLAB	HSE1500BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 15 in. bore
03BCP150MEXAT	HSM150BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 150mm bore
03BCP150MGRAT	HSM150BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 150mm bore
03BCP160MEXAT	HSM160BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
03BCP160MGRAT	HSM160BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 160mm bore
03BCP170MEXAT	HSM170BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
03BCP170MGRAT	HSM170BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 170mm bore
03BCP180MEXAT	HSM180BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
03BCP180MGRAT	HSM180BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 180mm bore
03BCP190MEXAT	HSM190BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
03BCP190MGRAT	HSM190BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 190mm bore
03BCP2000EXLAB	HSE2000BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
03BCP2000GRLAB	HSE2000BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 20 in. bore
03BCP200MEXAT	HSM200BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
03BCP200MGRAT	HSM200BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 200mm bore
03BCP220MEXAT	HSM220BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 220mm bore
03BCP220MGRAT	HSM220BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 220mm bore
03BCP240MEXAT	HSM240BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 240mm bore
03BCP240MGRAT	HSM240BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 240mm bore
03BCP260MEXAT	HSM260BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 260mm bore
03BCP260MGRAT	HSM260BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 260mm bore
03BCP300MEXAT	HSM300BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 300mm bore
03BCP300MGRAT	HSM300BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 300mm bore
03BCP315EXAT	HSE315BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 3 1/8 in. bore
03BCP315GRAT	HSE315BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 3 1/8 in. bore
03BCP320MEXLAB	HSM320BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
03BCP320MGRLAB	HSM320BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 320mm bore
03BCP380MEXLAB	HSM380BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
03BCP380MGRLAB	HSM380BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 380mm bore
03BCP400EXAT	HSE400BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 in. bore
03BCP400GRAT	HSE400BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 in. bore
03BCP400MEXLAB	HSM400BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
03BCP400MGRLAB	HSM400BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 400mm bore
03BCP407EXAT	HSE407BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 7/16 in. bore
03BCP407GRAT	HSE407BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 7/16 in. bore
03BCP408EXAT	HSE408BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 1/2 in. bore

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
03BCP408GRAT	HSE408BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 ½ in. bore
03BCP415EXAT	HSE415BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 4 ¼ in. bore
03BCP415GRAT	HSE415BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 4 ¼ in. bore
03BCP500EXAT	HSE500BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 in. bore
03BCP500GRAT	HSE500BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 in. bore
03BCP500MEXLAB	HSM500BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
03BCP500MGRLAB	HSM500BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 500mm bore
03BCP507EXAT	HSE507BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 ⅞ in. bore
03BCP507GRAT	HSE507BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 ⅞ in. bore
03BCP508EXAT	HSE508BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 ½ in. bore
03BCP508GRAT	HSE508BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 ½ in. bore
03BCP515EXAT	HSE515BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 5 ¼ in. bore
03BCP515GRAT	HSE515BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 5 ¼ in. bore
03BCP530MEXLAB	HSM530BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
03BCP530MGRLAB	HSM530BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 530mm bore
03BCP600EXAT	HSE600BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 in. bore
03BCP600GRAT	HSE600BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 in. bore
03BCP607EXAT	HSE607BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 ⅞ in. bore
03BCP607GRAT	HSE607BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 ⅞ in. bore
03BCP608EXAT	HSE608BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 ½ in. bore
03BCP608GRAT	HSE608BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 ½ in. bore
03BCP615EXAT	HSE615BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 6 ¼ in. bore
03BCP615GRAT	HSE615BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 6 ¼ in. bore
03BCP700EXAT	HSE700BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
03BCP700GRAT	HSE700BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 in. bore
03BCP715EXAT	HSE715BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 7 ¼ in. bore
03BCP715GRAT	HSE715BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 7 ¼ in. bore
03BCP800EXAT	HSE800BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
03BCP800GRAT	HSE800BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 8 in. bore
03BCP900EXAT	HSE900BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
03BCP900GRAT	HSE900BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 9 in. bore
03C1300GR	HSE1300HR	Heavy Series Imperial Retained Housing: 13 in. bore
03C1500GR	HSE1500HR	Heavy Series Imperial Retained Housing: 15 in. bore
03C2000GR	HSE2000HR	Heavy Series Imperial Retained Housing: 20 in. bore
03C320MGR	HSM320HR	Heavy Series Metric Retained Housing: 320mm bore
03C380MGR	HSM380HR	Heavy Series Metric Retained Housing: 380mm bore
03C400MGR	HSM400HR	Heavy Series Metric Retained Housing: 400mm bore
03C500MGR	HSM500HR	Heavy Series Metric Retained Housing: 500mm bore
03C530MGR	HSM530HR	Heavy Series Metric Retained Housing: 530mm bore
03C54EX	HS54HXTL	Heavy Series Housing configured for a Expansion Bearing and ATL Seals
03C54GR	HS54HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C55EX	HS55HXTL	Heavy Series Housing configured for a Expansion Bearing and ATL Seals
03C55GR	HS55HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C56EX	HS56HXTL	Heavy Series Housing configured for a Expansion Bearing and ATL Seals
03C56GR	HS56HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C57EX	HS57HXTL	Heavy Series Housing configured for a Expansion Bearing and ATL Seals
03C57GR	HS57HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
03C58EX	HS58HXTL	Heavy Series Housing configured for a Expansion Bearing and ATL Seals
03C58GR	HS58HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C59GR	HS59HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C60GR	HS60HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C61GR	HS61HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C62GR	HS62HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C63GR	HS63HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03C65GR	HS65HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
03EB1100EX	HSE1100BX	Heavy Series Imperial Expansion Bearing: 11 in. bore
03EB1100GR	HSE1100BR	Heavy Series Imperial Retained Bearing: 11 in. bore
03EB1400EX	HSE1400BX	Heavy Series Imperial Expansion Bearing: 14 in. bore
03EB1400GR	HSE1400BR	Heavy Series Imperial Retained Bearing: 14 in. bore
03EB1700EX	HSE1700BX	Heavy Series Imperial Expansion Bearing: 17 in. bore
03EB1700GR	HSE1700BR	Heavy Series Imperial Retained Bearing: 17 in. bore
03EB1800EX	HSE1800BX	Heavy Series Imperial Expansion Bearing: 18 in. bore
03EB1800GR	HSE1800BR	Heavy Series Imperial Retained Bearing: 18 in. bore
03EB2200EX	HSE2200BX	Heavy Series Imperial Expansion Bearing: 22 in. bore
03EB2200GR	HSE2200BR	Heavy Series Imperial Retained Bearing: 22 in. bore
03EB2300EX	HSE2300BX	Heavy Series Imperial Expansion Bearing: 23 in. bore
03EB2300GR	HSE2300BR	Heavy Series Imperial Retained Bearing: 23 in. bore
03EB280MEX	HSM280BX	Heavy Series Metric Expansion Bearing: 280mm bore
03EB280MGR	HSM280BR	Heavy Series Metric Retained Bearing: 280mm bore
03EB340MEX	HSM340BX	Heavy Series Metric Expansion Bearing: 340mm bore
03EB340MGR	HSM340BR	Heavy Series Metric Retained Bearing: 340mm bore
03EB360MEX	HSM360BX	Heavy Series Metric Expansion Bearing: 360mm bore
03EB360MGR	HSM360BR	Heavy Series Metric Retained Bearing: 360mm bore
03EB420MEX	HSM420BX	Heavy Series Metric Expansion Bearing: 420mm bore
03EB420MGR	HSM420BR	Heavy Series Metric Retained Bearing: 420mm bore
03EB440MEX	HSM440BX	Heavy Series Metric Expansion Bearing: 440mm bore
03EB440MGR	HSM440BR	Heavy Series Metric Retained Bearing: 440mm bore
03EB460MEX	HSM460BX	Heavy Series Metric Expansion Bearing: 460mm bore
03EB460MGR	HSM460BR	Heavy Series Metric Retained Bearing: 460mm bore
03EB560MEX	HSM560BX	Heavy Series Metric Expansion Bearing: 560mm bore
03EB560MGR	HSM560BR	Heavy Series Metric Retained Bearing: 560mm bore
03EB600MEX	HSM600BX	Heavy Series Metric Expansion Bearing: 600mm bore
03EB600MGR	HSM600BR	Heavy Series Metric Retained Bearing: 600mm bore
03EBC1100EXAT	HSE1100BXHATL	Heavy Series Imperial Expansion Bearing with Housing Assembly and ATL Seals: 11 in. bore
03EBC1100GRAT	HSE1100BRHATL	Heavy Series Imperial Retained Bearing with Housing Assembly and ATL Seals: 11 in. bore
03EBC1400EXLAB	HSE1400BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
03EBC1400GRLAB	HSE1400BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
03EBC1700EXLAB	HSE1700BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
03EBC1700GRLAB	HSE1700BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
03EBC1800EXLAB	HSE1800BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
03EBC1800GRLAB	HSE1800BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
03EBC2200EXLAB	HSE2200BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
03EBC2200GRLAB	HSE2200BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
03EBC2300EXLAB	HSE2300BXHLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore

Cooper Part Number	Timken Part Number	Timken Description
03EBC2300GRLAB	HSE2300BRHLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
03EBC280MEXAT	HSM280BXHATL	Heavy Series Metric Expansion Bearing with Housing Assembly and ATL Seals: 280mm bore
03EBC280MGRAT	HSM280BRHATL	Heavy Series Metric Retained Bearing with Housing Assembly and ATL Seals: 280mm bore
03EBC340MEXLAB	HSM340BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
03EBC340MGRLAB	HSM340BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
03EBC360MEXLAB	HSM360BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
03EBC360MGRLAB	HSM360BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
03EBC420MEXLAB	HSM420BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
03EBC420MGRLAB	HSM420BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
03EBC440MEXLAB	HSM440BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
03EBC440MGRLAB	HSM440BRJLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
03EBC460MEXLAB	HSM460BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
03EBC460MGRLAB	HSM460BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
03EBC560MEXLAB	HSM560BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
03EBC560MGRLAB	HSM560BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
03EBC600MEXLAB	HSM600BXHLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
03EBC600MGRLAB	HSM600BRHLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
03EBCP1100EXAT	HSE1100BXHSATL	Heavy Series Imperial Expansion Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
03EBCP1100GRAT	HSE1100BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 11 in. bore
03EBCP1400EXLAB	HSE1400BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
03EBCP1400GRLAB	HSE1400BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 14 in. bore
03EBCP1700EXLAB	HSE1700BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
03EBCP1700GRLAB	HSE1700BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 17 in. bore
03EBCP1800EXLAB	HSE1800BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
03EBCP1800GRLAB	HSE1800BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 18 in. bore
03EBCP2200EXLAB	HSE2200BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
03EBCP2200GRLAB	HSE2200BRHSLAB	Heavy Series Imperial Retained Bearing with Housing Assembly with a labyrinth grease groove: 22 in. bore
03EBCP2300EXLAB	HSE2300BXHSLAB	Heavy Series Imperial Expansion Bearing with Housing Assembly with a labyrinth grease groove: 23 in. bore
03EBCP2300GRLAB	HSE2300BRHSATL	Heavy Series Imperial Retained Bearing Full Housing Assembly with ATL Seals and support: 23 in. bore
03EBCP280MEXAT	HSM280BXHSATL	Heavy Series Metric Expansion Bearing Full Housing Assembly with ATL Seals and support: 280mm bore
03EBCP280MGRAT	HSM280BRHSATL	Heavy Series Metric Retained Bearing Full Housing Assembly with ATL Seals and support: 280mm bore
03EBCP340MEXLAB	HSM340BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
03EBCP340MGRLAB	HSM340BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 340mm bore
03EBCP360MEXLAB	HSM360BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
03EBCP360MGRLAB	HSM360BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 360mm bore
03EBCP420MEXLAB	HSM420BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
03EBCP420MGRLAB	HSM420BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 420mm bore
03EBCP440MEXLAB	HSM440BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
03EBCP440MGRLAB	HSM440BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 440mm bore
03EBCP460MEXLAB	HSM460BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
03EBCP460MGRLAB	HSM460BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 460mm bore
03EBCP560MEXLAB	HSM560BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
03EBCP560MGRLAB	HSM560BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 560mm bore
03EBCP600MEXLAB	HSM600BXHSLAB	Heavy Series Metric Expansion Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
03EBCP600MGRLAB	HSM600BRHSLAB	Heavy Series Metric Retained Bearing with Housing Assembly with a labyrinth grease groove: 600mm bore
03EC1400GR	HSE1400HR	Heavy Series Imperial Retained Housing: 14 in. bore
03EC1800GR	HSE1800HR	Heavy Series Imperial Retained Housing: 18 in. bore

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
03EC2200GR	HSE2200HR	Heavy Series Imperial Retained Housing: 22 in. bore
03EC2300GR	HSE2300HR	Heavy Series Imperial Retained Housing: 23 in. bore
03EC340MGR	HSM340HR	Heavy Series Metric Retained Housing: 340mm bore
03EC360MGR	HSM360HR	Heavy Series Metric Retained Housing: 360mm bore
03EC420MGR	HSM420HR	Heavy Series Metric Retained Housing: 420mm bore
03EC440MGR	HSM440HR	Heavy Series Metric Retained Housing: 440mm bore
03EC560MGR	HSM560HR	Heavy Series Metric Retained Housing: 560mm bore
03EC600MGR	HSM600HR	Heavy Series Metric Retained Housing: 600mm bore
03EC83GR	HS83HRTL	Heavy Series Housing configured for a Retained Bearing and ATL Seals
ATL1000	1000ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 10 in.
ATL100M	100MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 100MM
ATL103	103ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 3/8 in.
ATL104	104ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 1/4 in.
ATL105M	105MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 105MM
ATL107	107ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 7/8 in.
ATL108	108ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 1/2 in.
ATL1100	1100ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 11 in.
ATL110M	110MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 110MM
ATL110M/100	No Timken equivalent	
ATL111	111ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 in.
ATL112	112ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 in.
ATL115	115ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 1 in.
ATL115M	115MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 115MM
ATL1200	1200ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 12 in.
ATL120M	120MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 120MM
ATL120M/100	No Timken equivalent	
ATL125M	125MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 125MM
ATL1300	1300ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 13 in.
ATL130M	130MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 130MM
ATL130M/100	No Timken equivalent	
ATL135M	135MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 135MM
ATL1400	1400ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 14 in.
ATL140M	140MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 140MM
ATL150M	150MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 150MM
ATL155M	155MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 155MM
ATL160M	160MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 160MM
ATL170M	170MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 170MM
ATL180M	180MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 180MM
ATL190M	190MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 190MM
ATL200	200ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 in.
ATL200M	200MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 200MM
ATL203	203ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 3/8 in.
ATL204	204ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 1/4 in.
ATL207	207ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 7/8 in.
ATL208	208ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 1/2 in.
ATL211	211ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 in.
ATL212	212ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 in.

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
ATL215	215ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 2 in.
ATL215/100	No Timken equivalent	
ATL220M	220MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 220MM
ATL240M	240MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 240MM
ATL260M	260MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 260MM
ATL280M	280MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 280MM
ATL300	300ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 in.
ATL300M	300MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 300MM
ATL303	303ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 3/16 in.
ATL304	304ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 1/4 in.
ATL307	307ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 7/16 in.
ATL308	308ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 1/2 in.
ATL30M	30MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 30MM
ATL311	311ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 in.
ATL312	312ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 in.
ATL315	315ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 3 in.
ATL320M	320MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 320MM
ATL35M	35MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 35MM
ATL400	400ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 in.
ATL403	403ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 3/16 in.
ATL407	407ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 7/16 in.
ATL408	408ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 1/2 in.
ATL40M	40MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 40MM
ATL411	411ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 in.
ATL412	412ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 in.
ATL415	415ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 4 in.
ATL45M	45MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 45MM
ATL500	500ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 in.
ATL503	503ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 3/16 in.
ATL504	504ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 1/4 in.
ATL507	507ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 7/16 in.
ATL508	508ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 1/2 in.
ATL50M	50MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 50MM
ATL511	511ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 in.
ATL515	515ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 5 in.
ATL55M	55MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 55MM
ATL600	600ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 6 in.
ATL607	607ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 6 7/16 in.
ATL608	608ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 6 1/2 in.
ATL60M	60MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 60MM
ATL615	615ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 6 in.
ATL65M	65MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 65MM
ATL700	700ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 7 in.
ATL708	708ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 7 1/2 in.
ATL70M	70MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 70MM
ATL715	715ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 7 in.
ATL75M	75MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 75MM

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
ATL800	800ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 8 in.
ATL80M	80MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 80MM
ATL85M	85MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 85MM
ATL900	900ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 9 in.
ATL908	908ATL	Aluminium Triple Labyrinth Seal (2 required): Bore 9 1/2 in.
ATL90M	90MMATL	Aluminium Triple Labyrinth Seal (2 required): Bore 90MM
DF02	DF02	Square Flange Support - No Housing or Bearing
DF03	DF03	Square Flange Support - No Housing or Bearing
DF04	DF04	Square Flange Support - No Housing or Bearing
F01	F01	Standard Flange - No Housing or Bearing
F02	F02	Standard Flange - No Housing or Bearing
F03	F03	Standard Flange - No Housing or Bearing
F04	F04	Standard Flange - No Housing or Bearing
F05	F05	Standard Flange - No Housing or Bearing
F06	F06	Standard Flange - No Housing or Bearing
F07	F07	Standard Flange - No Housing or Bearing
F08	F08	Standard Flange - No Housing or Bearing
F09	F09	Standard Flange - No Housing or Bearing
F10	F10	Standard Flange - No Housing or Bearing
F11	F11	Standard Flange - No Housing or Bearing
F12	F12	Standard Flange - No Housing or Bearing
F13	F13	Standard Flange - No Housing or Bearing
F14	F14	Standard Flange - No Housing or Bearing
F15	F15	Standard Flange - No Housing or Bearing
F16	F16	Standard Flange - No Housing or Bearing
F17	F17	Standard Flange - No Housing or Bearing
F30	F30	Standard Flange - No Housing or Bearing
F31	F31	Standard Flange - No Housing or Bearing
F32	F32	Standard Flange - No Housing or Bearing
F33	F33	Standard Flange - No Housing or Bearing
F34	F34	Standard Flange - No Housing or Bearing
F35	F35	Standard Flange - No Housing or Bearing
F36	F36	Standard Flange - No Housing or Bearing
F37	F37	Standard Flange - No Housing or Bearing
F38	F38	Standard Flange - No Housing or Bearing
FSAFC517	SAFQ05A-2B	SAF Equivalent Support (Quick Series) - No Housing or Bearing
FSAFC520	SAFQ06A	SAF Dimensioned Support - No housing or Bearing
P01	S01	Standard Support - No Housing or Bearing
P02	S02	Standard Support - No Housing or Bearing
P03	S03	Standard Support - No Housing or Bearing
P04	S04	Standard Support - No Housing or Bearing
P05	S05	Standard Support - No Housing or Bearing
P0510	S05-4B	Standard Support 4 Bolt Version - No Housing or Bearing
P06	S06	Standard Support - No Housing or Bearing
P0613	S06-4B	Standard Support 4 Bolt Version - No Housing or Bearing
P07	S07	Standard Support - No Housing or Bearing
P0710	S07-4B	Standard Support 4 Bolt Version - No Housing or Bearing

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

Cooper Part Number	Timken Part Number	Timken Description
P08	S08	Standard Support - No Housing or Bearing
P09	S09	Standard Support - No Housing or Bearing
P10	S10	Standard Support - No Housing or Bearing
P11	S11	Standard Support - No Housing or Bearing
P12	S12	Standard Support - No Housing or Bearing
P13	S13	Standard Support - No Housing or Bearing
P14	S14	Standard Support - No Housing or Bearing
P15	S15	Standard Support - No Housing or Bearing
P16	S16	Standard Support - No Housing or Bearing
P17	S17	Standard Support - No Housing or Bearing
P18	S18	Standard Support - No Housing or Bearing
P19	S19	Standard Support - No Housing or Bearing
P20	S20	Standard Support - No Housing or Bearing
P21	S21	Standard Support - No Housing or Bearing
P22	S22	Standard Support - No Housing or Bearing
P23	S23	Standard Support - No Housing or Bearing
P24	S24	Standard Support - No Housing or Bearing
P25	S25	Standard Support - No Housing or Bearing
P26	S26	Standard Support - No Housing or Bearing
P27	S27	Standard Support - No Housing or Bearing
P28	S28	Standard Support - No Housing or Bearing
P29	S29	Standard Support - No Housing or Bearing
P30	S30	Standard Support - No Housing or Bearing
P31	S31	Standard Support - No Housing or Bearing
P32	S32	Standard Support - No Housing or Bearing
P33	S33	Standard Support - No Housing or Bearing
P34	S34	Standard Support - No Housing or Bearing
P35	S35	Standard Support - No Housing or Bearing
P36	S36	Standard Support - No Housing or Bearing
P37	S37	Standard Support - No Housing or Bearing
P38	S38	Standard Support - No Housing or Bearing
P39	S39	Standard Support - No Housing or Bearing
P40	S40	Standard Support - No Housing or Bearing
P41	S41	Standard Support - No Housing or Bearing
P42	S42	Standard Support - No Housing or Bearing
P43	S43	Standard Support - No Housing or Bearing
P44	S44	Standard Support - No Housing or Bearing
P45	S45	Standard Support - No Housing or Bearing
P46	S46	Standard Support - No Housing or Bearing
P47	S47	Standard Support - No Housing or Bearing
P48	S48	Standard Support - No Housing or Bearing
P49	S49	Standard Support - No Housing or Bearing
P50	S50	Standard Support - No Housing or Bearing
P54	S54	Standard Support - No housing or Bearing
P55	S55	Standard Support - No housing or Bearing
P56	S56	Standard Support - No housing or Bearing
P57	S57	Standard Support - No housing or Bearing

Cooper Part Number	Timken Part Number	Timken Description
P58	S58	Standard Support - No Housing or Bearing
P59	S59	Standard Support - No housing or Bearing
P60	S60	Standard Support - No housing or Bearing
P61	S61	Standard Support - No housing or Bearing
P62	S62	Standard Support - No housing or Bearing
P63	S63	Standard Support - No Housing or Bearing
P65	S65	Standard Support - No housing or Bearing
P66	S66	Standard Support - No Housing or Bearing
P68	S68	Standard Support - No housing or Bearing
P83	S83	Standard Support - No housing or Bearing
P86	S86	Standard Support - No housing or Bearing
P89	S89	Standard Support - No housing or Bearing
P90	S90	Standard Support - No housing or Bearing
P94	S94	Standard Support - No housing or Bearing
P95	S95	Standard Support - No housing or Bearing
SAFC511	SAFQ02A-2B	SAF Dimensioned Support - No housing or Bearing
SAFC513	SAFQ03-2B	SAF Dimensioned Support - No housing or Bearing
SAFC515	SAFQ03A-2B	SAF Dimensioned Support - No housing or Bearing
SAFC516	SAFQ04A-2B	SAF Dimensioned Support - No housing or Bearing
SAFC517	SAFQ04-2B	SAF Dimensioned Support - No housing or Bearing
SAFC518	SAFQ05B-2B	SAF Dimensioned Support - No housing or Bearing
SAFC520	SAFQ05-2B	SAF Dimensioned Support - No housing or Bearing
SAFC522	SAFQ07A	SAF Dimensioned Support - No housing or Bearing
SAFC526	SAFQ08A	SAF Dimensioned Support - No housing or Bearing
SAFC528	SAFQ10A	SAF Dimensioned Support - No housing or Bearing
SAFC532	SAFQ30	SAF Dimensioned Support - No housing or Bearing
SAFC534	SAFQ31	SAF Dimensioned Support - No housing or Bearing
SNC513	SNQ03	SN/SD Dimensioned Support - No housing or Bearing
SNC515	SNQ03A	SN/SD Dimensioned Support - No housing or Bearing
SNC516	SNQ04	SN/SD Dimensioned Support - No housing or Bearing
SNC517	SNQ04	SN/SD Dimensioned Support - No housing or Bearing
SNC518	SNQ05	SN/SD Dimensioned Support - No housing or Bearing
SNC519	SNQ05A	SN/SD Dimensioned Support - No housing or Bearing
SNC520	SNQ05B	SN/SD Dimensioned Support - No housing or Bearing
SNC522	SNQ06	SN/SD Dimensioned Support - No housing or Bearing
SNC524	SNQ07	SN/SD Dimensioned Support - No housing or Bearing
SNC526	SNQ07A	SN/SD Dimensioned Support - No housing or Bearing
SNC528	SNQ08	SN/SD Dimensioned Support - No housing or Bearing
SNC530	SNQ09	SN/SD Dimensioned Support - No housing or Bearing
SNC532	SNQ09A	SN/SD Dimensioned Support - No housing or Bearing

INTERCHANGE GUIDE

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

SAF Housing	Shaft Size	Timken Split Cylindrical Roller Housed Unit
509	1 3/8 in. - Imperial	LSE103BRHSAFQATL
509	1 1/4 in. - Imperial	LSE104BRHSAFQATL
509	1 7/8 in. - Imperial	LSE107BRHSAFQATL
510	1 11/16 in. - Imperial	LSE111BRHSAFQATL
510	1 3/4 in. - Imperial	LSE112BRHSAFQATL
511	1 13/16 in. - Imperial	LSE111BRHSAFQAATL
511	1 3/4 in. - Imperial	LSE112BRHSAFQAATL
511	1 15/16 in. - Imperial	LSE115BRHSAFQAATL
511	2 in. - Imperial	LSE200BRHSAFQAATL
513	2 3/8 in. - Imperial	LSE203BRHSAFQATL
513	2 1/4 in. - Imperial	LSE204BRHSAFQATL
513	2 7/8 in. - Imperial	LSE207BRHSAFQATL
513	2 1/2 in. - Imperial	LSE208BRHSAFQATL
515	2 3/8 in. - Imperial	LSE203BRHSAFQAATL
515	2 1/4 in. - Imperial	LSE204BRHSAFQAATL
515	2 7/8 in. - Imperial	LSE207BRHSAFQAATL
515	2 1/2 in. - Imperial	LSE208BRHSAFQAATL
516	2 11/16 in. - Imperial	LSE211BRHSAFQAATL
516	2 3/4 in. - Imperial	LSE212BRHSAFQAATL
516	2 15/16 in. - Imperial	LSE215BRHSAFQAATL
516	3 in. - Imperial	LSE300BRHSAFQAATL
517	2 1/4 in. - Imperial	MSE204BRHSAFQATL
517	2 1/2 in. - Imperial	MSE208BRHSAFQATL
517	2 11/16 in. - Imperial	LSE211BRHSAFQATL
517	2 13/16 in. - Imperial	MSE211BRHSAFQAATL
517	2 3/4 in. - Imperial	LSE212BRHSAFQATL
517	2 3/4 in. - Imperial	MSE212BRHSAFQAATL
517	2 15/16 in. - Imperial	LSE215BRHSAFQATL
517	2 15/16 in. - Imperial	MSE215BRHSAFQAATL
517	3 in. - Imperial	MSE300BRHSAFQAATL
518	3 3/8 in. - Imperial	LSE303BRHSAFQBATL
518	3 1/4 in. - Imperial	LSE304BRHSAFQBATL
520	3 7/8 in. - Imperial	MSE307BRHSAFQAATL
520	3 1/2 in. - Imperial	MSE308BRHSAFQAATL
522	3 11/16 in. - Imperial	MSE311BRHSAFQAATL
522	3 3/4 in. - Imperial	MSE312BRHSAFQAATL
522	3 15/16 in. - Imperial	MSE315BRHSAFQAATL
522	4 in. - Imperial	MSE400BRHSAFQAATL
524	4 3/8 in. - Imperial	LSE403BRHSAFQBATL
524	4 1/4 in. - Imperial	LSE404BRHSAFQBATL
524	4 3/8 in. - Imperial	LSE406BRHSAFQBATL
524	4 7/8 in. - Imperial	LSE407BRHSAFQBATL
524	4 1/2 in. - Imperial	LSE408BRHSAFQBATL
526	4 3/8 in. - Imperial	MSE403BRHSAFQAATL
526	4 1/4 in. - Imperial	MSE404BRHSAFQAATL
526	4 1/2 in. - Imperial	MSE408BRHSAFQAATL
526	4 7/8 in. - Imperial	MSE407BRHSAFQAATL

SAF Housing	Shaft Size	Timken Split Cylindrical Roller Housed Unit
528	4 1/8 in. - Imperial	MSE415BRHSAFQAATL
528	5 in. - Imperial	MSE500BRHSAFQAATL
530	5 3/8 in. - Imperial	LSE503BRHSAFQAATL
530	5 1/4 in. - Imperial	LSE504BRHSAFQAATL
530	5 7/8 in. - Imperial	LSE507BRHSAFQAATL
530	5 1/2 in. - Imperial	LSE508BRHSAFQAATL
532	5 3/8 in. - Imperial	MSE503BRHSAFQATL
532	5 1/4 in. - Imperial	MSE504BRHSAFQATL
532	5 7/8 in. - Imperial	MSE507BRHSAFQATL
532	5 1/2 in. - Imperial	MSE508BRHSAFQATL
534	5 11/16 in. - Imperial	MSE511BRHSAFQATL
534	5 3/4 in. - Imperial	MSE512BRHSAFQATL
534	5 15/16 in. - Imperial	MSE515BRHSAFQATL
534	6 in. - Imperial	MSE600BRHSAFQATL
536	6 7/8 in. - Imperial	MSE607BRHSAFQATL
536	6 1/2 in. - Imperial	MSE608BRHSAFQATL
538	6 11/16 in. - Imperial	LSE611BRHSAFQATL
538	6 3/4 in. - Imperial	LSE612BRHSAFQATL
538	6 15/16 in. - Imperial	LSE615BRHSAFQATL
538	7 in. - Imperial	LSE700BRHSAFQATL
540	7 3/8 in. - Imperial	LSE703BRHSAFQATL
540	7 1/4 in. - Imperial	LSE704BRHSAFQATL
540	7 1/2 in. - Imperial	LSE708BRHSAFQATL
540	7 15/16 in. - Imperial	LSE715BRHSAFQATL
540	8 in. - Imperial	LSE800BRHSAFQATL
544	7 3/8 in. - Imperial	MSE703BRHSAFQAATL
544	7 1/4 in. - Imperial	MSE704BRHSAFQAATL
544	7 1/2 in. - Imperial	MSE708BRHSAFQAATL
544	7 15/16 in. - Imperial	MSE715BRHSAFQAATL
544	8 in. - Imperial	MSE800BRHSAFQAATL

SPLIT CYLINDRICAL ROLLER BEARINGS INTERCHANGE GUIDE

SN Housing	Shaft Size	Timken Split Cylindrical Roller Housed Unit
508	35mm - Metric	LSM35BRHSNQATL
509	40mm - Metric	LSM40BRHSNQATL
509	1 7/8 in. - Imperial	LSE107BRHSNQATL
509	1 1/2 in. - Imperial	LSE108BRHSNQATL
510	45mm - Metric	LSM45BRHSNQATL
510	1 1/4 in. - Imperial	LSE111BRHSNQATL
510	1 3/4 in. - Imperial	LSE112BRHSNQATL
511	50mm - Metric	LSM50BRHSNQATL
511	1 3/8 in. - Imperial	LSE115BRHSNQATL
511	2 in. - Imperial	LSE200BRHSNQATL
513	60mm - Metric	LSM60BRHSNQATL
513	2 3/8 in. - Imperial	LSE203BRHSNQATL
513	2 1/4 in. - Imperial	LSE204BRHSNQATL
515	65mm - Metric	LSM65BRHSNQATL
515	2 7/8 in. - Imperial	LSE207BRHSNQATL
515	2 1/2 in. - Imperial	LSE208BRHSNQATL
516	70mm - Metric	LSM70BRHSNQATL
516	2 1/8 in. - Imperial	LSE211BRHSNQATL
516	2 3/4 in. - Imperial	LSE212BRHSNQATL
517	75mm - Metric	LSM75BRHSNQATL
517	2 1/2 in. - Imperial	LSE215BRHSNQATL
517	3 in. - Imperial	LSE300BRHSNQATL
518	80mm - Metric	LSM80BRHSNQATL
518	3 3/8 in. - Imperial	LSE303BRHSNQATL
518	3 1/4 in. - Imperial	LSE304BRHSNQATL
519	85mm - Metric	LSM85BRHSNQATL
520	90mm - Metric	LSM90BRHSNQATL
520	3 7/8 in. - Imperial	LSE307BRHSNQATL
520	3 1/2 in. - Imperial	LSE308BRHSNQATL
522	100mm - Metric	LSM100BRHSNQATL
522	3 1/8 in. - Imperial	LSE315BRHSNQATL
522	4 in. - Imperial	LSE400BRHSNQATL
524	110mm - Metric	LSM115BRHSNQATL
524	4 3/8 in. - Imperial	LSE403BRHSNQATL
524	4 1/4 in. - Imperial	LSE404BRHSNQATL
526	115mm - Metric	LSM115BRHSNQATL
526	4 7/8 in. - Imperial	LSE407BRHSNQATL
526	4 1/2 in. - Imperial	LSE408BRHSNQATL
528	125mm - Metric	LSM125BRHSNQATL
528	4 1/8 in. - Imperial	LSE415BRHSNQATL
528	5 in. - Imperial	LSE500BRHSNQATL
530	135mm - Metric	LSM135BRHSNQATL
530	5 3/8 in. - Imperial	LSE503BRHSNQATL
532	140mm - Metric	LSM140BRHSNQATL
532	5 7/8 in. - Imperial	LSE507BRHSNQATL
532	5 1/2 in. - Imperial	LSE508BRHSNQATL

SD3100 Housing	Shaft Size	Timken Split Cylindrical Roller Housed Unit
3134	150mm - Metric	LSM150BRHSDQATL
3136	160mm - Metric	LSM160BRHSDQATL
3138	170mm - Metric	LSM170BRHSDQATL
3140	180mm - Metric	LSM180BRHSDQATL
3144	200mm - Metric	LSM200BRHSDQATL
3148	220mm - Metric	LSM220BRHSDQATL
3152	240mm - Metric	LSM240BRHSDQATL
3156	260mm - Metric	LSM260BRHSDQATL
3160	280mm - Metric	LSM280BRHSDQATL
3164	300mm - Metric	LSM300BRHSDQATL

TIMKEN

The Timken team applies their know-how to improve the reliability and performance of machinery in diverse markets worldwide. The company designs, makes and markets bearings, gear drives, automated lubrication systems, belts, brakes, clutches, chain, couplings, linear motion products and related power transmission rebuild and repair services.

Stronger. By Design.

www.timken.com